



## Model No. 6327EURD

66mm wide ProSeries® Weather Tough® with shrouded shackle

### Best Used For:



Industrial,  
Storefront &  
Business Gates



Residential Gates &  
Fences



Sheds, Workshops  
& Garages



Self-Storage Units &  
Lockers



Tools, Job Boxes &  
Gang Boxes

### Security Level:



High to maximum  
security:

Recommended for all use  
including industrial applications

## Overview & Features

## Product Features

- Ideal for harsh outdoor conditions - exclusive Pro Series® Weather Tough® cover protects lock from water, ice, dirt and grime
- 66mm heavy steel body withstands physical attack
- Hardened boron alloy shackle for maximum cut resistance
- Iron shroud protects shackle from bolt cutters
- Dual ball locking mechanism resists pulling and prying
- High security 5-pin cylinder with spool pins is virtually impossible to pick
- Limited Lifetime Warranty

## Certifications




## Product Details

The Master Lock No. 6327EURD ProSeries® Shrouded Padlock features a 66mm heavy steel body that withstands physical attack and a 18mm tall, 11mm diameter hardened boron alloy shackle for superior cut resistance. Ideal for transportation and industrial applications, the iron shroud protects the shackle from bolt cutters and a dual ball locking mechanism resists pulling and prying. The high security 5-pin cylinder with spool pins is virtually impossible to pick. The Limited Lifetime Warranty provides peace of mind from a brand you can trust.

Product Specifications

Product Number	6327EURD
Body Width	66mm
Shackle Dimensions	A: 11mm B: 18mm C: 22mm
Colour	Black
Description	Keyed Different
Shelf Pack Qty	4
Master Carton Qty	24

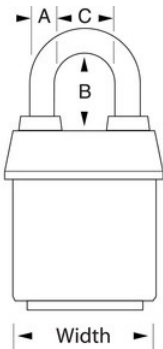

Master Lock Europe S.A.S.

10 avenue de l'arche - Le Colisée Gardens, bâtiment A - 92 400 Courbevoie - La Défense - France  
O:+33-1-41437200 | F:+33-1-41437204  
www.masterlock.eu