


12W USB CHARGER - USB-A

Application

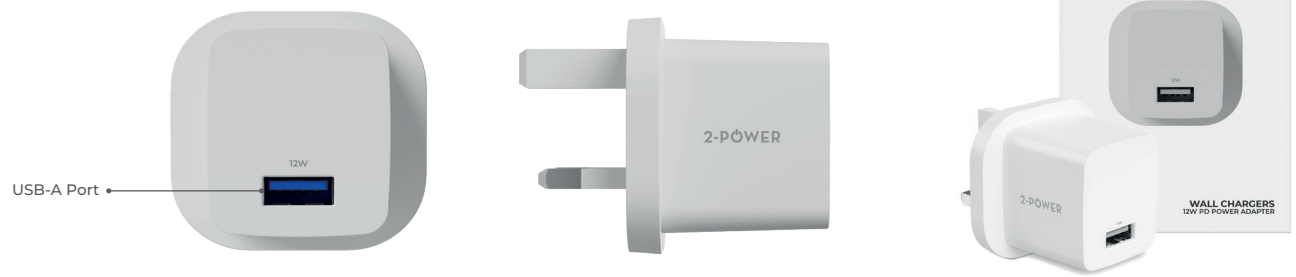

Specification

Model	2PWC12W01-UK
Region	UK
Input	100-240VAC 50/60Hz
Standby input power	0.1W
Output	USB-A: 5V/2.4A, 12W max
Operating temperature range	0 - 25°C
Efficiency	≥ 79.9% @ 5V
Size (L*W*H)	50.2mm *46.7mm *39.2mm
Weight	50±10g
EAN	5056304398195
Warranty	2 Years

32W USB PD CHARGER - USB-C & USB-A

Application



Specification

Model	2PWC32W02-UK
Region	UK
Input	100-240VAC 50/60Hz
Standby input power	0.3W
Output	USB-C: 5V3A, 9V/2.22A, 20W max USB-A: 5V/2.4A, 12W max
Operating temperature range	0 - 25°C
Efficiency	5V Output ≥ 81.84% 9V Output ≥ 85.96%
Size (L*W*H)	59.5mm *58.3mm *27.7mm
Weight	110±20g
EAN	5056304398218
Warranty	2 Years

45W GaN USB PD CHARGER - USB-C

Application



Specification

Model	2PWC45W01G-UK
Region	UK
Input	100-240VAC 50/60Hz 1.5A max
Standby input power	0.1W
Output	USB-C: 5V3A, 9V/3A, 15V/3A, 20V/2.25A, 45W max
Operating temperature range	0 - 25°C
Efficiency	≥ 81.84%@5V ≥ 85.96%@9V ≥ 86.7%@15V ≥ 87.4%@20V
Size (L*W*H)	48.5mm*48.3mm*27.7mm
Weight	75±15g
EAN	5056304398232
Warranty	2 Years

65W GaN USB PD CHARGER - USB-C x2

Application



Specification

Model	2PWC65W02G-UK
Region	UK
Input	100-240VAC 50/60Hz 1.5A max
Standby input power	0.3W
Output single port	USB-C1/USB-C2: PD5V/3A, 9V/3A, 12V/3A, 15V/3A, 20V/3.25A (65W) PPS:3.3V-21V/3.25A 65W Max
Output dual port	USB-C1: PD45W (PD: 5V/3A, 9V/3A, 12V/3A, 20V/2.25A) USB-C2: PD20W (5V/3A, 9V/2,22A)
Operating temperature range	0 - 25°C
Efficiency	≥ 81.61% @ 5V/3A+5V/3A ≥ 84.65% @ 9V/2.22A+20V/2.25A ≥ 88% @ 20V/3.25A
Size (L*W*H)	51.6mm*50mm*46.5mm
Weight	120±20g
EAN	5056304398256
Warranty	2 Years