


Pallet Trucks

GX 2000 SERIES HAND PALLET TRUCK

- 2000 and 2500 kg capacity models available
- Highly manoeuvrable, steers through full 230°
- Spares and service available on request

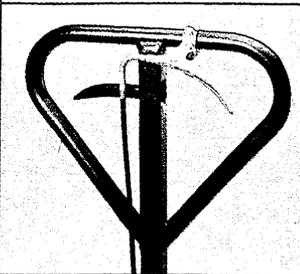

OPTIONAL BRAKE GX006B

- Progressive brake system
- Brake incorporates parking facility

GX252N - 2500 kg Cap

- Fork width 150 mm
- Fork height when lowered 85 mm
- Fork height when raised 200 mm
- Overall height 1160 mm

GX202N - 2000 kg Cap

GX 2000 SERIES

This robust range of hand pallet trucks has been designed to be compact thus reducing the overall length. This combined with its unique steering arrangement reduces the actual pulling effort required. The highly efficient hydraulic system makes pumping easier and enables rapid lifting and lowering on a continuous basis. Controlled lowering is made possible through the use of the trigger lever. All other functions, pumping and drive (neutral), are automatically selected.

Fork length mm	Width over forks mm	Weight approx kg	2000 kg cap unit Nylon Roller / Steering Wheels	Price	2500 kg Cap unit Nylon Roller / Steering Wheels	Price	FACTORY FITTED OPTIONAL EXTRAS	Ref	Price
810	450	58	GX205N		GX255N		Single Polyurethane Rollers / Steering Wheels:	GX001P	
910		58	GX206N		GX256N		Single steel rollers only	GX002S	
1000		59	GX207N		GX257N		Steel steering wheels only	GX022S	
	60	GX201N		GX251N		Tandem Rollers: Nylon	GX003N		
1150	62	GX202N		GX252N		Polyurethane (with steering to match)	GX004P		
	61	GX208N		GX258N		Steel (with steering to match)	GX005S		
1220	60	GX209N		GX259N		Braking system - complete with rubber steering wheels	GX006B		
	61	GX203N		GX253N					
	63	GX204N		GX254N					

LOW PROFILE TRUCK GX101N


- Reduced fork height of 57 mm
- Units made to meet your specific requirement with maximum length of 1220 mm and overall width of 685 mm, Please specify when ordering.

REEL CARRIER TRUCK GX102N

When ordering please specify the maximum diameter of the reel to enable the truck to be made specifically to your individual requirements. N.B. This maximum diameter will then determine the minimum size reel this pallet truck can take, which is 66% of the maximum reel size quoted. Catalogue price is based on maximum fork length of 1220 mm and width of 685 mm.

Product Description	Model Nylon Roller / Steering Wheels	Price
Low Profile Truck. Specify fork sizes required when ordering	GX101N	
Reel Carrier Truck made to suit individual requirements. Specify max. reel diameter when ordering	GX102N	

Made to order sizes available on request

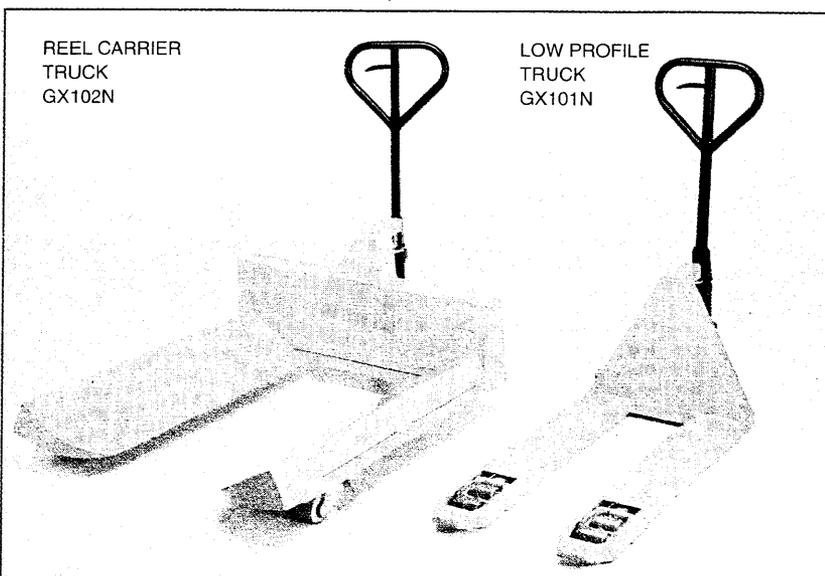

3

DAYS DESPATCH