


OMNITRONIC ODP-208T Installation Speaker 100V black

Weather-proof 8" wall speaker (IP65) with mount, 150 W RMS

Art. No.: 11036960

GTIN: 4026397629781

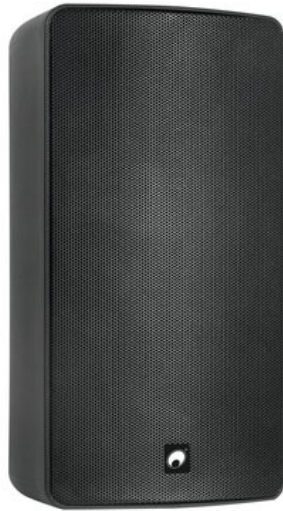

List price: 320.11 €

incl. 19% VAT.

Description:

Great sound - also runs with 100 volts

You want reliable and balanced sound for your bar, restaurant, shop or the conference area of your hotel? You need indoor and outdoor speakers? With the OPD series you get powerful installation speakers that meets all your requirements.

The speakers have a brilliant sound pattern and are available in a low ohm (16 ohms) and in a 100 V version. These two cover both small and large installations. A rotatable mounting bracket is included in the delivery. A swivel wall mount with matching colors is optionally available.

With their weatherproofed (IP65) plastic cabinet the ODP speakers are well prepared for outdoor use, indoor use is of course also possible.

Features:

- 2-way system with 20 cm woofer (8") and 2.5 cm dome tweeter (1")
- Durable plastic cabinet with metal grille
- Power selector switch with 16 ohms operating position
- Screw plug terminal for easy handling
- With Mounting bracket
- Black aluminum grille with acoustic foam
- Suitable for outdoor use IP65
- For application areas such as: Trade fair and shop fitting; restaurants, bars and hotels; product presentations and lectures

Package contents

- 1 x user manual, 1 x top, 1 x mounting bracket, 6 x screw, 1 x safety eyelet, 1 x lid, 2 x washer, 1 x screwing, 1 x screw plug-in terminal

Logistic

EAN / GTIN: 4026397629781

Weight: 11,75 kg

Length: 0.36 m

Width: 0.30 m

Height: 0.51 m

Technical specifications:

IP classification:	IP65
Power:	Program: 300W Rated: 150W RMS
Frequency range:	60 - 18000 Hz
Sensitivity:	94 dB (1W/1m)
Max. SPL:	116 dB
Dispersion angle:	90° x 50°
Impedance:	16 ohms; Public address systems 100V
Attachment system:	Mounting bracket
Power tapping:	37,5W; 75W; 150W RMS via Selector switch switchable
Connections:	Input: speaker via screw plug-in terminal
Crossover frequency:	2300 Hz
Speaker:	1 x woofer 8" Basket material: Steel Voice coil lows 2" 1 x Calottes highs 1" Voice coil calotte tweeter 1"
Type of speaker:	Compact cabinet speaker; On-ceiling/on-wall speaker
Color:	Black
Dimensions:	Width: 24,1 cm Depth: 28,5 cm Height: 45 cm
Weight:	10,60 kg