


AC Rotary Isolator Switches

Range: Rotary Isolator Switches

Part Number: DE1S.04.40AC

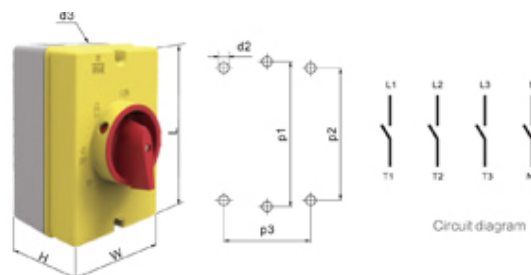

Model	Dimensions				Holes Dimensions			
	d3	W	H	L	p1	p2	p3	d2
20		98	80	145	134	115	81	4.2
25		98	80	145	134	115	81	4.2
32		98	80	145	134	115	81	4.2
40		98	80	145	134	115	81	4.2

DESCRIPTION

IP66 40A AC Isolator Switch

ROTARY ISOLATOR SWITCHES FEATURES

- IP66 Rated
- AC & DC Range Available
- Silver Plated Alloy Contacts for High Reliability
- Highly Visible & Robust Housing
- 4-Pole Earth terminal Included
- Polycarbonate UL94V-0 Flame Retardant
- Captive Retained Cover Screws
- Can be Padlocked (padlock not included)

Subject to technical modification without notice.

Typographical and other errors do not justify claim for damages.

SPECIFICATION

Rated insulation voltage (Ui) VAC	690
Rated Carry Current (A)	40
Rated operating current (A) AC-23A	30
Rated operating current (A) AC-3	22
Rated voltage	240/440
Rated power control (kW) AC-23A	7.5/15
Rated power control (kW) AC-3	5.5/11
UL-CSA	240/440
Motor Load (HP)	7.5/15
Rated current within (A)	360