


Solar Power Connectors

Range: Solar Power Connection

Part Number: CPV-KC4-1T1-I

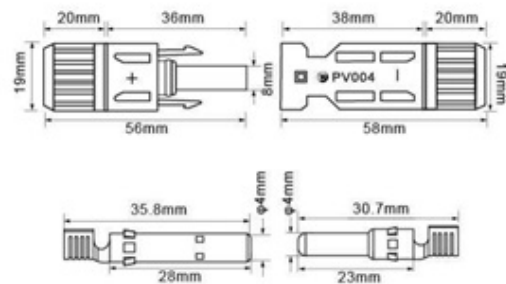

DESCRIPTION

Solar PV Connectors, Pair of Male & Female locking Connectors, MC4 compatible, Max current 30A, 1,000V

SOLAR POWER CONNECTION FEATURES

- High Currency/Voltage capacity
- Contact Material - 99.98% pure copper . minimises power loss
- Halogen free XPLO insulation, Virgin PVC sheathing, maximises protection from the elements
- Flame retardant to UV94 V-0
- Highly resitant to high/low temperatures, water, UV light, oxidation, rust, and corrosion
- 25 year life span

Subject to technical modification without notice.

Typographical and other errors do not justify claim for damages.

SPECIFICATION

Connection Method	MC4, Bayonet locking, cable to cable
Max Current (A)	30
Max Voltage (V)	1000
Colour	Black
IP Rating	IP68
Max Temperature Rating °C	85
Min Temperature Rating °C	-40
UL94 Rating	UL94 V-0
Cable Diameter (mm)	2.5, 4, 6
Contacts Material	Tin Plated copper
Cable Entries	2
Standards	IEC628582:2014

INDUSTRY ACCREDITATIONS

