


Product data sheet

Specifications

SQUARE D

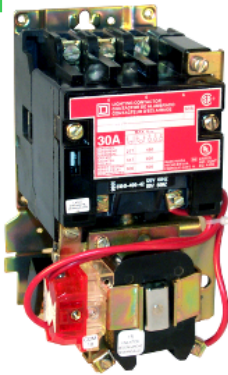

Contactor, Type S, multipole lighting, mechanically held, 60A, 4 pole, 110/120 VAC 50/60 Hz coil, open style

8903SPO12V02

Product availability : Non-Stock - Not normally stocked in distribution facility

Main

Product	Mechanically Held Lighting Contactor
Type	S

Complementary

Control Circuit Voltage	120 V AC 60 Hz 110 V AC 50 Hz
Current Rating	60 A
Number of Poles	4P
Control Units	No control units
Pilot Light	Without pilot light
Auxiliary Contacts	Without
Other Options	None
Electrical Connection	Lugs
Height	7.80 in (198 mm)
Depth	5.24 in (133 mm)
Width	5.91 in (150 mm)

Environment

Enclosure Type	Not rated (open device) surface none
Product Certifications	UL Listed CSA

Ordering and shipping details

Category	21324 - 8903 S (NOT S*C) MECH.
Discount Schedule	CP1
GTIN	785901023968
Returnability	No
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.80 in (19.8 cm)
Package 1 Width	5.91 in (15.0 cm)
Package 1 Length	5.24 in (13.3 cm)
Package 1 Weight	7.33 lb(US) (3.325 kg)

Offer Sustainability

California proposition 65	WARNING: Cancer and Reproductive Harm - www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
EU RoHS Directive	Not compliant
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information.

Contractual warranty

Warranty	18 months
----------	-----------

Recommended replacement(s)