



AB-PB-1059 Round, 2NO2NC, Red 12V, Momentary, 22mm, IP65 Push Button Switch

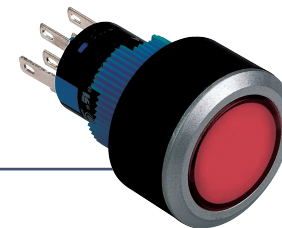


Specifications



Specifications	AB-PB-1059
Terminal type	Pin terminals (2.8x0.5mm)
Actuator shape	Round
Switching	2NO/2NC
Switching action	Momentary
Panel cut out	22mm
Illumination	LED 12V AC/DC
Colour	Red
IP degree	IP65
Switch rating	250V 5A
Mechanical life	≥1,000,000 cycles
Electrical life	≥50,000 cycles
Initial contact resistance	≤50MΩ
Insulation resistance	≥100MΩ
Operating temperature	-25°C~+55°C
Operating force	About 3N
Operating travel	About 3mm

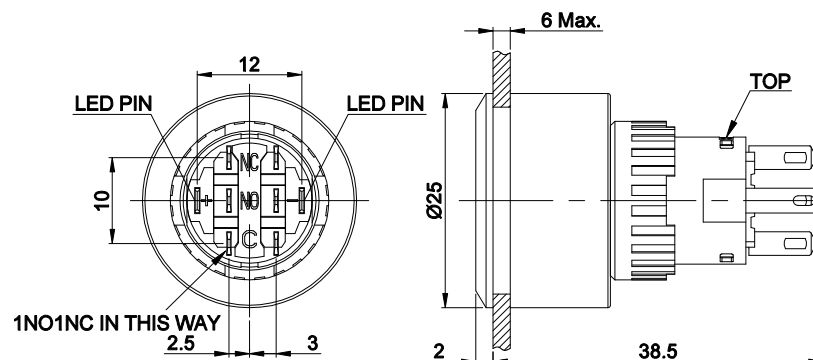

 
Please note: 1NO/1NC = 5 terminals only



SEAL RING(IP40 HAS NO GASKET)

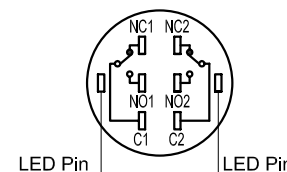
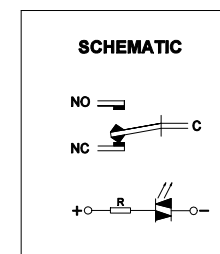


Contact Composition

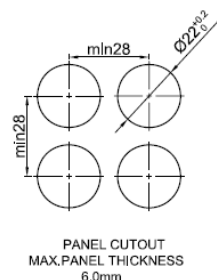

PANEL CUTOUT
MAX. PANEL THICKNESS
6.0mm

THE SHADED PART IS ILLUMINATED

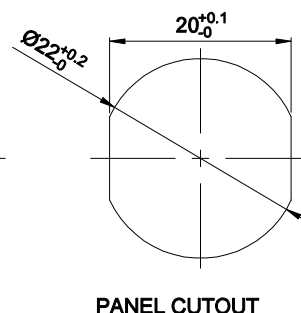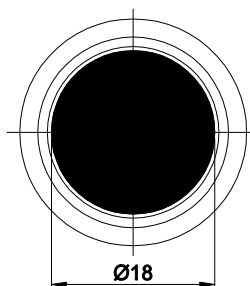

MATERIALS:

- 1.Button: PC.
- 2.Contact: Silver alloy.
- 3.Nut: PC.
- 4.Base: PBT.



Alan Butcher Components

Alan Butcher Components Ltd

Unit 1 Beechwood Clump Farm Industrial Estate Tin Pot Lane Blandford Dorset DT11 7TD

Telephone 01258 456360 Email sales@abcomponents.co.uk

www.abcomponents.co.uk