


Category 8 24 Port 0.5U STP Patch Panel

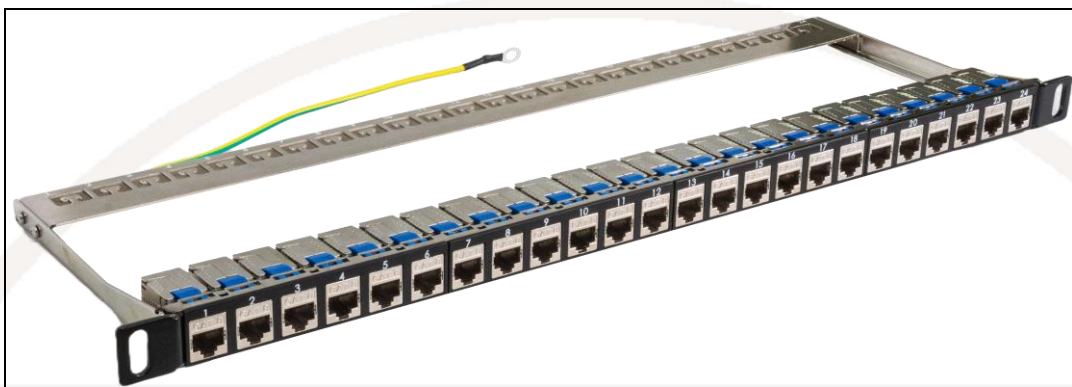

Category 8 24 Port 0.5U STP Patch Panel (SEF24tk0.5)

TUK's Category 8 0.5U STP patch panel offers tried and tested top level performance in a compact package.

Features

- Transmission performance in compliance with the ANSI/TIA 568-C.2-1 specifications for Category 8 cabling systems (i. e. suitable for runs of 5 – 30 metres) to Permanent Link standard
- Compliant with IEC60512-99-002 – suitable for use with IEEE 802.3bt (4PPoE+) applications at up to 100W
- 3rd Party (Delta/FORCE) verified
- Fully shielded die-cast keystone body is robust as well as offering outstanding performance in eliminating alien cross-talk
- Connectors provide quick and easy tool-less lever “butterfly style” termination
- Suitable for 0.51 – 0.65 mm/ 22 – 24 AWG stranded and solid wire
- Clear numbering on the front provides a quick, easy way to identify cable run
- Supplied with a removeable rear cable management bar, 2 sets of M6 black cage nuts and 270mm long earth wire (comes fitted)

Specifications

- Weight: 1280g approx.
- Dimensions: 505 x 162 x 30 (W x D x H) approx.
- Colour:
 - front: black + silver
 - rear: silver

- **Material:**
Panel: cold-rolled steel with ABS plastic facia
Rear of panel and cable management: nickel plated
Contacts: 50µ"/1.27µm gold plating over nickel over phosphor bronze
Keystone housing: Zinc alloy

Packaging: Supplied as a kit of 1 x FFK24mt0.5pt panel and 24 x SEKje keystones in an individual carton

EAN: 5055386511393

Commodity Code: 85177090

Country of Origin: China

For further information on components, please see links below:

SEKje <https://tuk.co.uk/product/category-8-shielded-keystone-socket/>

FFK24mt0.5pt <https://tuk.co.uk/product/0-5u-24-port-unpopulated-keystone-panel/>

ROHS Compliant

Code: SEF24tk0.5

