


Product data sheet

Specifications

SQUARE D

Green Premium™

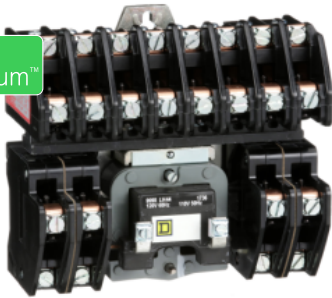

Contactor, Type L, multipole lighting, electrically held, 30A, 12 pole, 600 V, 110/120 VAC 50/60 Hz coil, open style

8903LO1200V02

Product availability : Stock - Normally stocked in distribution facility

Main

Product or Component Type	Electrically Held Lighting Contactor
Range of Product	8903L
Control Circuit	Separate control circuit

Complementary

Control Circuit Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Inrush power in VA	180 VA 60 Hz 170 VA 50 Hz
Hold-in power consumption in VA	35 VA 60 Hz 35 VA 50 Hz
Current Rating	20 A tungsten 30 A fluorescent
Number of Poles	12P 12 NO
Control Unit	No control units
Pilot Light	No indicator
Electrical Connection	Screw-clamp terminals
Height	5.00 in (127 mm)
Depth	3.11 in (79 mm)
Width	5.63 in (143 mm)

Environment

Enclosure Type	Not rated (open device)
Product Certifications	UL Listed CSA

Ordering and shipping details

Category	21321-8903 L (NOT LX)
Discount Schedule	CP1
GTIN	785901851813

Returnability	Yes
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	5.71 in (14.5 cm)
Package 1 Width	7.09 in (18.0 cm)
Package 1 Length	8.11 in (20.6 cm)
Package 1 Weight	4.45 lb(US) (2.02 kg)
Unit Type of Package 2	PAL
Number of Units in Package 2	126
Package 2 Height	40.00 in (101.6 cm)
Package 2 Width	40.00 in (101.6 cm)
Package 2 Length	48.00 in (121.92 cm)
Package 2 Weight	561.12 lb(US) (254.52 kg)

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
PVC free	Yes
Halogen content performance	Halogen free plastic parts product

Contractual warranty

Warranty	18 months
----------	-----------

Recommended replacement(s)