

PSI Displays Ltd




Unit 4, Butts Business Centre, Butts Road, Chiseldon, Swindon, Wiltshire, SN4 0PP. UK.

Tel: +44 (0) 1793 740456

e-mail: sales@psidisplays.co.uk Website www.psidisplays.co.uk

LCD COLOUR MONITOR Model No. L56RSDI

3 Monitors x 5.6" TFT LCD with Digital Colour LED Backlight, with SDI In/Out, VGA, Composite Video BNC and Audio. Audio out via speaker – 3U High. Metal Cased in 19" Rack Mounting.

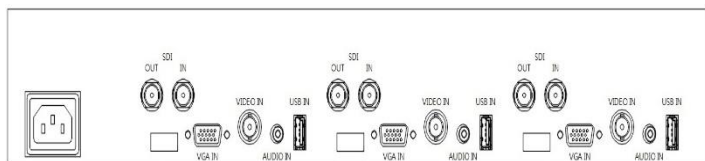

Main Features:

- Resolution: 640xRGBx480 pixels.
- Picture Ratio: 4:3
- Brightness: 200 cd/m2 LED Back Light.
- Contrast Ratio: 500:1
- Input: SDI, VGA, Composite Video BNC, Audio.
- Output: SDI, Audio via Speaker.
- Full OSD and Hot keys.
- Metal Cabinet finished in Black.
- Mounting: 19" Rack Mounting. 3U High.
- Single 240VAC Power connection.
- Rack Tilt 15/15°.
- True 10bit Colour processing engine.
- ICM (Independent Colour Management).
- DCC (Dynamic Contrast control).

The L56RSDI offers 3 Monitors of 5.6" TFT LCD in one rugged 19" rack mounting 3U high. With Digital panel, Active Matrix technology and LED Backlight it offers a superb sharp and high contrast images. Individual On/Off switch and Full OSD with Hot keys. SDI, VGA and Composite Video and Audio inputs. Outputs SDI and Audio out via Speaker. Single power connection 100-240volt operation. With universal application potential, the unit is ideal for surveillance systems, monitoring systems and multimedia video applications.

SPECIFICATIONS:

- Active area: 112.896 x 84.672 (WxH)mm. • 16.2M Colours. • PAL and NTSC Auto.
- Response Time: 10/15ms (Tr / Tf). • Viewing angle: Left/Right: 70°, Up: 50°. Down: 70°.
- SDI Standard: 3G-SDI (SMPTE 424M), HD-SDI (SMPTE 292M) SD-SDI (SMPTE 259M).
- SDI Video: 3G-1080P50/60 (4:2:2), HD-720P@50/60Hz & 1080i@50/60Hz, 1080P25/30Hz, SD-NTSC/60Hz, PAL/50Hz. • SDI Bandwidth: 2.97 Gbps, 2.975 / 1.001 Gbps.
- Controls: Full OSD via Menu, Up, Down, Power On/Off, On LED.
- Dot Pitch: 0.0588 x 0.1764 (WxH)mm. • Power Source: 100-240 VAC, 21Watts approx.
- Dimensions: 483 x 133.4 x 135.3. Weight: Unit: 4.3 Kgms, Carton: 5 Kgms. • Temp: 0°C~50°C.

Connections: SDI In/Out: BNC sockets. VGA: 15 pin D-sub. Composite Video: BNC socket. Audio: 3.5mm Jack socket. AC input: IEC socket. USB: Media playback and updates only.

Standard accessories: Single UK AC Mains Lead.

- All information correct at time of going to press. Design and specification are subject to change without prior notice. E&EO