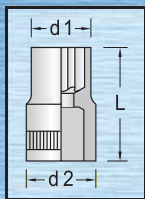


1/4" 





TX 20 Socket

for protruding TORX® head screws

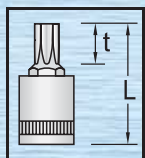
Socket, hand-operated, with square drive as per DIN 3120 - C 6.3, ISO 1174 with ball retaining groove, knurled grip. In GEDORE vanadium steel 31CrV3, mat. No. 1.2208, chrome-plated, polished.

® = reg. trademark of Camcar-TeXtron Inc. USA

Code	No.	 M	mm	L	d ₁	d ₂	
6193880	TX 20 E4	M 3	3,86	25	5,5	11	10
6187640	TX 20 E5	M 4	4,75	25	7,0	11	10
6187720	TX 20 E6	M 5	5,74	25	8,0	11	10
6187800	TX 20 E7	M 6	6,22	25	9,5	11	10
6187990	TX 20 E8	M 6 - M 7	7,52	25	10,5	12	15
6193960	TX 20 E10	M 8	9,42	25	13,0	13	15

3

1/4" 


 


ITX 20 Screwdriver bit socket

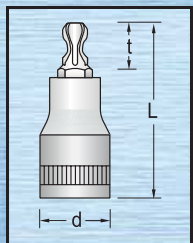
for recessed TORX® head screws

Screwdriver bit socket, hand-operated, with square drive as per DIN 3120 - C 6.3, ISO 1174 with ball retaining groove. Chrome-plated, knurled grip. Bit in GEDORE vanadium special steel, gun-metal finish.

® = reg. trademark of Camcar-TeXtron Inc. USA

Code	No.	 M	mm	L	t	
6190430	ITX 20 T8	M 2,5	2,31	30,5	14,5	10
6190510	ITX 20 T9	M 3	2,50	30,5	14,5	10
6190780	ITX 20 T10	M 3-3,5	2,74	30,5	14,5	10
6190860	ITX 20 T15	M 3,5 - M 4	3,27	30,5	14,5	10
6190940	ITX 20 T20	M 4 - M 5	3,86	30,5	14,5	10
6191080	ITX 20 T25	M 4,5 - M 5	4,43	30,5	14,5	10
6191160	ITX 20 T27	M 4,5 - M 6	4,99	30,5	14,5	10
6191240	ITX 20 T30	M 6 - M 7	5,52	30,5	14,5	15
6265890	ITX 20 T40	M 7 - M 8	6,65	33,5	14,0	20

1/4" 





ITX 20 K Screwdriver bit socket

with ball end for recessed TORX® head screws

Screwdriver bit socket, hand-operated. Swivel angle approx. 15°-20°, optimum transfer of power, also at places which are difficult of access. Square drive as per DIN 3120 - C 6.3, ISO 1174 with ball retaining groove. Chrome-plated, knurled grip. Bit in GEDORE vanadium special steel, gun-metal finish.

® = reg. trademark of Camcar-TeXtron Inc. USA

Code	No.	 M	mm	L	t	
6120220	ITX 20 K T10	M 3 - M 3,5	2,74	30,5	11	20
6120300	ITX 20 K T15	M 3,5 - M 4	3,27	30,5	11	20
6120490	ITX 20 K T20	M 4 - M 5	3,86	30,5	11	20
6120570	ITX 20 K T25	M 4,5 - M 5	4,43	30,5	11	20
6120650	ITX 20 K T27	M 4,5 - M 6	4,99	30,5	11	20
6120730	ITX 20 K T30	M 6 - M 7	5,52	30,5	11	20
6120810	ITX 20 K T40	M 7 - M 8	6,65	33,5	11	20

 
 

1/4" 



IS 20 Screwdriver bit socket

for slotted head screws

Screwdriver bit socket, hand-operated, with square drive as per DIN 3120 - C 6.3, ISO 1174 with ball retaining groove. Chrome-plated, knurled grip. Bit in GEDORE vanadium special steel, gun-metal finish. Bits as per DIN 5264, Form B.

Code	No.	mm 	mm 	L	
6171560	IS 20 4	0,8	4,0	28	20
6171640	IS 20 5,5	1,0	5,5	28	20
6174230	IS 20 6,5	1,2	6,5	28	20
6174310	IS 20 8	1,6	8,0	28	20

1/4" 



IKS 20 Screwdriver bit socket

for cruciform head screws PHILLIPS

Description as No. IS 20

Bits as per DIN ISO 8764-1 PH.

Code	No.	L	
6174580	IKS 20 1	28	20
6174660	IKS 20 2	28	20
6174740	IKS 20 3	28	20
6174820	IKS 20 4	28	20