
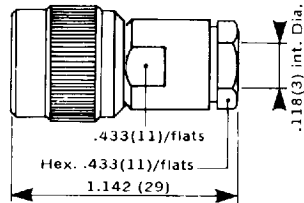


# TNC



## CABLE CLAMP TYPE FOR FLEXIBLE CABLE

### Straight plug

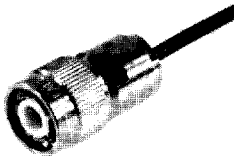



CABLE GROUP	.102 (2.6) / 50 + 75	
PART NUMBER	<b>R 143 004 000</b>	
Captive contact	YES	
Assembly instructions	M04 page 29	

### Straight plugs

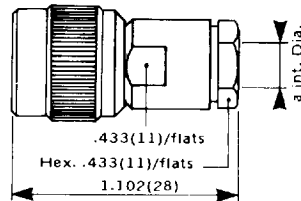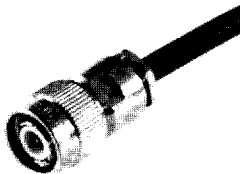

CABLE GROUP	.197 (5) / 50	.236 (6) / 75 + 93
PART NUMBER	<b>R 143 008 000</b>	<b>R 143 012 000</b>
a Dia. max.	.220 (5.6)	.260 (6.6)
Captive contact	NO	
Assembly instructions	M02 page 27	



### Straight plugs

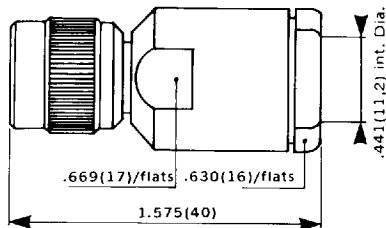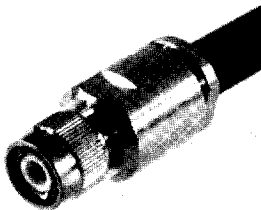

CABLE GROUP	.393 (10) + .433 (11) / 50	
PART NUMBER	<b>R 143 018 000</b>	<b>*R 143 018 500*</b>
Captive contact	YES	
Assembly instructions	M08 page 27	

\*2 Locwire holes.

### Right angle plug

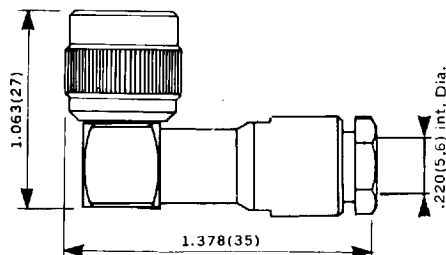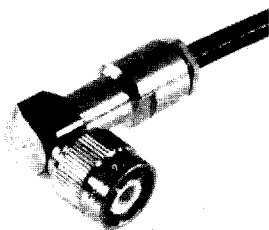

CABLE GROUP	.197 (5) / 50	
PART NUMBER	<b>R 143 156 000</b>	
Assembly instructions	M02 page 27	

• Manufactured upon request.