


TNC


CRIMP TYPE FOR FLEXIBLE CABLE

Straight plugs

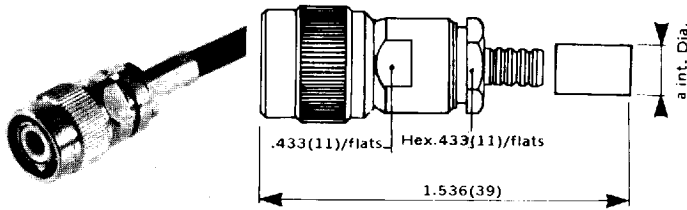


CABLE GROUP	.197 (5) / 50 S. scr.	.197 (5) / 50 D. scr.	.236 (6) / 75 + 93
PART NUMBER	R 143 072 000	R 143 073 000	R 143 074 000
a Dia. max.	.220 (5.6)		.260 (6.6)
Captive contact	YES		
Assembly instructions	M06 page 31		

Straight plugs

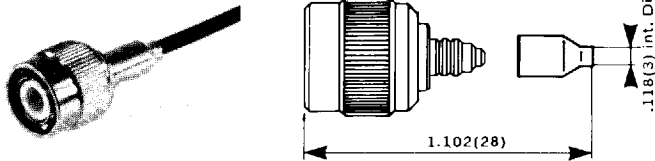


CABLE GROUP	.102 (2.6) / 50 + 75 S. scr.	.197 (5) / 50 S. scr.
PART NUMBER	R 143 075 000	R 143 082 000
a Dia. max.	.118 (3)	.220 (5.6)
Captive contact	YES	
Assembly instructions	M05 page 30	M03 page 28

Right angle plugs

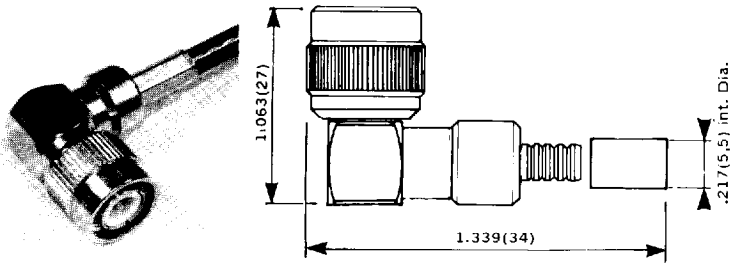

CABLE GROUP	.102 (2.6) / 50 + 75 S. scr.	.197 (5) / 50 S. scr.
PART NUMBER	R 143 181 000●	R 143 182 000
a Dia. max.	.118 (3)	.220 (5.6)
Captive contact	YES	
Assembly instructions	M05 page 30	M03 page 28

Bulkhead panel sealed straight jack

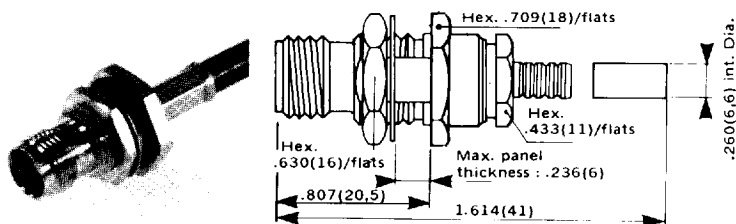

CABLE GROUP	.236 (6) / 75 + 93
PART NUMBER	R 143 328 000
Captive contact	YES
Assembly instructions	M06 page 31
Panel drilling	P11 + P12 page 18

● Manufactured upon request.