



## SKINDICHT® SHV-M-VITON® sealing cone Viton®

Compressed water proof cable gland for highest requirements with metric connection thread in accordance to EN 50262. The conical special seal of Viton® ensures an extended sealing. Thus an excellent compression strength and strain relief is achieved. The Viton® sealing cone is resistant against bio oils, solvents, chemicals at increased temperatures up to 200°C.

**EXAMPLE - for ordering**  
SHV-M-VITON® 20 / 11 / 7  
20 = connection thread metric  
11 = function thread PG  
7 = sealing cone width

### Design:

- 1 Fitting
- 2 Washer
- 3 Viton® sealing cone
- 4 Brass cone
- 5 Compression screw

### Note

Suitable accessories see SKINDICHT® SM-M page 10.50.




### Technical Data

Material:  
Body: Nickel plated brass;  
Sealing cone: FKM  
O-ring: FKM

Temperature range:  
-15°C up to +200°C

Protection class:  
IP 68 - 10 bar

Attention  
Installation dimensions  
see T21

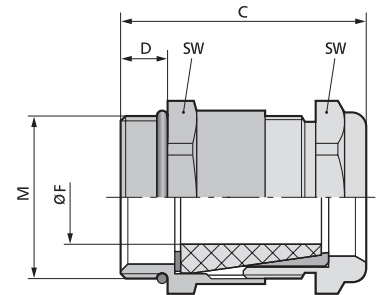

Part number	Connection thread M	Inner thread PG	Inner diam. sealing cone	Clamping range ØF mm	SW mm	C mm	D mm	PU pieces
<b>SKINDICHT® SHV-M-VITON®</b>								
5210 5430	12 x 1,5	7	5	3,8 - 4,8	14 / 14	26,0	5	50
5210 5440	16 x 1,5	9	6	4,8 - 5,8	18 / 17	27,5	5	50
5210 5450	16 x 1,5	9	7	5,8 - 6,8	18 / 17	27,5	5	50
5210 5460	20 x 1,5	11	7	5,8 - 6,8	22 / 20	31,0	6	25
5210 5470	20 x 1,5	11	9	6,8 - 8,8	22 / 20	31,0	6	25
5210 5480	20 x 1,5	13,5	11	8,5 - 10,8	22 / 22	32,5	6	25
5210 5490	20 x 1,5	13,5	9	6,8 - 8,8	22 / 22	32,5	6	25
5210 5500	20 x 1,5	16	13	10,8 - 12,8	24 / 24	34,5	6	25
5210 5510	20 x 1,5	16	15	13,8 - 14,8	24 / 24	34,5	6	25
5210 5520	25 x 1,5	21	18	15,8 - 17,8	30 / 30	38,0	7	25
5210 5530	25 x 1,5	21	20	17,5 - 19,8	30 / 30	38,0	7	25
5210 5540	32 x 1,5	29	22	19,5 - 21,8	40 / 40	44,5	8	10

Viton® is a registered trademark of DuPont de Nemour.