


Tungsten Halogen

Lamps for headlights & auxiliary lighting

Reference No Volt Watt Type Dim(mm)


H4

HB12	12v	60/55	H4	P45t
485	12v	100/80	H4	P45t
495	12v	130/90	H4	P45t
HB24	24v	75/70	H4	P45t
497	24v	100/80	H4	P45t

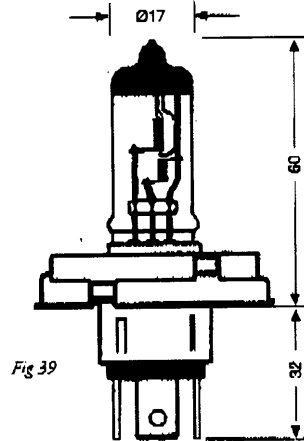


H7

499	12v	55w	H7	Px26d
498	24v	70w	H7	Px26d

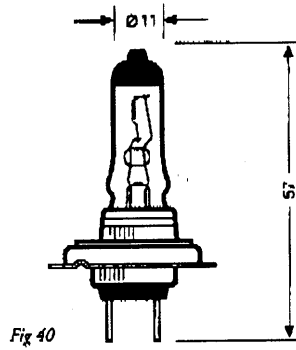

BA9

431	12v	5w	Halogen	BA9
432	12v	10w	Halogen	BA9
433	12v	20w	Halogen	BA9

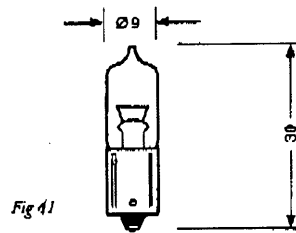

PCB HALOGEN

64124	12v	5w	PCB	9
--------------	-----	----	-----	---

