


0604 NYLON CABLE GLAND



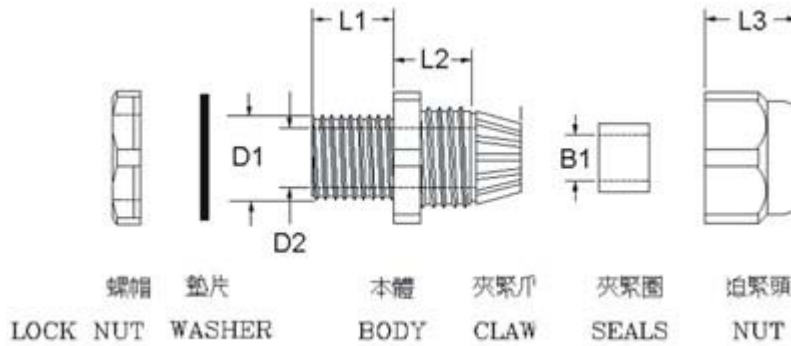



Material: UL approved NYLON 66, 94V-2(Black)



METRIC THREAD

Unit:mm


	Item No.	Mounting Hole D1	Pitch (mm)	D2	B1	L1	L2	L3	Cable Range	Packing
	<input type="checkbox"/> AG-12	12	1.25	8.3	6.0	7.9	12.1	13.3	3~6.5	50pcs
	<input type="checkbox"/> AG-12L	12	1.5	8.3	6.0	7.9	12.1	13.3	3~6.5	
	<input type="checkbox"/> AG-16	16	1.5	10.9	9.6	15.7	14.4	16.7	5~10	
	<input type="checkbox"/> AG-20	20	1.5	14.8	12.9	15.0	19.5	18.4	10~14	
	<input type="checkbox"/> AG-25	25	1.5	18.6	16.4	15.0	18.7	22.3	13~18	

	<input type="checkbox"/> AG-32	32	1.5	26.0	23.4	14.7	20.3	26.2	18~25	25pcs
	<input type="checkbox"/> AG-40	40	1.5	33.0	30.6	17.7	23.4	31.6	22~32	10pcs
	<input type="checkbox"/> AG-50	50	1.5	41.2	38.2	17.3	25.7	31.6	30~38	
	<input type="checkbox"/> AG-63	61	1.5	54.1	44.0	18.5	27.0	32.6	34~44	
	<input type="checkbox"/> AG-63M	63	1.5	54.1	44.0	18.5	27.0	32.6	34~44	
	<input type="checkbox"/> AG-63L	63	1.5	56.0	49.5	25.4	29.5	36.5	42~50	

Unit:mm

Item No.	Mounting Hole D1	Pitch (mm)	D2	B1	L1	L2	L3	Cable Range	Packing
<input type="checkbox"/> AG-16F	20.8	PF1/2"	11	13	9.5	14.0	18.7	5~10	50pcs
<input type="checkbox"/> AG-20F	20.8	PF1/2"	14.7	14.7	9.5	16.0	18.5	6~13	

JIS THREAD

	<input type="checkbox"/> AGJ-14	14	1.5	8.04	6.33	8.07	12.15	13.3	3~6.5	50pcs
	<input type="checkbox"/> AGJ-17	17	1.5	10.76	10.25	14.63	14.53	16.7	5~10	
	<input type="checkbox"/> AGJ-21	21	1.5	14.98	13.50	12.87	19.60	18.4	10~14	
	<input type="checkbox"/> AGJ-27	27	1.5	18.37	18.65	14.66	18.45	22.3	13~18	
	<input type="checkbox"/> AGJ-34	34	1.5	25.84	25.31	14.84	20.75	26.1	18~25	25pcs