

EK024 – Polystyrene – 361x254mm (14.21x10.00in.)

Standard Features

- **Protection Level:** IP54* / IP65**
- **Technical:** Knockout Sidewalls
Tinted Transparent Door
Multiple Enclosure Combination Option
- **Enclosure Material:** Polystyrene
- **Door Material:** Polycarbonate
- **Gasket Material:** Polyurethane
- **Temperature Range:** -40°C to 70°C (-40°F to 158°F)
- **Color:** Light Gray
- **Included Accessories:** 2 ea. 35mm DIN Rail, 17 Pole Ground/Neutral Terminal Strip
24 ea. 9mm (0.35 in.) Filler Strips
1 ea. Pg21 & Pg29 Entry Spouts
14 ea. Pg16 Entry Spouts
2 ea. Label Strips
- **Accessories:** See section below



* With Supplied Entry Spouts

** As Equipped or with Optional IP65 Cable Glands



EK

Ordering Information	Cat. No.	Type	Length	Dimensions mm (in) Width	Height	Std. Pk.
Enclosure	542-424	EK024	361 mm (14.21 in)	254 mm (10.00 in)	110 mm (4.33 in)	1


Accessories

Ordering Information	Cat. No.	Type	Std. Pk.
Key Lock	548-102	KL	1
Terminal	X-721-02	PE/N Terminal - 17 pole	1

Please refer to pages 106-113 for additional accessories and detailed information.

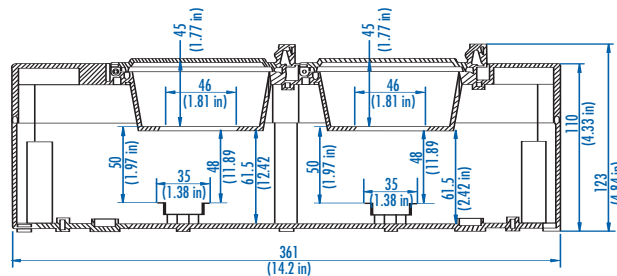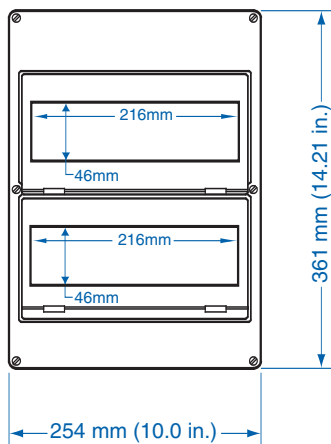

Knockout Detail

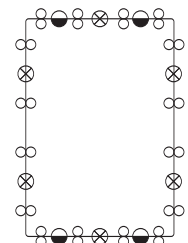

Pg11



Pg13.5



Pg16



Pg21/16



Pg29/21



Pg36/29