



Trust Gaming GXT 925 Redex II Lightweight Gaming Mouse - Black

Lightweight gaming mouse with fully adjustable RGB lighting

Article number: 25125

Barcode: 8713439251258

GTIN: 08713439251258

Core content

Brand	Trust Gaming
Product type	Lightweight Gaming Mouse
Colour	Black
Key features	- Lightweight design of only 82g allows for swift and easy movement - Made with 55% recycled plastics for greener gaming - 10.000 DPI sensor to play with the utmost precision and accuracy - Durable Kailh switches tested up to 80M clicks so you can game on and on - Full 3-zone RGB illumination with 16.8 million colour combinations allows you to play in style - 6 programmable buttons including 2 side buttons & a DPI select button grant you total control - Included software enables you to program the buttons and lighting to match your gaming style - 1.8m braided cable for hassle-free connection to your PC
Package contents	- Gaming mouse
System requirements	- USB port - Windows 10 or 11

Marketing

Extended retailer text	Light weight, heavy duty Clunky mice are out, featherlight ones are in. Weighing only 82g, the Redex II ensures that you have no weight dragging you down whilst you play, keeping you feeling comfortable and making sure you're always ready for another match. Victory meets sustainability
------------------------	---

A win for you, a win for the planet. With a sustainable design made with 55% recycled plastics, this mouse lets you make a more conscious choice when it comes to your gaming gear.

All about accuracy

Make your moves with the Redex II's adjustable and highly accurate optical sensor. Going all the way up to 10.000 DPI, this mouse prepares you for intense matches, fast reactions, and non-stop wins.

Long-term partner

Don't worry about this mouse breaking down on you – with durable Kailh switches that last up to 80 million clicks, this mouse is here to play AND stay.

Light up your life

Feel like a star and shine like one to thanks to the Redex II's full 3-zone RGB. With lighting on the sides, scroll wheel and logo, enjoy up to 16.8 million different colours (we didn't even know there were that many colours!) for some ultra-groovy gaming.

Specifications

Plastic material	rABS
Sustainability method	PCR
Total weight	110 g
Weight of main unit	82 g
Height of main product (in mm)	125 mm
Width of main product (in mm)	63 mm
Depth of main product (in mm)	41 mm
Ergonomic design	No
Gliding pads	teflon
Software	Yes
Special features	Physical polling rate slider on bottom

Silent click	Yes
Formfactor	standard
Sensor technology	optical
DPI	10000
DPI range	200 - 10.000 dpi
Max. DPI	10.000 dpi
DPI adjustable	Yes
Adjustable weights	No
Controls	backward dpi loop left LED light color mode right forward
DPI button	Yes
Grip type	palm finger claw
Horizontal scrolling	No
Number of buttons	6
Programmable buttons	Yes
Scroll wheel	Yes
Suitable surface	carpet/laminate/parket/resin floors/floor tiles
Left-right handed use	right-handed
Cable length main cable	180 cm
Connection type	wired

Connector type	USB
USB version	2.0
Designed for gaming	Yes
LED colours adjustable	yes
Lights	Yes
LED colours	Full RGB
Power source	USB
Compatible Device Types	pc laptop gaming console
Compatible Software Platforms	Windows

Main image

	25125_pictures_product_visual_1.tif ImageWidth: 5.000 px ImageHeight: 5.000 px ImageResolution: 300 dpi
--	---

Additional Product Images

	25125_pictures_product_visual_2.tif ImageWidth: 5.000 px ImageHeight: 5.000 px ImageResolution: 300 dpi
--	---



25125_pictures_product_top_1.tif

ImageWidth: 5.000 px

ImageHeight: 5.000 px

ImageResolution: 300 dpi



25125_pictures_product_side_1.tif

ImageWidth: 5.000 px

ImageHeight: 5.000 px

ImageResolution: 300 dpi



25125_pictures_product_side_2.tif

ImageWidth: 5.000 px

ImageHeight: 5.000 px

ImageResolution: 300 dpi



25125_pictures_product_bottom_1.tif

ImageWidth: 5.000 px

ImageHeight: 5.000 px

ImageResolution: 300 dpi

Product Pictorials




25125_EN_pictures_product_pictorial_1.tif

ImageWidth: 4.000 px

ImageHeight: 4.000 px

ImageResolution: 300 dpi

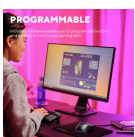

25125_EN_pictures_product_pictorial_6.tif

ImageWidth: 4.000 px

ImageHeight: 4.000 px

ImageResolution: 300 dpi



25125_EN_pictures_product_pictorial_4.tif

ImageWidth: 4.000 px

ImageHeight: 4.000 px

ImageResolution: 300 dpi



25125_EN_pictures_product_pictorial_5.tif

ImageWidth: 4.000 px

ImageHeight: 4.000 px

ImageResolution: 300 dpi



25125_EN_pictures_product_pictorial_2.tif

ImageWidth: 4.000 px

ImageHeight: 4.000 px

ImageResolution: 300 dpi




25125_EN_pictures_product_pictorial_3.tif

ImageWidth: 4.000 px

ImageHeight: 4.000 px

ImageResolution: 300 dpi

Lifestyle Images

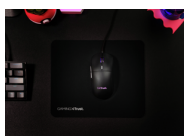

25125_pictures_lifestyle_visual_5.jpg

ImageWidth: 3.000 px

ImageHeight: 2.185 px

ImageResolution: 300 dpi



25125_pictures_lifestyle_visual_6.jpg

ImageWidth: 3.000 px

ImageHeight: 2.250 px

ImageResolution: 300 dpi



25125_pictures_lifestyle_visual_4.jpg

ImageWidth: 3.000 px

ImageHeight: 2.250 px

ImageResolution: 300 dpi



25125_pictures_lifestyle_visual_3.jpg

ImageWidth: 3.000 px

ImageHeight: 2.250 px

ImageResolution: 300 dpi



25125_pictures_lifestyle_visual_2.jpg

ImageWidth: 3.000 px

ImageHeight: 2.250 px

ImageResolution: 300 dpi



25125_pictures_lifestyle_visual_1.jpg

ImageWidth: 3.000 px

ImageHeight: 2.250 px

ImageResolution: 300 dpi

Package Images



25125_pictures_package_visual_1.tif

ImageWidth: 5.000 px

ImageHeight: 5.000 px

ImageResolution: 300 dpi



25125_pictures_package_front_1.tif

ImageWidth: 1.648 px

ImageHeight: 2.421 px

ImageResolution: 300 dpi