


YourHome Spot IP65
SYLSPOT 500LM 830 IP65 WHT 3-PACK
0090022



Product features

- Integrated LED recessed spotlight, fixed, RAL9016 colour, 540lm, 6.5W, non-dimmable, 3000K, 38° degree beam angle, polycarbonate white body, low profile 47mm recessed depth, IP65 from the front, IK03, loop-in/loop-out terminals for fast wiring, 86mm bezel diameter, 68-74mm cutout, frosted lens. Additional silver bezel included in the packaging. Pack of 3 pieces.

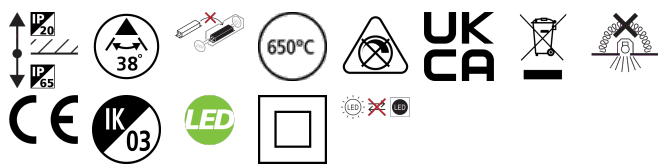

PRODUCT OVERVIEW

Product name	SYLSPOT 500LM 830 IP65 WHT 3-PACK
Technology	LED
Cap/Base	N/A
Housing	PC Polycarbonate
Mount	Ceiling recessed mounting
Environment	Indoor
General application	Residential & Consumer
ETIM Class	EC001744
Warranty	3 years
Useful luminous flux (Fuse)	500
Fixture luminous flux (lm)	500
Luminous flux (lm)	500
Luminaire efficacy (lm/W)	104
Colour temperature (K)	3000
Light colour	Warm White
CRI (Ra)	80
Colour Variation Initial (SDCM)	SDCM6
Beam Angle (°)	38
Photobiological Risk Group	RG1
Total power consumption (W)	4.8
Electrical protection	Class II
Control gear type	LED driver constant current
Dimmable	No
Dimming method	N/A
LED Flickering Rate	Low (6% - 20%)
Housing colour	RAL 9003 - Signal white
IP rating	IP65/20
IK rating	IK03
Product EAN number	5410288900223

DATA TABLE

YourHome Spot IP65

SYLSPOT 500LM 830 IP65 WHT 3-PACK

0090022

General data

Product name	SYLSPOT 500LM 830 IP65 WHT 3-PACK
Technology	LED
Cap/Base	N/A
Housing	PC Polycarbonate
Mount	Ceiling recessed mounting
Environment	Indoor
General application	Residential & Consumer
Operating temperature range (°C)	-10°C...+40°C
Performance ambient temperature T _q (°C)	25
ETIM Class	EC001744
Warranty	3 years

Optical data

Useful luminous flux (Fuse)	500
Fixture luminous flux (lm)	500
Luminous flux (lm)	500
Luminaire efficacy (lm/W)	104
Colour temperature (K)	3000
Light colour	Warm White
CRI (Ra)	80
Colour Variation Initial (SDCM)	SDCM6
Beam Angle (°)	38
Distribution type	Symmetric
Photobiological Risk Group	RG1

Electrical data

Total power consumption (W)	4.8
Primary Supply/Product voltage - min (V)	220
Primary Supply/Product voltage - max (V)	240
Lamp power factor	0.5
THD (at 230 V, 50 Hz, full load, at 100% dimming level) xx.x %	155
Electrical protection	Class II
Control gear type	LED driver constant current
Dimmable	No
Dimming method	N/A
Drive current (mA)	15
Inrush Current (A)	11.8
Inrush Duration (µs)	220
Glow Wire Test (°C)	650
Energy Efficiency Class (A->G) of contained light source	F
Nominal Frequency (Hz)	50/60Hz
LED Flickering Rate	Low (6% - 20%)
Max. products per 10A C Breaker	68
Max. products per 13A C Breaker	89
Max. products per 16A C Breaker	112

YourHome Spot IP65

SYLSPOT 500LM 830 IP65 WHT 3-PACK

0090022

Max. products per 20A C Breaker	137
Max. products per 10A B Breaker	41
Max. products per 16A B Breaker	66
Connectable conductor cross section - Min (mm²)	0.75
Connectable conductor cross section - Max (mm²)	1.5

Lifetime data

Lifespan L70 B50	57000
Lifespan L70 B20	54000
Lifespan L70 B10	53000
Lifespan L80 B50	36000
Lifespan L80 B20	34000
Lifespan L80 B10	33000
Lifespan L90 B50	17000
Lifespan L90 B20	16000
Lifespan L90 B10	16000

Physical data

Housing colour	RAL 9003 - Signal white
IP rating	IP65/20
IK rating	IK03
Diffuser finish	Other
Diffuser material	None
Reflector finish	None
Nominal Product Height (mm)	47
Nominal Product Diameter (mm)	87
Cutout Dimensions (W x L in mm or Diameter in mm)	68-74
Weight (kg)	0.218

Packaging


Product EAN number	5410288900223
Packaging single length / height (cm)	29.1
Packaging single width (cm)	10.0
Packaging single depth (cm)	5.8
DUN14 (outer)	15410288900220
Units per outer package	16
Packaging outer length / height (cm)	41.9
Packaging outer width (cm)	31.6
Packaging outer depth (cm)	27.2

Safety data

Optimal operating condition (°C)	-10-40
----------------------------------	--------

PHOTOMETRY

YourHome Spot IP65
SYLSPOT 500LM 830 IP65 WHT 3-PACK
0090022

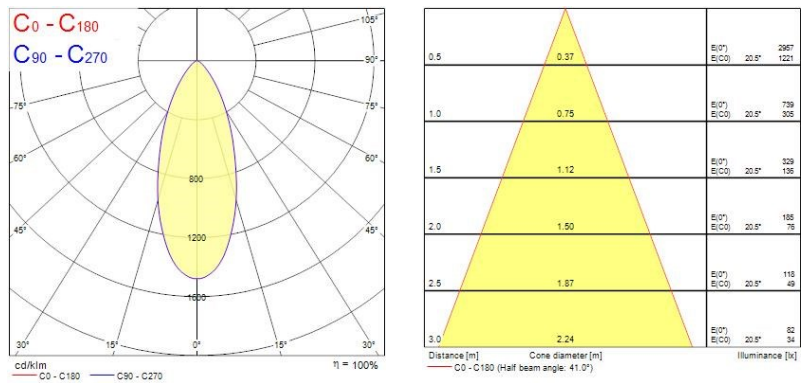

TECHNICAL DRAWINGS

