


SylSpot White
SYLSPOT KIT ROUND 345LM 830 ADJ IP20 BLK 3-PACK
0005740



Product features

- Recessed spotlight Kit with RefLED GU10 LED spotlight lamp Ø50mm. Polycarbonate body, round bezel ring in black color finish, vertical tilt 25°, IP20 degree of protection, class II. Lumen output 345lm, CCT 3000K, beam angle 36°, power 4,5W, efficacy 77 lm/W, lifetime 15.000h. Outer dimensions: Ø80x90mm, cut-out Ø68-76mm. Suitable for internal environment only and for LED lamps only. Pack of 3 pieces.

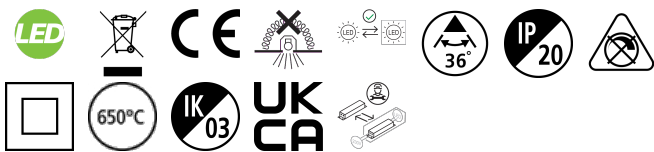

PRODUCT OVERVIEW

Product name	SYLSPOT KIT ROUND 345LM 830 ADJ IP20 BLK 3-PACK
Technology	LED
Cap/Base	N/A
Housing	PC Polycarbonate
Mount	Ceiling recessed mounting
Environment	Indoor
General application	Residential & Consumer
ETIM Class	EC001744
Warranty	3 years
Useful luminous flux (Fuse)	345
Fixture luminous flux (lm)	345
Luminaire efficacy (lm/W)	77
Colour temperature (K)	3000
Colour Code	830
Light colour	Warm White
CRI (Ra)	80
Colour Variation Initial (SDCM)	SDCM6
Beam Angle (°)	36
Photobiological Risk Group	RG1
Total power consumption (W)	4.5
Electrical protection	Class II
Control gear type	LED driver constant current
Dimmable	No
Dimming method	N/A
Housing colour	Black
IP rating	IP20
IK rating	IK03
Product EAN number	5410288057408

DATA TABLE

General data	
Product name	SYLSPOT KIT ROUND 345LM 830 ADJ IP20 BLK 3-PACK

SylSpot White

SYLSPOT KIT ROUND 345LM 830 ADJ IP20 BLK 3-PACK

0005740

Technology	LED
Cap/Base	N/A
Housing	PC Polycarbonate
Mount	Ceiling recessed mounting
Environment	Indoor
General application	Residential & Consumer
Operating temperature range (°C)	-10°C...+40°C
ETIM Class	EC001744
Warranty	3 years

Optical data

Useful luminous flux (Fuse)	345
Fixture luminous flux (lm)	345
Luminaire efficacy (lm/W)	77
Colour temperature (K)	3000
Colour Code	830
Light colour	Warm White
CRI (Ra)	80
Colour Variation Initial (SDCM)	SDCM6
Beam Angle (°)	36
Distribution type	Symmetric
Photobiological Risk Group	RG1

Electrical data

Total power consumption (W)	4.5
Primary Supply/Product voltage - min (V)	220
Primary Supply/Product voltage - max (V)	240
Lamp power factor	0.9
THD (at 230 V, 50 Hz, full load, at 100% dimming level) xx.x %	155
Electrical protection	Class II
Control gear type	LED driver constant current
Dimmable	No
Dimming method	N/A
Inrush Current (A)	10
Inrush Duration (µs)	150
Glow Wire Test (°C)	650
Energy Efficiency Class (A->G) of contained light source	F
Nominal Frequency (Hz)	50/60Hz
Max. products per 10A C Breaker	100
Max. products per 13A C Breaker	130
Max. products per 16A C Breaker	160
Max. products per 20A C Breaker	200
Max. products per 16A B Breaker	160
Connectable conductor cross section - Min (mm²)	0.75
Connectable conductor cross section - Max (mm²)	1

SylSpot White
SYLSPOT KIT ROUND 345LM 830 ADJ IP20 BLK 3-PACK
0005740

Lifetime data

Lifespan L70 B50	15000
------------------	-------

Physical data

Housing colour	Black
IP rating	IP20
IK rating	IK03
Diffuser finish	Other
Diffuser material	None
Reflector finish	None
Nominal Product Height (mm)	85
Nominal Product Diameter (mm)	90
Cutout Dimensions (W x L in mm or Diameter in mm)	70-75
Weight (kg)	0.27


Packaging

Product EAN number	5410288057408
Packaging single length / height (cm)	9.0
Packaging single width (cm)	7.5
Packaging single depth (cm)	30.0
DUN14 (outer)	15410288057405
Units per outer package	16
Packaging outer length / height (cm)	38.0
Packaging outer width (cm)	30.0
Packaging outer depth (cm)	37.5

Safety data

Optimal operating condition (°C)	-10-40
----------------------------------	--------

PHOTOMETRY

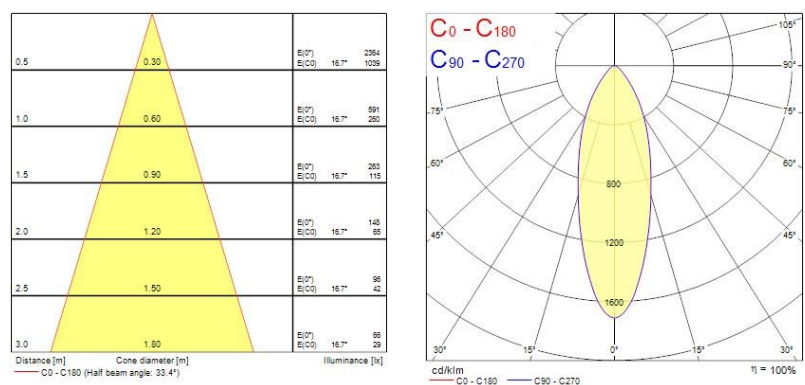

TECHNICAL DRAWINGS

SylSpot White

SYLSPOT KIT ROUND 345LM 830 ADJ IP20 BLK 3-PACK

0005740

