

ToLEDo Retro Ball
ToLEDo RT Ball CL 470LM 827 E14 SL4
0029553



Product features

- Perfect for decorative and general lighting applications and creates a warm ambience similar to traditional lampsThe versatile ToLEDo Retro ball range is the ideal replacement for halogen and incandescent lamps and perfect for chandeliers and decorative applicationsSame look, size and functionality as incandescent lampsOmni-directional light distributionGives same sparkling light effect as the incandescent lampDimensionally identical to incandescent lamps - fits all fixturesEnvironment-friendly - no mercury and lower CO2 emissions



PRODUCT OVERVIEW

Product name	ToLEDo RT Ball CL 470LM 827 E14 SL4
Technology	LED
Watt (Rated) (W)	4.5
Cap/Base	E14
Fixture rating	Open
General application	Residential & Consumer
ETIM Class	EC001959
Warranty	2 years
Useful luminous flux (Fuse)	470
Luminous flux (lm)	470
Colour temperature (K)	2700
Light colour	Homelight
CRI (Ra)	80
Colour Variation Initial (SDCM)	SDCM6
Photobiological Risk Group	RG1
Power consumption (W)	4.5
Wattage (W)	4.5
Dimmable	No
Average life (Nominal) (h)	15000
Product EAN number	5410288295534

DATA TABLE

General data	
Product name	ToLEDo RT Ball CL 470LM 827 E14 SL4
Technology	LED

ToLEDo Retro Ball

ToLEDo RT Ball CL 470LM 827 E14 SL4

0029553

Watt (Rated) (W)	4.5
Cap/Base	E14
Fixture rating	Open
General application	Residential & Consumer
Operating temperature range (°C)	-20°C...+40°C
Performance ambient temperature Tq (°C)	25
ETIM Class	EC001959
Warranty	2 years

Optical data

Useful luminous flux (Fuse)	470
Luminous flux (lm)	470
Luminous flux (Rated) (lm)	470
Colour temperature (K)	2700
Light colour	Homelight
CRI (Ra)	80
Colour Variation Initial (SDCM)	SDCM6
Photobiological Risk Group	RG1
Lumen maintenance at end of nominal life (%)	70

Electrical data

Power consumption (W)	4.5
Wattage (W)	4.5
Equivalent watt (W)	40
Primary Supply/Product voltage - min (V)	220
Primary Supply/Product voltage - max (V)	240
Control gear required	No
No. Of switching cycles before premature failures	>50000
Dimmable	No
Inrush Current (A)	6.3
Inrush Duration (µs)	240
Lamp Energy Label (class)	F
Nominal Frequency (Hz)	50/60Hz
Max. products per 16A C Breaker	25
Max. products per 16A B Breaker	13

Lifetime data

Lifespan L70 B50	12000
Average life (Nominal) (h)	15000
Average life (Rated) (h)	15000

Physical data

Nominal Product Length (mm)	80
Nominal Product Diameter (mm)	45
Weight (kg)	0.18

ToLEDo Retro Ball
ToLEDo RT Ball CL 470LM 827 E14 SL4
0029553


Packaging

Product EAN number	5410288295534
Packaging single length / height (cm)	11.0
Packaging single width (cm)	15.7
Packaging single depth (cm)	3.9
DUN14 (outer)	15410288295531
Units per outer package	6
Packaging outer length / height (cm)	10.5
Packaging outer width (cm)	31.1
Packaging outer depth (cm)	20.2


Safety data

Optimal operating condition (°C)	-20-40
Breakage cleaning instructions	Not applicable
Special purpose lamp	No
Dry applications use only	Yes
Suitable for household illumination	Yes
Safety message	Not Suitable for totally enclosed fixtures

PHOTOMETRY

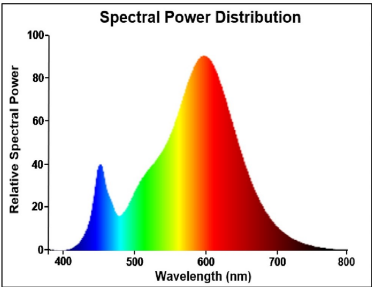

TECHNICAL DRAWINGS

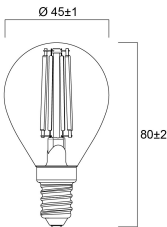



ToLEDo Retro Ball
ToLEDo RT Ball CL 470LM 827 E14 SL4
0029553

**ENERG**

SYLVANIA

0029553




5
kWh/1000h



2019/2015

ToLEDo Retro Ball
ToLEDo RT Ball CL 470LM 827 E14 SL4
0029553


SYLVANIA
0029553

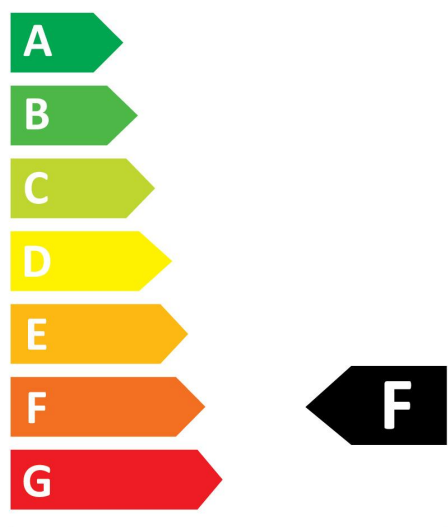

5
kWh/1000h



2019/2015