



FICHE TECHNIQUE - TECHNICAL SPECIFICATIONS

4R20 - 4R25


PRS9005




CARACTERISTIQUES ELECTRIQUES ELECTRICAL CHARACTERISTICS

IEC	4R25X
Couple chimique / Chemical system	Primary Zinc Chloride
Tension nominale / Nominal Voltage	6V
Capacité nominale / Nominal Capacity	6600mAh (15Ω, 24h/d, 20°C, e.v. : 3.6V)
Température de fonctionnement / Operating temperature	-30°C ~50°C
Teneur en métaux lourds/Heavy metal contents	0% Hg
Details	Boitier Plastique / Plastic casing Ressorts / Springs
Poids / Weight	540 gr

Dimensions (mm)

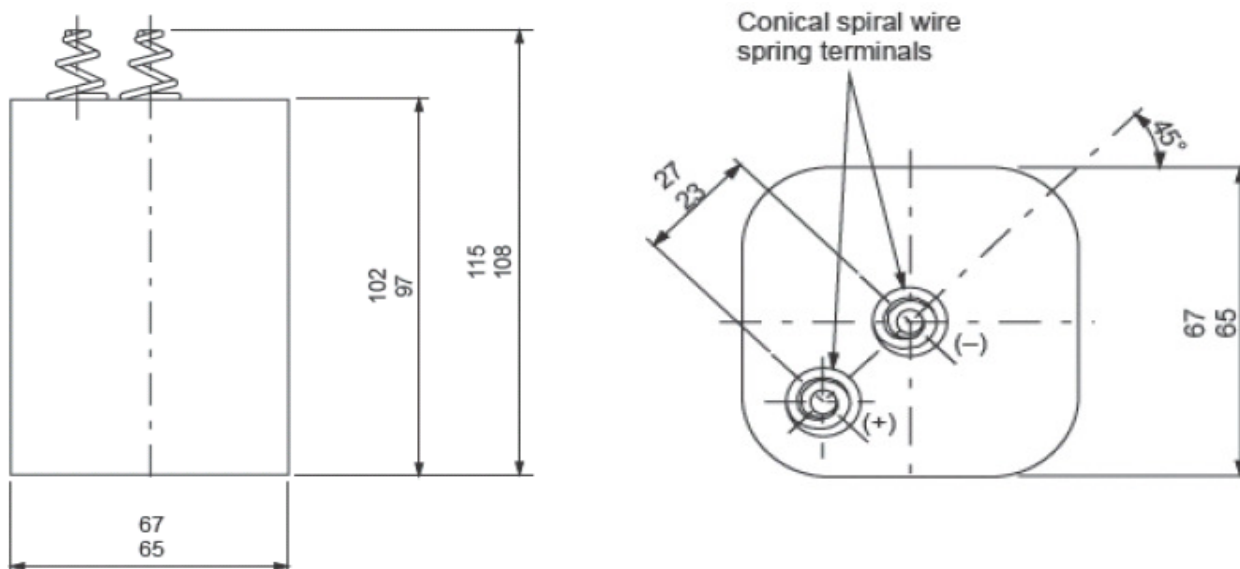

Discharge at 10 ohms

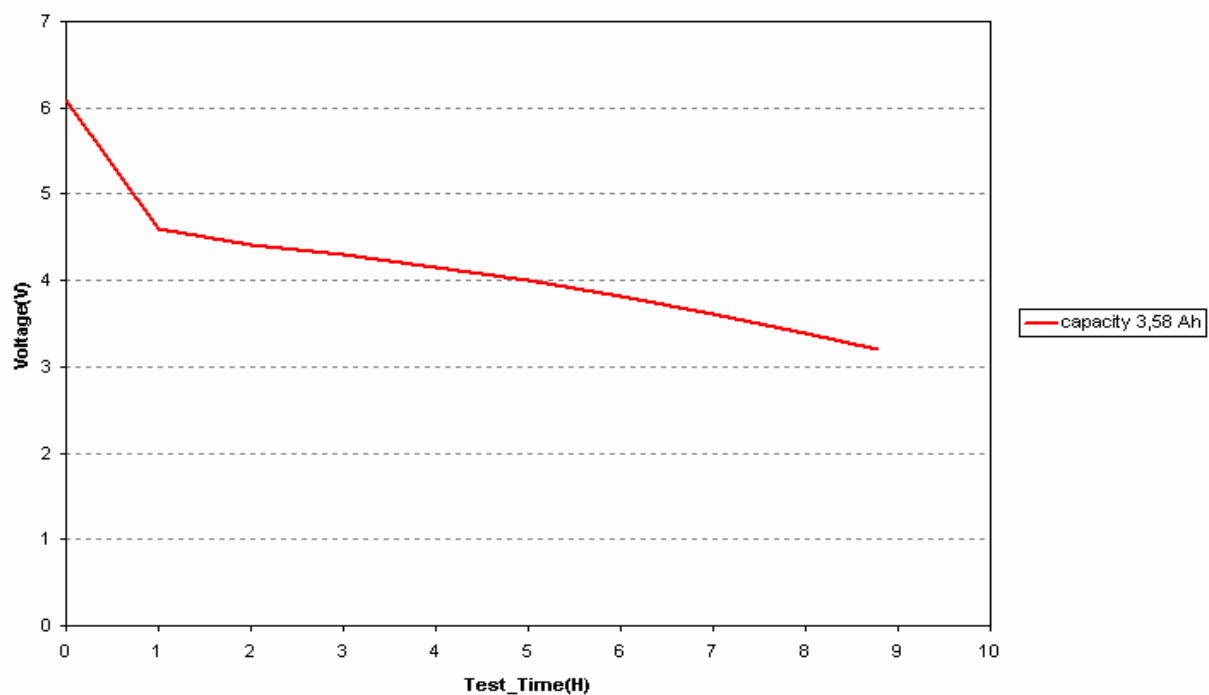

Discharge at 22 ohms

