

Input Cable for Intelligent LED Pixels

ILPA-INPUT-CAB-3WAY-90MM


Product Overview

Mating half connector for our ILP products to enable easy connection
Works with all our; ILPX, ILPY, ILPR and ILPS product families.

Ratings etc:

Maximum current	8A
Temperature range	-25° to +85° C
Insulation resistance	1,000 m Ohms min
Withstanding voltage	800V AC/minute
RoHS compliant	Yes


*This datasheet should be read in conjunction with the relevant JST data on the connector used

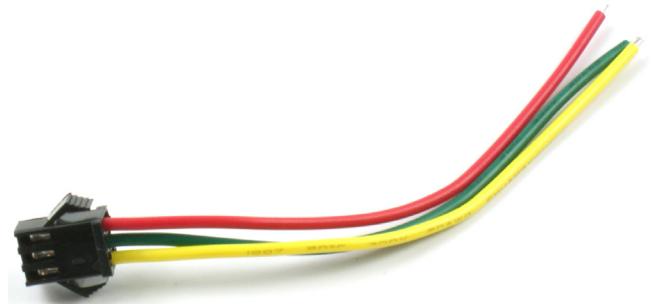

Pin Out



Mechanical Drawing

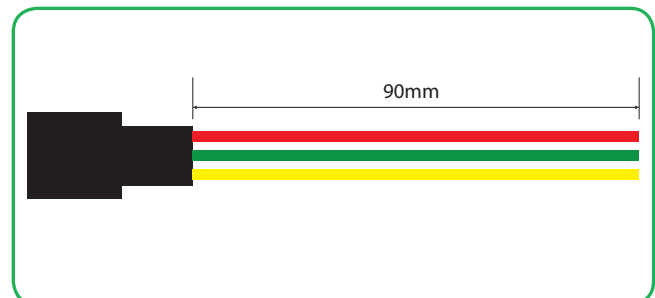

Important Information and Precautions

- Do not exceed the maximum current and voltage
- Minimum bend radius for cables is 5mm
- Do not pull on cables or use them for physical support

For further information please contact ILS

The values contained in this data sheet can change due to technical innovations. Any such changes will be made without separate notification.