



USER INSTRUCTIONS & FAQs



***SRCAMV6.5MAX Super Cam Max
20 M Wireless Inspection Camera with on-board memory***

THE SMARTER WAY TO INSPECT

Contents	3
Start-up guide	4
Super Cam Max features	5
Super Cam Max App	6
- Buttons Configuration	6
- Manual/Auto Focus	6
- Brightness	6
- Pinch Zoom	6
- Saving Pictures/Videos	7
- Settings	8
- Icon Options	9
Charging the Super Cam Max	10
Connecting the Super Cam Max to multiple devices	11
Specifications	12
Warranty	13
FAQs	14

CONTENTS

- 1 Carry Case
- 2 Type C Charging Cable
- 3 Super Cam Max Wireless Inspection Camera - With On-Board Memory
- 4 Super Rod Flexi
- 5 Super Rod Gooseneck
- 6 Super Rod Tuff Hook
- 7 Adaptors
- 8 Male Gender Changer
- 9 Super Magnet
- 10 1m Telescopic Stick



START-UP GUIDE

DOWNLOAD THE SUPER CAM APP: Scan the QR Code to get the App or search for Super Rod



Requires Android
V6.0 or later



Requires IOS
V11.2 or later



Apple, the App Store and the Apple Logo are trademarks of Apple Inc., registered in the U.S. and other countries. Google Play and the Google Play logo are trademarks of Google LLC

On first use you need to give the App access to the gallery of photos and videos on your device to be able to allow you to save photos and videos.

CONNECT TO YOUR SUPER CAM MAX CAMERA:

First unscrew the red cap at the back of the camera. Turn the power switch on. Once on, the dot should be green.



Ensure the camera is charged, the on button has been pushed to the right and that the green light is on.

Turn on WiFi connection in your Settings on Apple devices or Connections on your Android devices


Click on WiFi and search for "Super Cam xxxxxx" on the WiFi list (no other WiFi network is needed)

SUPER CAM MAX FEATURES

Work safer and smarter by streaming high resolution to your smart device in real time for up to 20m. Also record anytime/anywhere even when the WiFi signal is out-of-reach. Maximise storage with the on-board memory card, even if smart device storage is full.

- Maximum operating distance
- Use underground and underwater
- Speed up visual inspections
- Accurate inspection reports/quotations
- Easier fault finding
- Safe working in hard-to-reach places
- Time-saving cable installation

• INSPECT • ROUTE • CAPTURE DATA • WORK SAFE

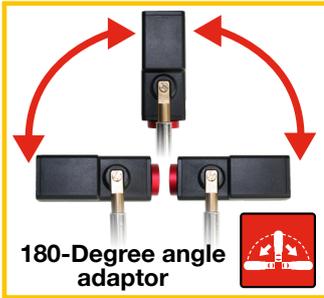

CONNECT TO YOUR SMART PHONE OR TABLET



On-board memory when WiFi signal out-of-reach
- Memory Capacity: 16GB, 10,000 pictures, 30h video recording



Wireless range up to 20m
- In line of sight



Always up viewing mode
- When the camera rotates, the image stays the right way up (when selected in settings)



60 min fast charge
- Fully charged in 1h with Type-C USB quick charge



Auto/manual focus
- Long press icon for manual adjustments



Non-contact voltage detector
- Audio & visual alert, 50V-1000V AC



IP67 dustproof and waterproof
- Only when back cap is securely fastened



Built-in WiFi hotspot
- Provides a high resolution live stream up to a 20m range



Record video with sound
- Accurate inspection reports for your customers



Digital pinch zoom
- Increases visibility and precision on inspections

BUTTON CONFIGURATION



SD Card Indicator



Battery Level Indicator

Adjust
Brightness



Manual/Auto
Focus



Help



Settings



Icon Layout Settings



Capture
Photos



Capture
Videos



Content
Gallery

AUTO/MANUAL FOCUS




Tap the AF/MF icon on your Super Cam app to adjust the focus. Alternatively, long press on the AF/MF icon and adjust the focus with a slider for detailed close-up viewing.



BRIGHTNESS



Tap the Brightness icon on your Super Cam app to adjust the lighting. Alternatively, long press on the icon and adjust the brightness up or down with a slider.

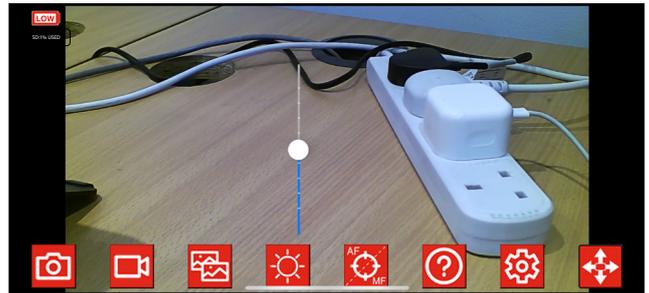

PINCH ZOOM



Use 2 fingers to use the digital zoom to bring your image closer.



SAVING PICTURES/VIDEOS




Tap the Camera icon to take a picture.



On-board memory when WiFi signal is out-of-reach


You can either save photos to the SD Card, or save to your device memory, the picture will be stored in both your Super Cam app photo gallery and the camera roll from the device you are using if “Phone” is selected in the Settings. If “SD Card” is selected in the Settings, the picture will then be stored in the SD Memory section of of the app and the camera roll from the device you are using.

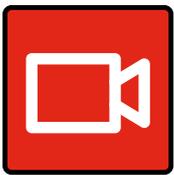

Tap the Video icon to take a video

If “Phone” is selected in the Settings, the video will be saved in your Super Cam app video gallery automatically as well as the camera roll from the device you are using. If “SD Card” is selected in the Settings, the video will then be stored in the SD Memory section of of the app as well as the camera roll from the device you are using.

Photo Gallery Tap on the Photo Gallery icon to access all images taken with your Super Cam Max.

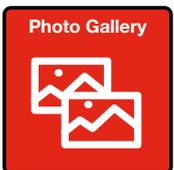

To view an image, tap on it. To delete an image press ‘select’ and tap on the image(s) you want to select then press delete.

Video Gallery







Tap on the Video Gallery icon to access all footage taken with your Super Cam Max.

To view a video, tap on it. To delete an image press ‘select’ and tap on the video(s) you want to select then press delete.

WIN!

For a chance to receive a gift send us your best footage and images captured using the Super Cam Max. If your content is shared then we will send you a gift. Any content you sent us can be used for marketing purposes. Send your content to sales@super-rod.co.uk

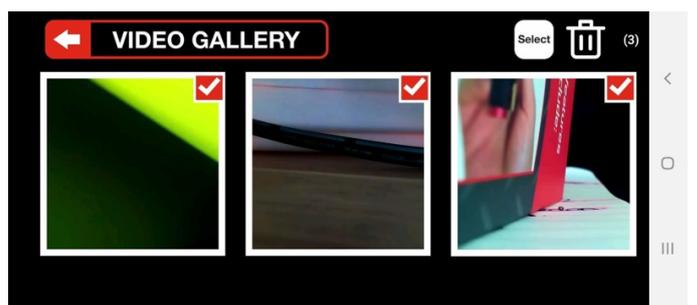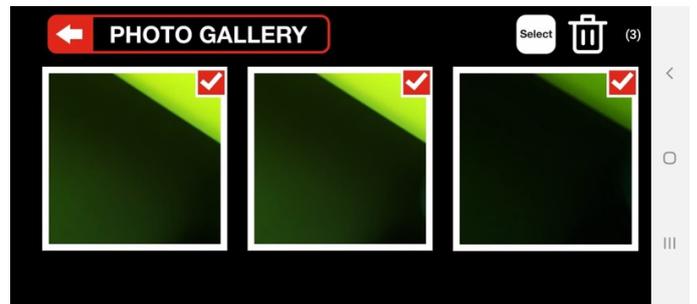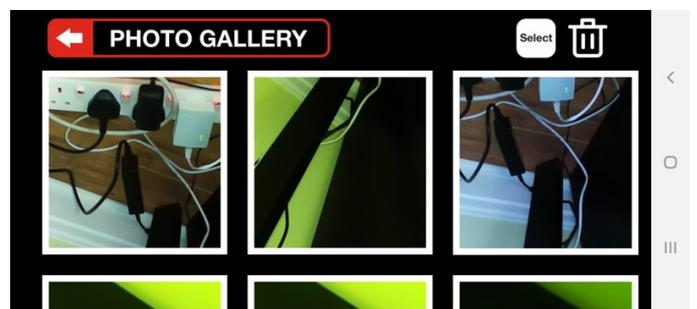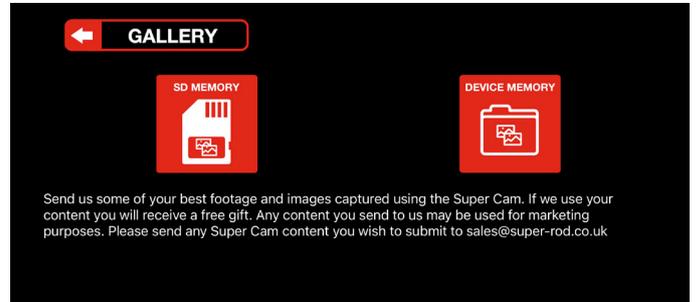

SETTINGS



The Settings screen allows you to do the following: Change the Display Mode from Standard to Always up Round or Full Screen, Save to SD card or phone options.

Change the settings to save your pictures and videos:

- Phone - stored in both your Super Cam app photo gallery and the camera roll from the device you are using
- SD Card - stored in the SD Memory section of the Super Cam app and the camera roll from the device you are using

• Standard Mode: the image on the screen rotates as the camera rotates

• Always up Mode (either Round or Full Screen): the image on the screen remains the right way up on the app display, regardless of the camera's orientation

Change the Freeze Frame option







- On: this will allow you to have a choice to save the image or not when taking a picture
- Off: the image you have taken will save automatically

Change the settings for the Non-Contact Voltage Detector

- Off: The Voltage detector is deactivated
- Visual Only: Red light around the image on our Super Cam app

• Visual & Audible: Red light around the image on your Super Cam app as well as a beeping sound


Make sure you save once you have changed the settings.

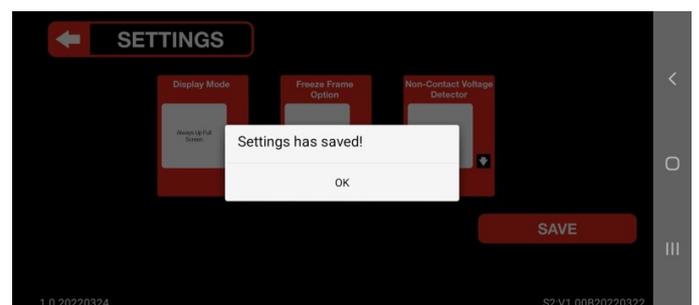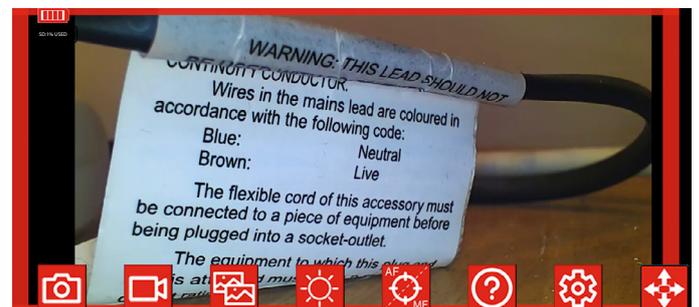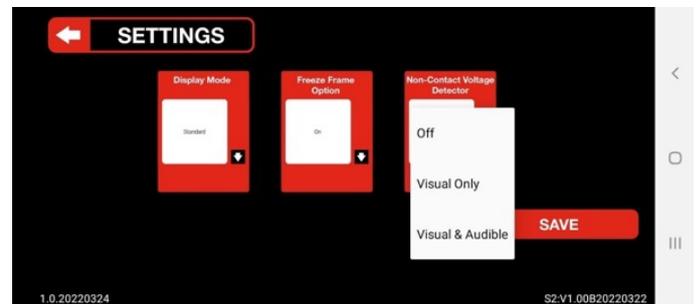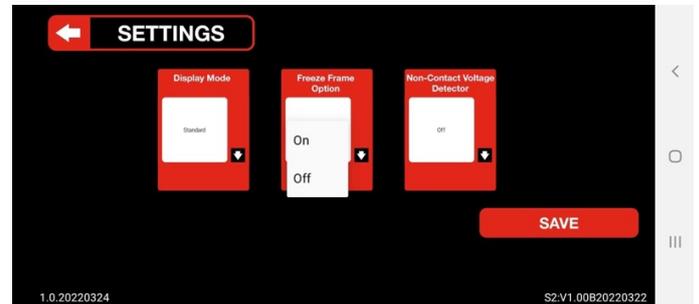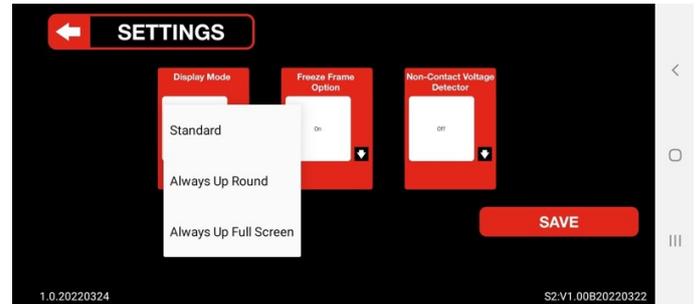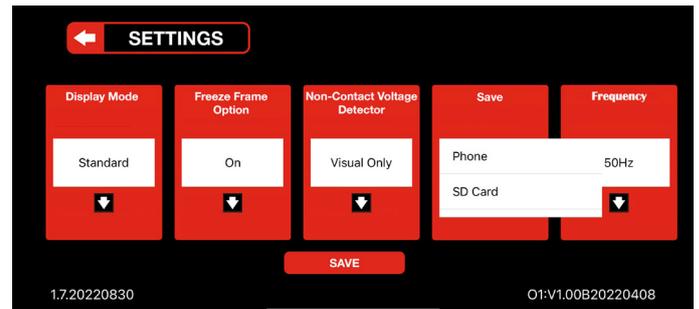


ICON OPTIONS



Press long on the Icon Options icon to choose the position of the icons

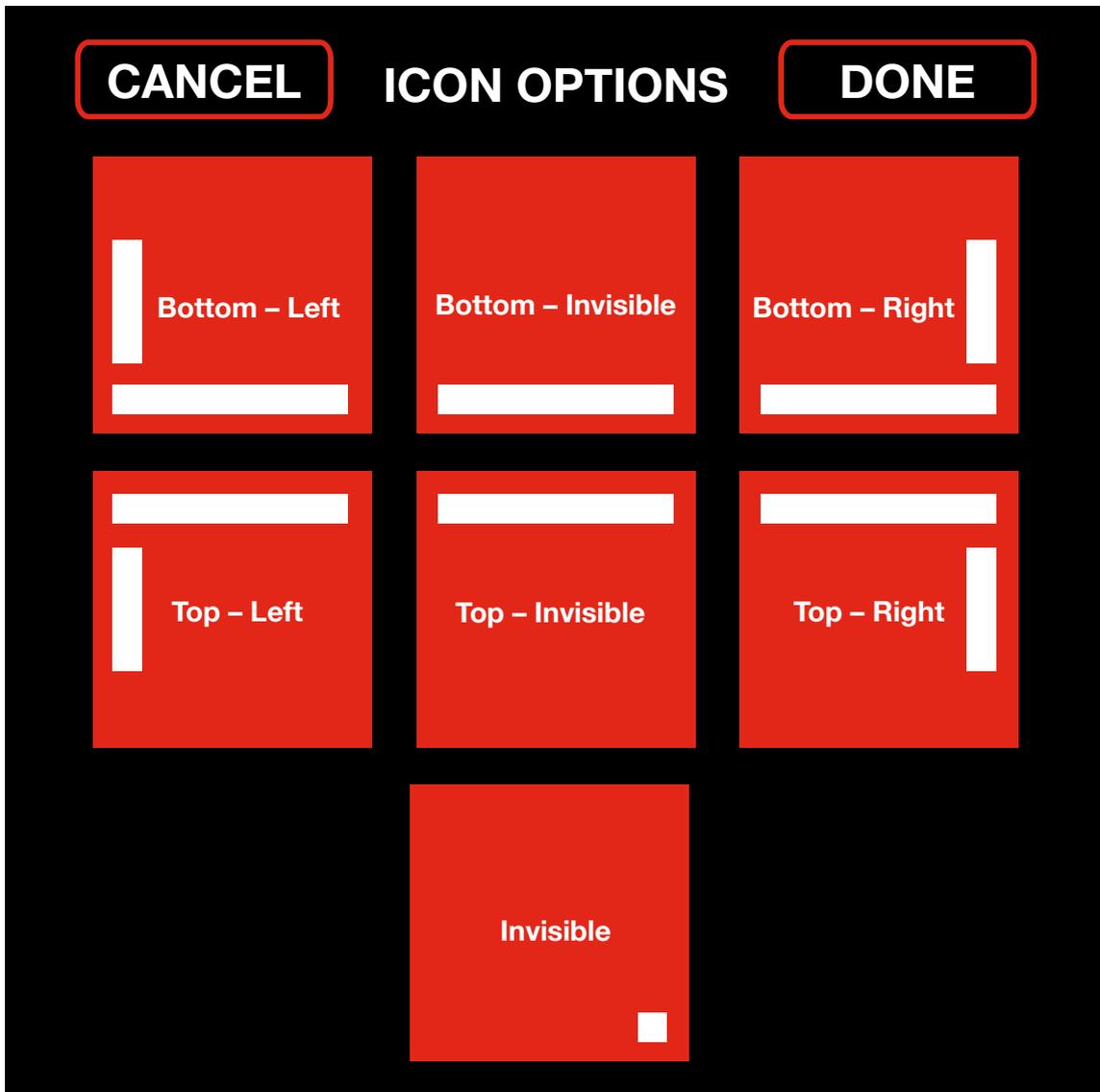

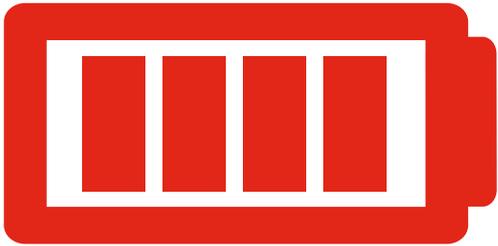

A Type-C USB Charging Cable is included in the Super Cam Max kit. The Super Cam Max features a fast-charge allowing you to charge it fully in an hour.



Green light when in use.



Red light when it's charging

The charge is indicated on the top left of your screen while using the app



Blue light when it's fully charged


CONNECTING THE SUPER CAM TO MULTIPLE DEVICES

Connect your Super Cam Max wirelessly to multiple devices at the same time allowing users not in same location to use the same Super Cam Max. Users will be able to view the same thing and control the features directly on their device.

To connect multiple devices to the Super Cam Max:

Turn on WiFi connection in your Settings on Apple devices or Connections on your Android devices
Click on WiFi and search for "Super Cam xxxxxx" on the WiFi list (no other WiFi network is needed)

Note: There is no limit of numbers of devices connected to the same camera, but the more devices connected the higher latency. For better users' experience two devices is recommended.

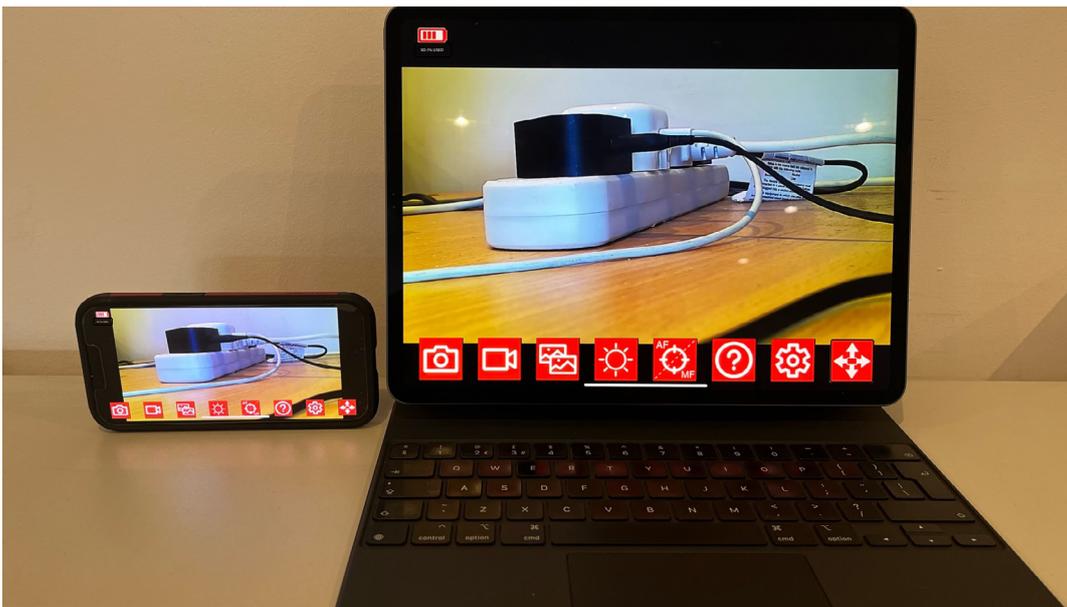

SRCAMV6.5MAX - Super Cam Max Wireless Inspection Camera Specifications	
Wireless Range	20m with WiFi Hotspot on board memory when signal is out of reach
Memory Capacity	16GB, 10,000 pictures 30h video recording
Frequency	2.4GHz WIFI
Camera Resolution	720p (1280 x 720) for both live and recorded videos
Operating Time	approx 90 mins (LEDs full) to 105 mins (LEDs off)
Charging Time	60 min fast charge
Viewing Angle	33 Degrees (Horizontal)
Charge Port	USB Type C
Battery Capacity	650mAh
Battery Type	lithium polymer
Operating Temperature	0 degrees to 35 degrees Celsius
Storage Temperature	-20 degrees to 45 Degrees Celsius
Charge Voltage	5V DC
Non-Contact Voltage Detector Sensitivity	best sensitivity 150 voltage AC and above - CATIII 600V
Non-Contact Voltage Detector Sensor Range	50V-1000V AC (Approx)
Adjustable bright white LEDs	6 white - control functionality via the app (off, 25%, half, full)
IP67	dustproof and waterproof with back cap on
Built in right angle adaptor	180 degrees

WARRANTY

The Super Cam Max warranty covers defects in materials and workmanship for a period of 2 years after date of original retail purchase.

At its option, Super Rod will repair or replace, any product which fails to conform to this warranty. This warranty does not apply to damage from alterations, abuse, misuse, lack of maintenance, or normal wear and tear of the product.

This warranty explicitly does NOT cover cut or deliberately damaged tape, rust or corrosion or foreign material, cracked or broken cases, or bent hooks or bent/missing accessories.

Please email sales@super-rod.co.uk, or simply return your Super Cam Max to your place of purchase with proof of purchase.

Important Information – Li-Ion Batteries

The Super Cam Max camera contains a Li-Ion battery. For optimal battery life, do not store the camera while the battery is flat, do not store the camera in temperatures of over 35°C (95°F) and if the camera is not being used, top up the charge every 6 months.

I can't connect or see the camera when I search on Bluetooth?

The Super Cam Max has a built-in WiFi hotspot. No other network is needed, and the camera does not connect via Bluetooth. Refer to the start-up guide on page X to connect the Super Cam Max to your device.

Can I use the camera underground, underwater or inside a conduit?

The Super Cam Max is IP67 dustproof and waterproof only when back cap is securely fastened. When using the Super Cam Max underground, underwater or inside a metallic conduit you might lose the WiFi signal so the live video might be interrupted. However you will still be able to record footage as long as the SD Card option is selected in the Settings. The content can then be retrieved in the SD Gallery.

How long does the battery last?

The Super Cam Max will give you up to 90 minutes of use, with the LEDs on full brightness and 105 minutes of use with the LEDs off, before it needs recharging.

What does the rear LED indicate?

Green light when in use.

Red light when it's charging

Blue light when it's fully charged.

Refer to page X for more information.

I don't use Super Rods can I use the Super Cam Max with other cable rods on the market?

Yes the Super Cam Max comes with two Cable Rod Adaptors that have M4 & M5 threads, these can be used with the Super Cam Max to fit most Cable Rods sold in the UK & Europe.

I can connect to the WiFi, but it won't show an image in the iOS App? It shows an error message Error(100)(Connect the device time out!)

Go to Settings-> Mobile Data-> Scroll down to find the Super Cam App and turn off to prevent the App trying to use mobile data.

I can connect to the WiFi, but it won't show an image in the Android App? It shows an error message Error(100)(Connect the device time out!)

Go to Settings-> Connections-> Data Usage-> Mobile Data only apps-> Scroll down to find the Super Cam App. Turn off background data to prevent the App trying to use mobile data.