




VIVANCO


# UK SWING L (39775)

Version 1.0


Vivanco Gmbh  
Ewige Weide 15  
22926 Ahrensburg, Germany  
www.vivanco.com

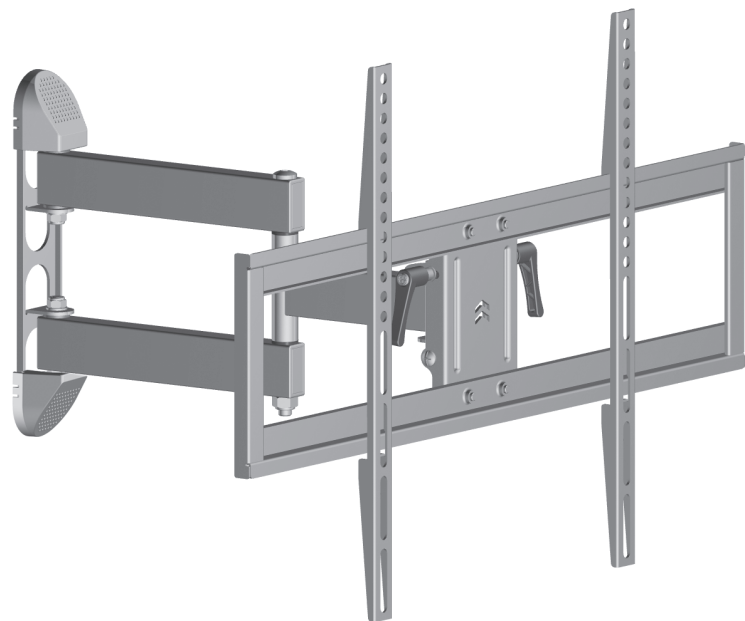


1

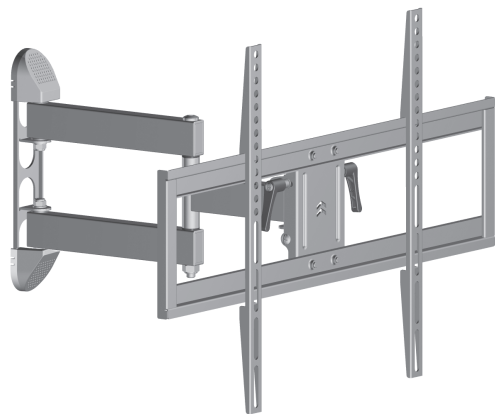

2

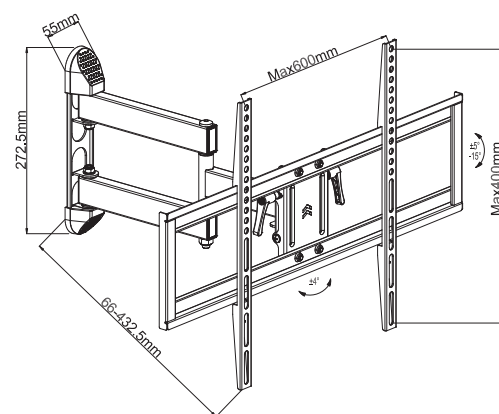


3

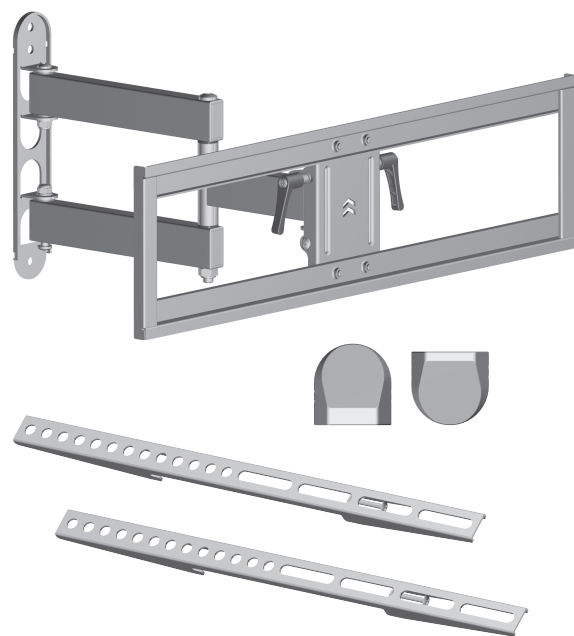


|     |  |               |       |  |              |
|-----|--|---------------|-------|--|--------------|
| (A) |  | 3x 6,3 x 65   | (F-M) |  | 4x M4 x 15mm |
| (B) |  | 3x 10 x 61    |       |  | 4x M4 x 30mm |
| (C) |  | 4x Ø 5 x Ø 16 |       |  | 4x M4 x 45mm |
| (D) |  | 4x            |       |  | 4x M6 x 15mm |
| (E) |  | 3x Ø 6        |       |  | 4x M6 x 30mm |
|     |  |               |       |  | 4x M8 x 15mm |
|     |  |               |       |  | 4x M8 x 30mm |
|     |  |               |       |  | 4x M8 x 45mm |


4

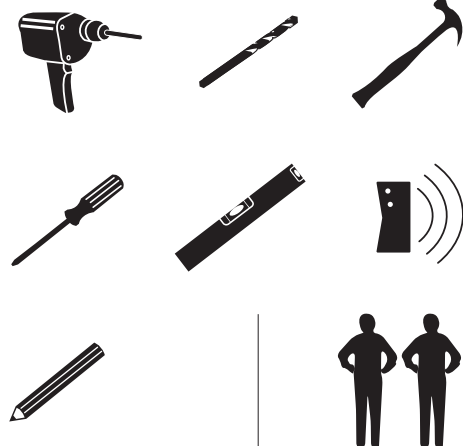

5

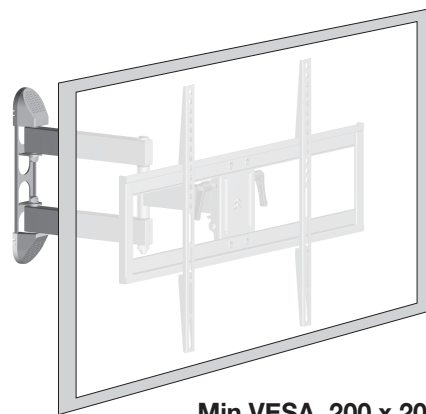


Min VESA 200 x 200  
Max VESA 600 x 400

 

Max.  
216cm/85"




45kg  
max.

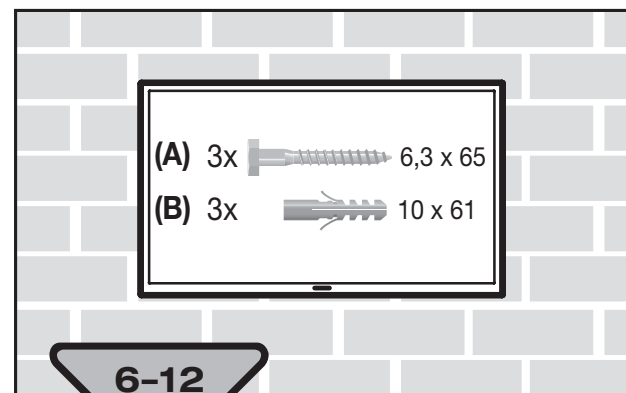

6-12




SPECIALIST

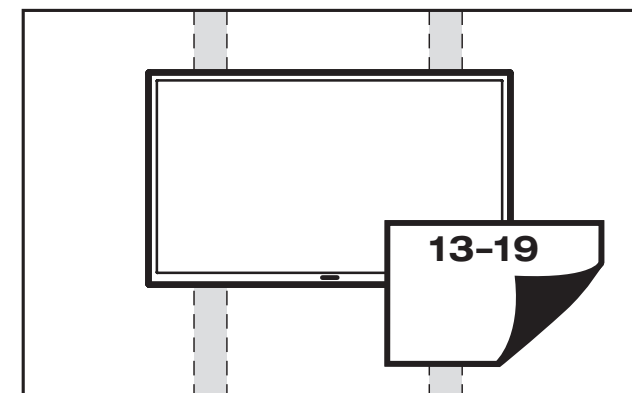


13-19


6

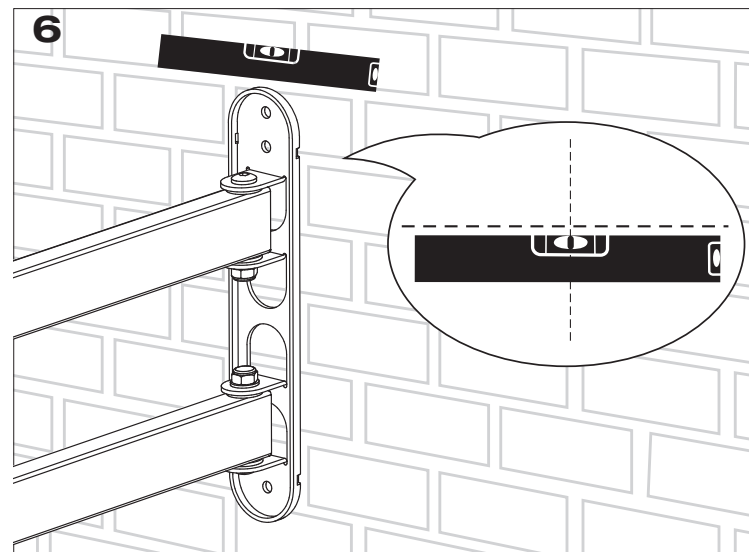


7

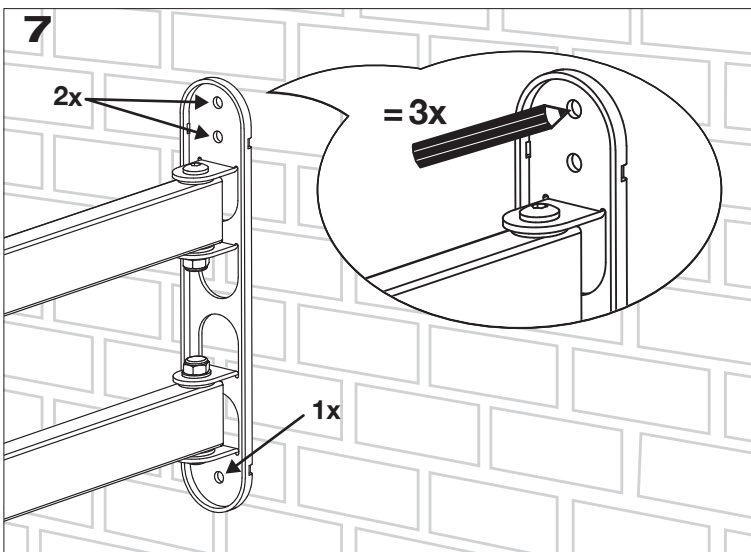


8

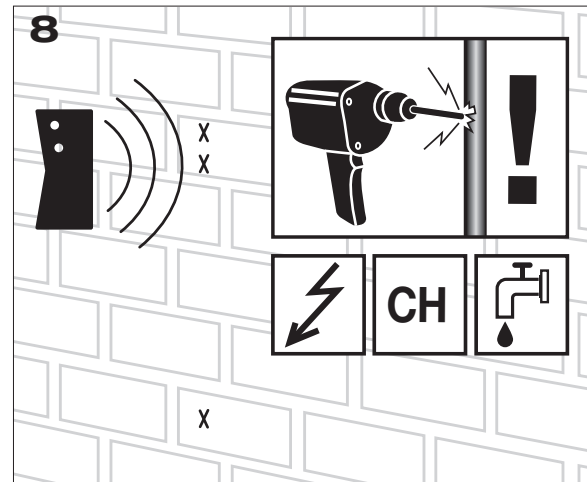


9

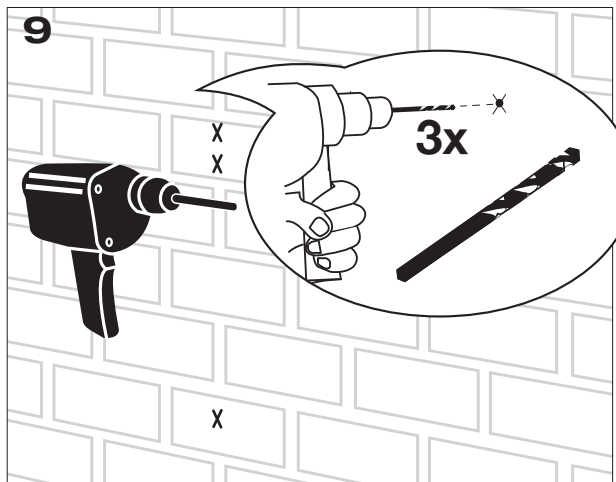


10

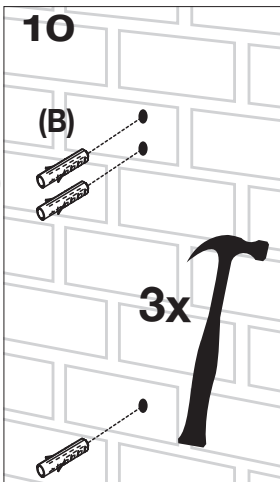

11

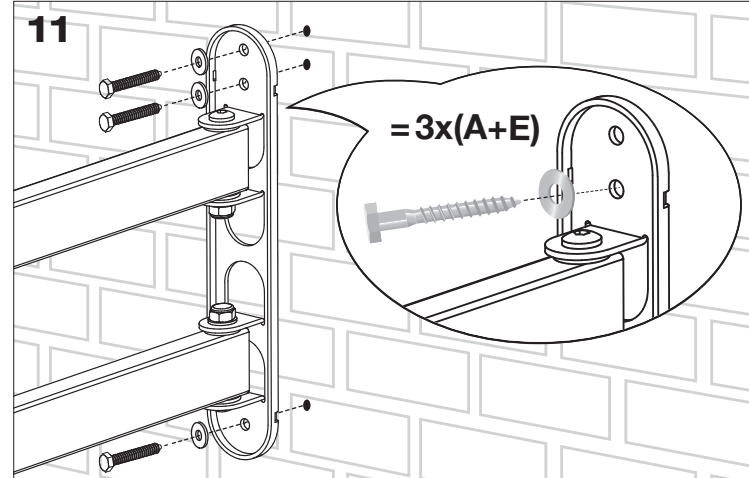

12

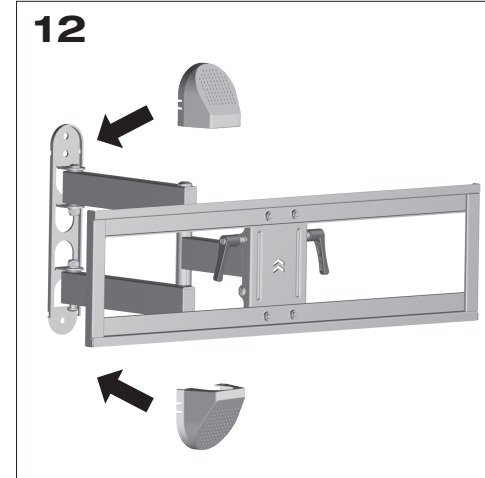

SPECIALIST

