

**Surface-mount Ceramic Multilayer Capacitors (RoHS compliant & Halogen Free)**



CS888800000SB000

Soft termination Series Sample Kit

Spec Sheet

**Scope**

This product specification is applied to Multi-layer Ceramic Capacitor used for General Electronic equipments .

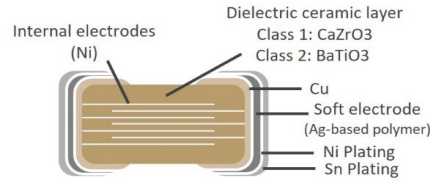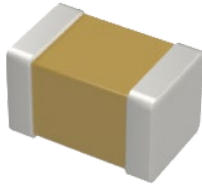

No.	Part. NO.	Size	TC	Cap.	Volt.	Tol	No.	Part. NO.	Size	TC	Cap.	Volt.	Tol
1	CS0402KRX7R8BB104	0402	X7R	100nF	25V	±10%	26	CS0805KRX7R9BB104	0805	X7R	100nF	50V	±10%
2	CS0402KRX7R9BB473	0402	X7R	47nF	50V	±10%	27	CS0805KKX7R9BB474	0805	X7R	470nF	50V	±10%
3	CS0603KRX7R7BB105	0603	X7R	1uF	16V	±10%	28	CS0805KRX7RYBB222	0805	X7R	2.2nF	250V	±10%
4	CS0603KRX7R8BB154	0603	X7R	150nF	25V	±10%	29	CS0805KKX7RBBB223	0805	X7R	22nF	500V	±10%
5	CS0603KRX7R8BB224	0603	X7R	220nF	25V	±10%	30	CS0805KKX7RZBB103	0805	X7R	10nF	630V	±10%
6	CS0603KRX7R8BB474	0603	X7R	470nF	25V	±10%	31	CS0805KRX7RCBB102	0805	X7R	1nF	1KV	±10%
7	CS0603KRX7R9BB101	0603	X7R	100pF	50V	±10%	32	CS1206KRX7R8BB224	1206	X7R	220nF	25V	±10%
8	CS0603KRX7R9BB221	0603	X7R	220pF	50V	±10%	33	CS1206KRX7R9BB102	1206	X7R	1nF	50V	±10%
9	CS0603KRX7R9BB471	0603	X7R	470pF	50V	±10%	34	CS1206KRX7R9BB103	1206	X7R	10nF	50V	±10%
10	CS0603KRX7R9BB102	0603	X7R	1nF	50V	±10%	35	CS1206KRX7R9BB104	1206	X7R	100nF	50V	±10%
11	CS0603KRX7R9BB222	0603	X7R	2.2nF	50V	±10%	36	CS1206KKX7R9BB334	1206	X7R	330nF	50V	±10%
12	CS0603KRX7R9BB332	0603	X7R	3.3nF	50V	±10%	37	CS1206KRX7R0BB332	1206	X7R	3.3nF	100V	±10%
13	CS0603KRX7R9BB472	0603	X7R	4.7nF	50V	±10%	38	CS1206KRX7R0BB472	1206	X7R	4.7nF	100V	±10%
14	CS0603KRX7R9BB103	0603	X7R	10nF	50V	±10%	39	CS1206KKX7RZBB471	1206	X7R	470pF	630V	±10%
15	CS0603KRX7R9BB223	0603	X7R	22nF	50V	±10%	40	CS1206KKX7RZBB102	1206	X7R	1nF	630V	±10%
16	CS0603KRX7R9BB333	0603	X7R	33nF	50V	±10%	41	CS1206KKX7RZBB222	1206	X7R	2.2nF	630V	±10%
17	CS0603KRX7R9BB473	0603	X7R	47nF	50V	±10%	42	CS1206KKX7RZBB332	1206	X7R	3.3nF	630V	±10%
18	CS0603KRX7R9BB104	0603	X7R	100nF	50V	±10%	43	CS1206KKX7RZBB472	1206	X7R	4.7nF	630V	±10%
19	CS0603KRX7R0BB104	0603	X7R	100nF	100V	±10%	44	CS1206KKX7RZBB103	1206	X7R	10nF	630V	±10%
20	CS0603KRX7RYBB222	0603	X7R	2.2nF	250V	±10%	45	CS1206KKX7RZBB333	1206	X7R	33nF	630V	±10%
21	CS0805KKX7R7BB225	0805	X7R	2.2uF	16V	±10%	46	CS1206KKX7RCBB221	1206	X7R	220pF	1KV	±10%
22	CS0805KKX7R8BB105	0805	X7R	1uF	25V	±10%	47	CS1206KKX7RCBB471	1206	X7R	470pF	1KV	±10%
23	CS0805KRX7R9BB102	0805	X7R	1nF	50V	±10%	48	CS1206KKX7RCBB102	1206	X7R	1nF	1KV	±10%
24	CS0805KRX7R9BB222	0805	X7R	2.2nF	50V	±10%	49	CS1206KKX7RCBB472	1206	X7R	4.7nF	1KV	±10%
25	CS0805KRX7R9BB103	0805	X7R	10nF	50V	±10%	50	CS1206KKX7RCBB103	1206	X7R	10nF	1KV	±10%

Pieces per items: Case size 01005 to 0402, 80pcs; 0603 to 1808, 40pcs; 1812, 20pcs.