




## 4L2/6001

### Solar Bollard LED



#### Features

- Modern die-cast solar powered aluminium LED bollard
- Rotatable head design which can swing in 90° allowing for a varied range of installation options
- Mode 1: 15% output after sunset, motion detected 100% output, no motion 15% output for 15 hours
- Mode 2: Motion detected 100% light output, no motion off

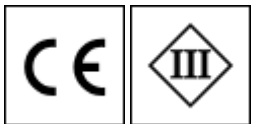

Specification

Lamp	LED
Colour / Finish	Graphite
Wattage	
Warranty	4*
Lumens Delivered	165
Input	
Operating Temp	-20° to 45°