



LED monitor

B196L A


Flexible viewing, professional style

- 19" HD Acer ComfyView display with Acer eColor technology
- Ergonomic stand: adjustable tilt, swivel, pivot and height
- Earth-friendly: recycled plastic, LED backlight, Acer EcoDisplay
- EPEAT gold, EnergyStar and TCO 6.0 certification



Specifications

Model number	B196L A	
Display	19" (5:4)	
Active display area	37.5 x 30.0 cm	
Maximum resolution and refresh rate	1280 x 1024 @ 60 Hz	
Glare	No	
Panel type	IPS	
Response time	5 ms (on/off)	
Contrast ratio (ACM)	100 million:1 max	
Brightness	250 cd/m2	
Viewing angle (CR=10)	178°(H), 178°(V)	
Colors	16.7 million	
Bits	6-bit + Hi-FRC	
Input signal	HDMI,VGA+DVI (w/ HDCP)	
VESA wall mount	100 x 100 mm	
Speaker	NA	
Pivot	Y	
Tilt/swivel/height adjust	-5°~35° / ±60° / 150mm	
Power supply	Internal (100 – 240 V)	
Power consumption (ENERGY STAR®)	Off	0.14 W
	Sleep	0.30 W
	On	15.8 W

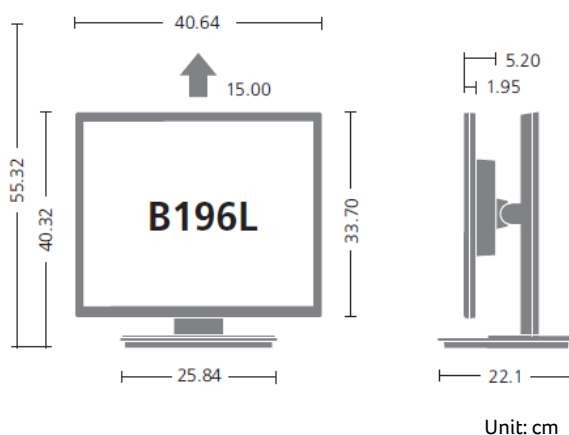

HD LED monitor



The 1280 x 1024 resolution of this LED monitor delivers excellent detail, making it perfect for advanced HD productivity and multimedia applications. LED monitors also consume less power and last longer than those with CCFL lamps. In addition, this monitor is mercury free, making it safer for you and the environment.



Acer Eco Display

Acer monitors using white LED backlight technology minimize environmental impact while providing superior performance. White LED monitors do not contain mercury, making them safer for the environment. They also consume less power and are more durable than CCFL lamps, for good savings. Plus, as part of our commitment to sustainable operations and CSR, Acer uses methods to carry out product design and material management distinctly meant to reduce environmental impact.



ComfyView

ComfyView

Acer ComfyView monitors reflect less ambient light to deliver vivid colors, reduced glare and more comfortable viewing, even over prolonged periods.



ErgoStand

ErgoStand

The ergonomic design of this monitor optimizes the viewing position for maximum comfort even during prolonged use.

- Height: 150 mm up or down
- Tilt: 35° up or 5° down
- Swivel: 60° to the left and right
- Pivot (rotation): Up to 90°

About Acer

Established in 1976, Acer is an information and communication technology company dedicated to the research, design, marketing, sale and support of innovative products that enhance people's lives. Acer's green supply chain delivers environmentally friendly PCs, displays, projectors, servers, tablets and smartphones — tools our customers need to explore beyond limits and experience more. Ranked No. 2 for notebooks globally (Gartner 2011), Acer employs 8,000 people, and 2011 revenues reached US\$15.7 billion. Please visit www.acer.com for more information.

acer
explore beyond limits™