


Energizer®

QE10007PQ

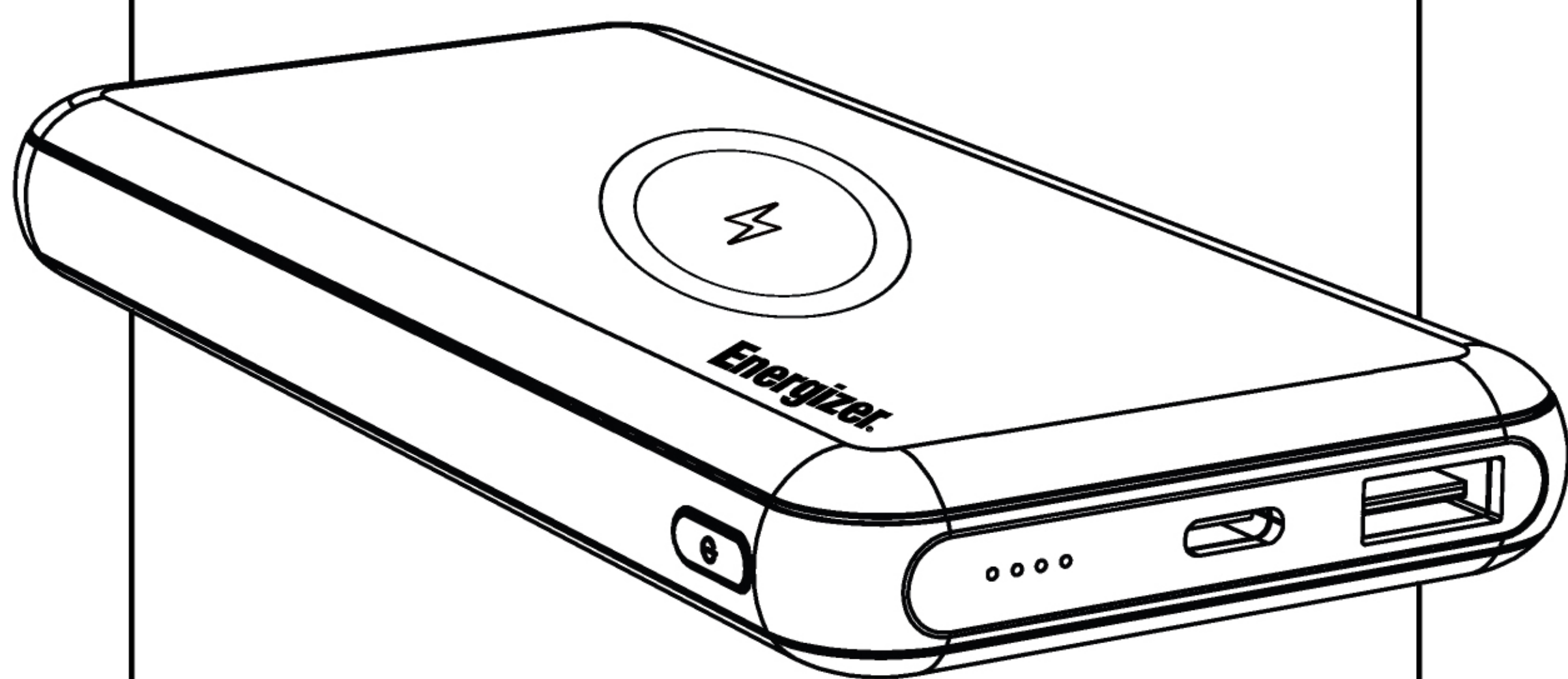

Includes

EN

Specification:

Model Name : QE10007PQ
Cell Type : Lithium Polymer
Battery Capacity : 10000 mAh/ 37Wh (Max.)
Rated Input : Micro USB 5V/2A
Rated Input : USB-C PD 5V/2A, 9V/2A
Rated Output : USB-A Quick Charge 5V/3A, 9V2A, 12V/1.5A
Rated Output : USB-C PD 5V/2A, 9V/2A, 12V/1.5A
Wireless Output : 5W/7.5W/10W
Total Output : 18W Max.
Dimensions : 144.1(L) x 68.8(W) x 16.5(H)mm
Weight : 210g±10g

FR

Spécifications:

Modèle : QE10007PQ
Type de cellule : Lithium Polymère
Capacité de la batterie : 10000 mAh/ 37Wh (Max.)
Entrée : Micro USB 5V/2A
Entrée : USB-C PD 5V/2A, 9V/2A
Sortie : USB-A Quick Charge 5V/3A, 9V2A, 12V/1.5A
Sortie : USB-C PD 5V/2A, 9V/2A, 12V/1.5A
Sortie sans fil : 5W/7.5W/10W
Sortie totale : 18W Max.
Dimensions : 144.1(L) x 68.8(W) x 16.5(H)mm
Poids : 210g±10g

DE

Technische Daten:

Modell : QE10007PQ
Zellentyp : Lithium-Polymer
Akkukapazität : 10000 mAh/ 37Wh (Max.)
Eingangsspannung : Micro USB 5V/2A
Eingangsspannung : USB-C PD 5V/2A, 9V/2A
Ausgangsspannung : USB-A Quick Charge 5V/3A, 9V2A, 12V/1.5A
Ausgangsspannung : USB-C PD 5V/2A, 9V/2A, 12V/1.5A
Drahtlos-Leistung : 5W/7.5W/10W
Gesamtleistung : 18W Max.
Abmessungen : 144.1(L) x 68.8(W) x 16.5(H)mm
Gewicht : 210g±10g

SP

Especificaciones:


Modelo : QE10007PQ
Tipo de celda : Polímeros de Litio
Capacidad de la batería : 10000 mAh/ 37Wh (Max.)
Tensión de Entrada : Micro USB 5V/2A
Tensión de Entrada : USB-C PD 5V/2A, 9V/2A
Tensión de Salida : USB-A Quick Charge 5V/3A, 9V2A, 12V/1.5A
Tensión de Salida : USB-C PD 5V/2A, 9V/2A, 12V/1.5A
Salida inalámbrica : 5W/7.5W/10W
Producción total : 18W Max.
Dimensiones : 144.1(L) x 68.8(W) x 16.5(H)mm
Peso : 210g±10g

IT

Specifiche tecniche:

Modello : QE10007PQ
Tipo di cella : polimeri di litio
Capacità batteria : 10000 mAh/ 37Wh (Max.)
Ingresso Nominale : Micro USB 5V/2A
Ingresso Nominale : USB-C PD 5V/2A, 9V/2A
Potenza Nominale : USB-A Quick Charge 5V/3A, 9V2A, 12V/1.5A
Potenza Nominale : USB-C PD 5V/2A, 9V/2A, 12V/1.5A
Uscita wireless : 5W/7.5W/10W
Output totale : 18W Max.
Dimensioni : 144.1(L) x 68.8(W) x 16.5(H)mm
Peso : 210g±10g


Package Contents

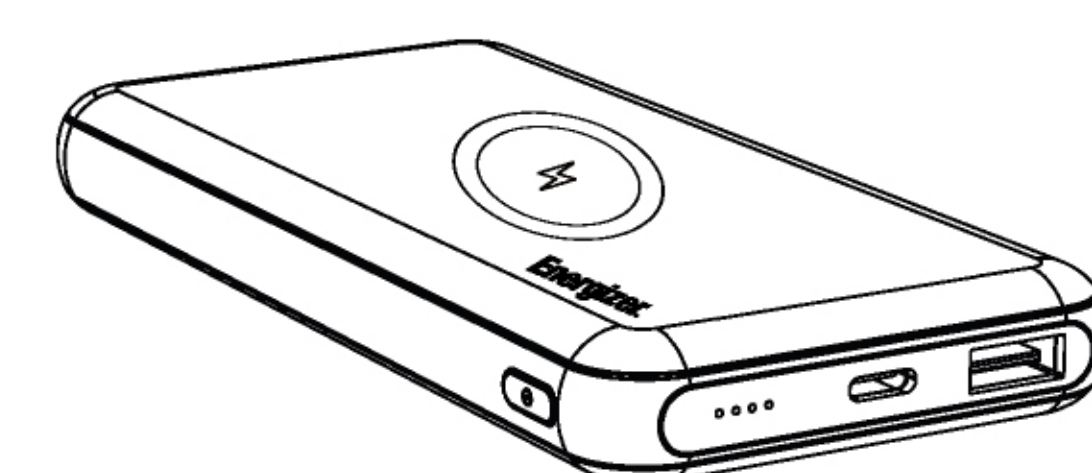

1 QE10007PQ



2 User Manual

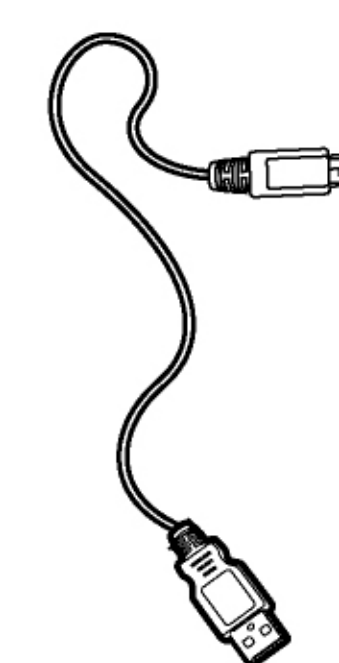

3 Charging Cable



PowerSafe Management

Guarantees against short circuit and over-charging for your power bank and devices.



Customer Service


For any question about the product, please contact us at service@energizerpowerbanks.com

© 2019 Energizer. Energizer and certain graphic designs are trademarks of Energizer Brands, LLC and related subsidiaries and are used under license by TennRich International Corp. All other brand names are trademarks of their respective owners. Neither TennRich International Corp. nor Energizer Brands, LLC is affiliated with the respective owners of their trademarks.


Qualcomm Quick Charge is a product of Qualcomm Technologies, Inc. Qualcomm is a trademark of Qualcomm Incorporated, registered in the United States and other countries. Quick Charge is a trademark of Qualcomm Incorporated. All Qualcomm Incorporated trademarks are used with permission.

How to USE

*Compatible with wireless charging standard

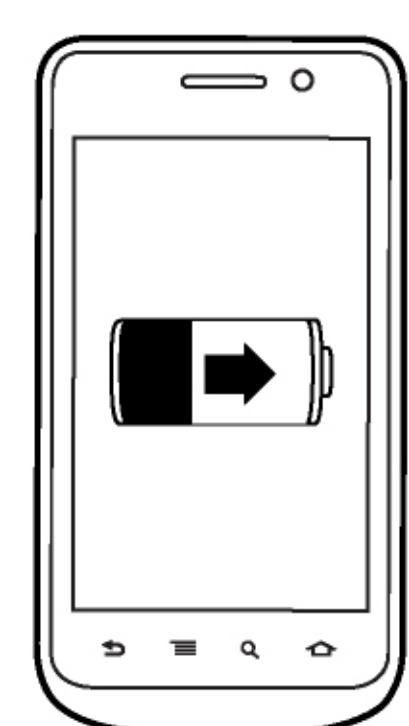


For fast charge (via cable): connect only one device to power bank to activate fast charge, do not press the power button
For wireless: press the power button once to activate wireless charging, fast charge (via cable) will switch to normal charging mode. After 2 mins of idle, wireless charging will shut off, fast charge will then resume

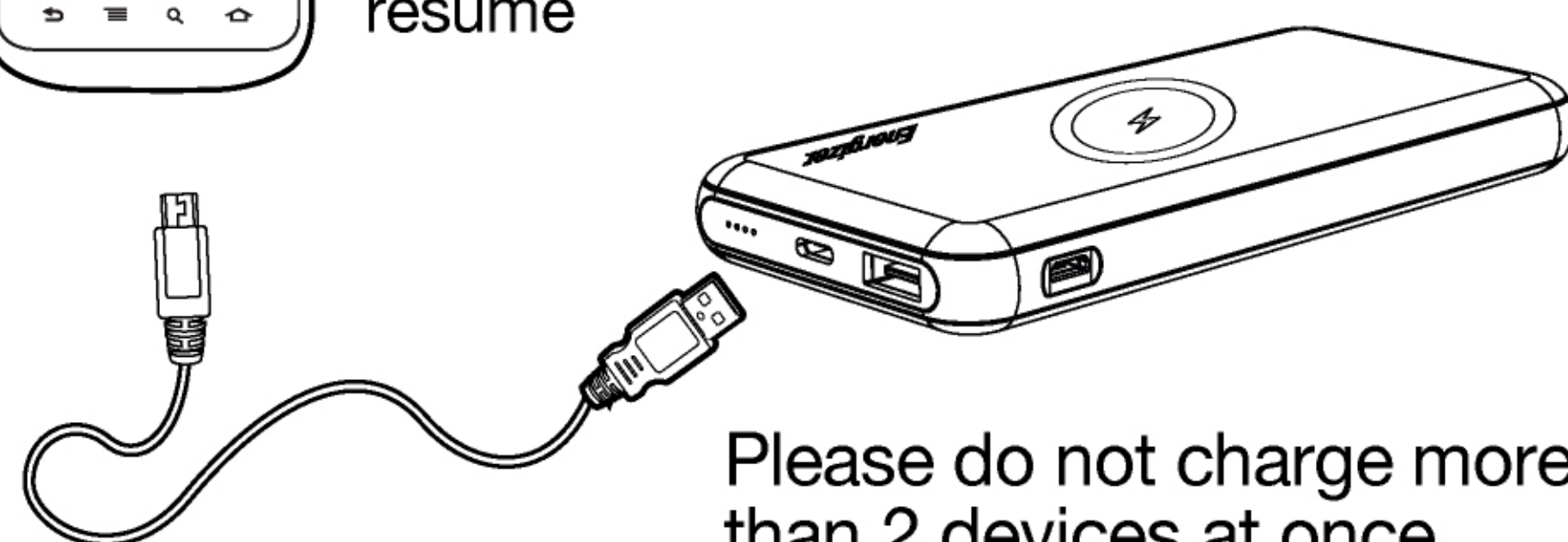


Please do not charge more than 2 devices at once (wireless charger is included)

Green light indicates wireless charging is activated

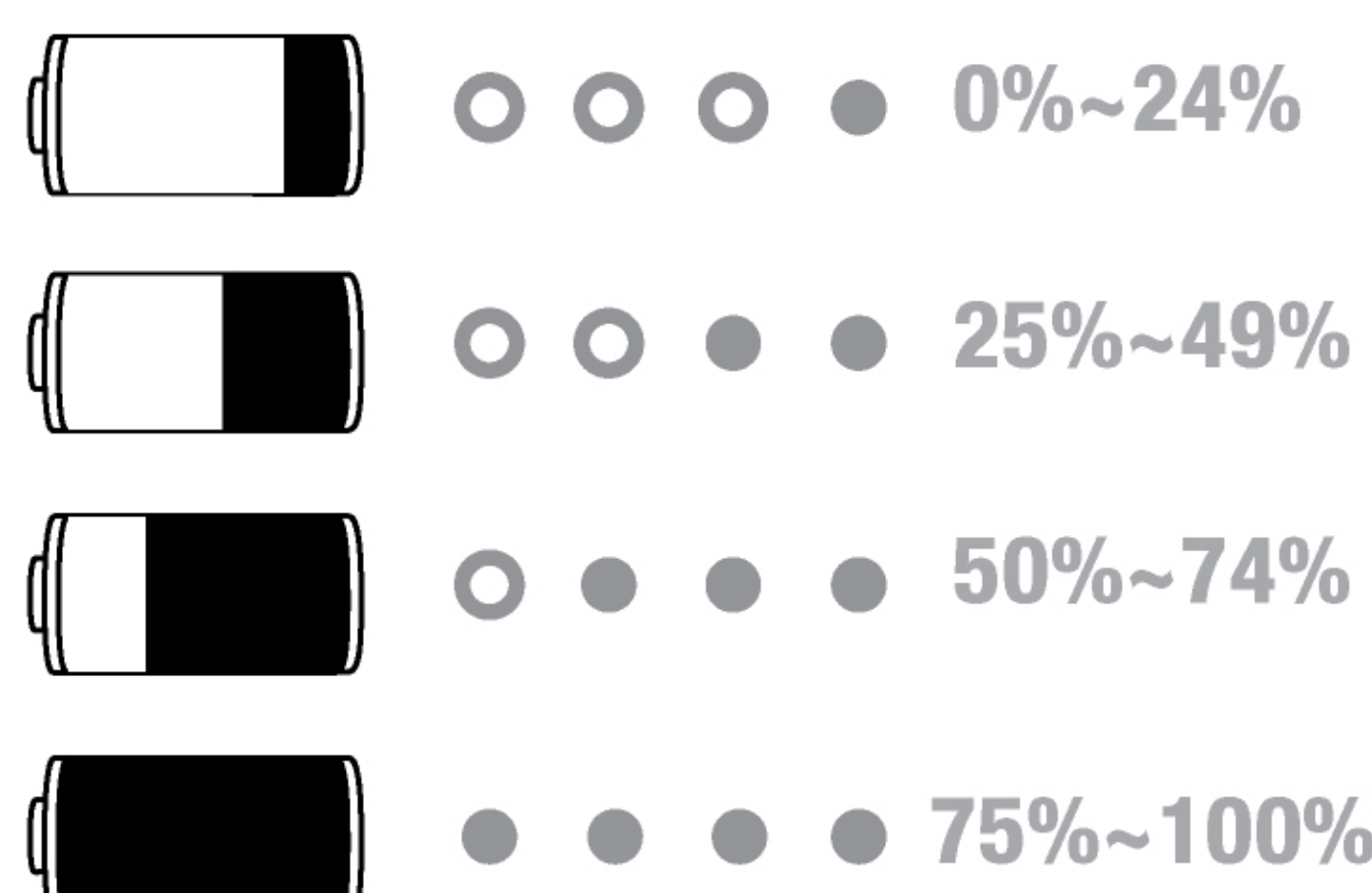

Blinking light indicates recharging.
Solid light indicates fully charged.

How to Recharge

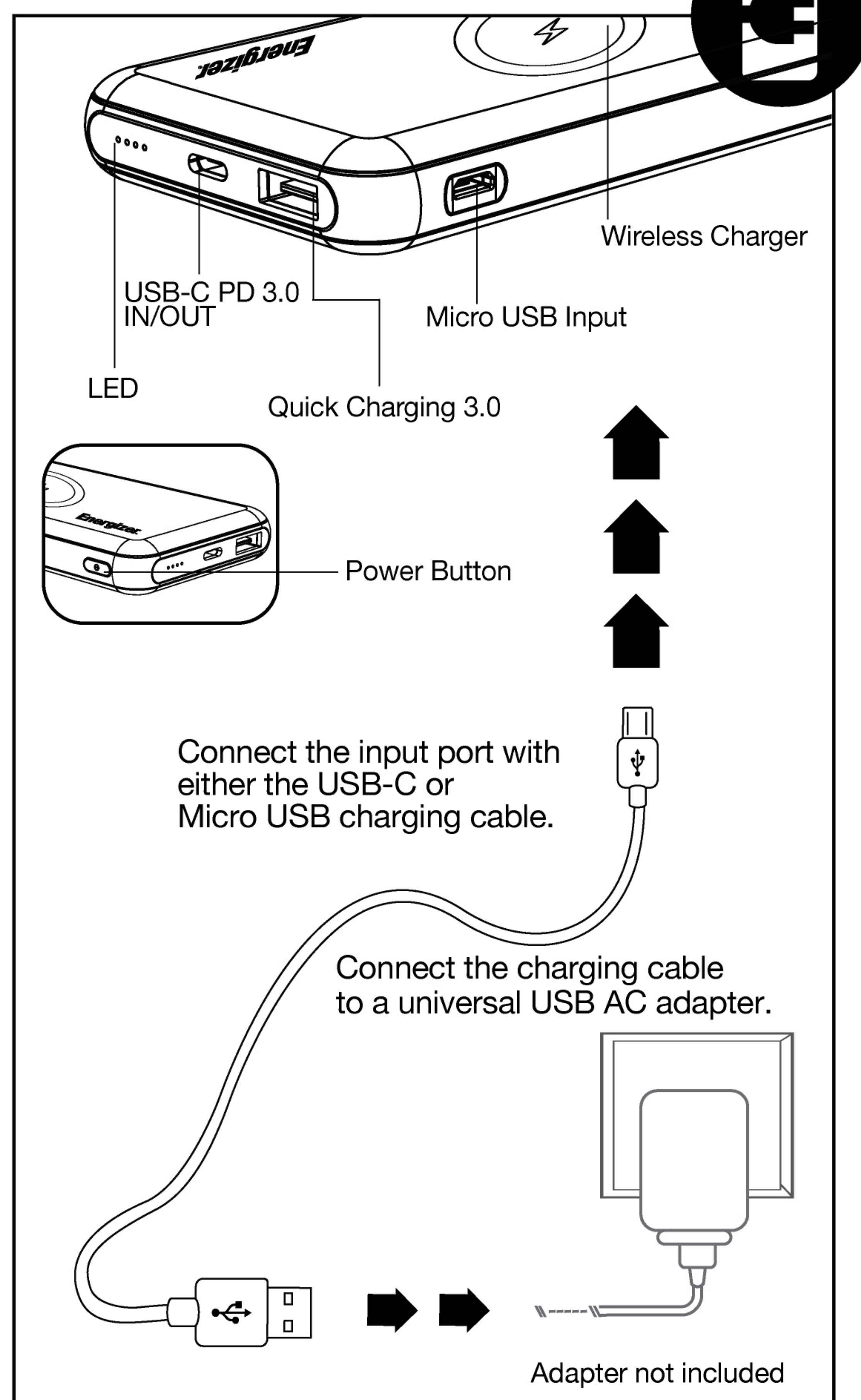

Safety Instruction

- Avoid water, heat, fire, penetration of the battery, and severe drops at all times.
- Do not insert other objects into the USB ports other than the USB connectors.
- Once the product is fully charged, your power pack automatically shuts off to save power.
- During charge & recharge, battery may feel slightly warm.
- Do not clean the battery with water or other cleaning products, clean the exterior with a lightly wetted cloth or napkin.
- Normally the battery performance will decline after 2 years
- Any intentional and physical damage to the battery will not be under the warranty conditions.
- Battery storage temperature is between -10°C~+60°C, operating temperature is 0°C~45°C.
- Fully charge the battery before first use to maximize the battery life.

WARRANTY

All products from the date of purchase are qualified for limited time warranty. For more warranty information, please visit: <http://www.energizerpowerbanks.com>

GARANTIE

Alle Produkte eignen sich ab dem Kaufdatum zu einer beschränkten Qualitätsgarantiezeit. Für zusätzliche Garantieinfos klicken Sie bitte auf: <http://www.energizerpowerbanks.com>

GARANTIE


Tous les articles bénéficient d'une garantie limitée dans le temps à partir de la date d'achat. Pour plus d'informations concernant la garantie, merci de visiter notre site : <http://www.energizerpowerbanks.com>

GARANZIA

Tutti i prodotti, a partire dalla data di acquisto, hanno la certificazione sulla qualità per un periodo limitato di tempo. Per ulteriori informazioni sulla garanzia si prega di visitare il sito: <http://www.energizerpowerbanks.com>

GARANTIA

Todos los productos desde la fecha de compra gozan de la garantía de tiempo limitado. Para más información sobre la garantía, puede visitar: <http://www.energizerpowerbanks.com>

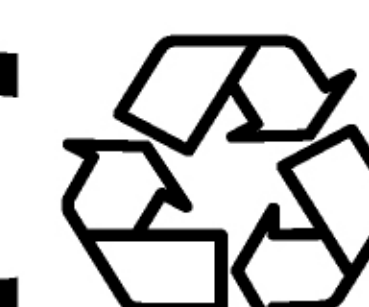

Dispose the battery properly, seek for local disposal facility for advice.
Do not dispose, dissemble, damage, or incinerate the battery at all time.