


## Low-Profile TV Wall Mount - Tilting

**Product ID:** FPWTLTBAT

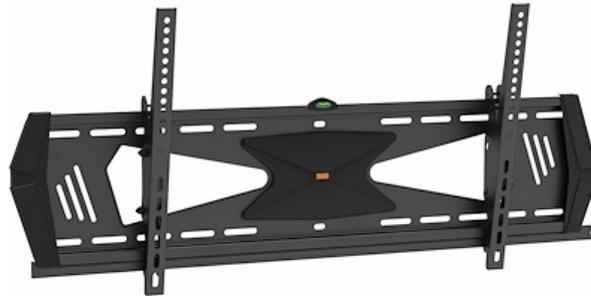

Save space while improving the appearance of your work area, with this low-profile TV wall mount. The mount sits close to the wall to support a VESA Mount compliant TV from 37" to 75", and offers theft deterrence as well as tilting capability that makes it easy to find the perfect viewing position.

Mount your flat-screen TV or monitor in a location that's convenient for visitors, clients or employees. The wall mount safely and securely supports your TV about two inches (51 mm) from the wall to provide a sleek, low-profile look.

It's ideal for lobbies, hallways, boardrooms, works areas, customer-facing areas or for creating digital signage. The wall mount supports most 37" to 75" (940 to 1905 mm) LED or LCD flat panel TVs weighing up to 88 lb. (40 kg).

This TV wall mount tilts -10 to +5 degrees, so you can adjust the angle of your display with ease to customize your viewing experience.

Engineered with heavy-duty steel, the robust steel TV wall mount securely supports your flat-screen TV, to protect your investment. Ideal for areas with high traffic and minimal supervision, the TV mount features a steel bar that can be locked into place with a padlock (purchased separately) to deter theft of your equipment.

A built-in level helps to ensure your TV is aligned in a straight position on your wall, to ensure optimum viewing.

The FPWTLTBAT is backed by a StarTech.com 5-year warranty and free lifetime technical support.

## Certifications, Reports and Compatibility



## Applications

- Securely wall-mount a TV
- Keep guests informed and entertained
- Ideal for classrooms, lecture halls or customer-facing areas
- Deter theft of your TV or monitor

## Features

- Save space with this flat-screen TV wall mount for 37" to 75" TVs (fits curved TVs, with compatible VESA mount)
- Low profile TV mount sits only 2" (51 mm) from the wall; Tilts -10 to +5 degrees for optimal viewing
- Lockable bar securely holds TV and provides theft deterrence (padlock required)
- Heavy-duty steel TV wall mount (tool-less assembly) supports up to 88 lb. (40 kg)
- Universal LCD/LED television mount supports LG, Samsung, Sony, Sharp, others (screws/spacers incl) & VESA bracket hole patterns 300x200, 300x300, 400x200, 400x300, 400x400, 600x200, 600x300, 600x400, 800x400

---

## Hardware

Warranty	5 Years
Cable Management	No
Articulating	No
# of Displays Supported	1
Mounting Options	Wall-Mount
Minimum Profile from Wall	2.0 in [51 mm]
VESA Hole Pattern(s)	400x400 mm
	400x300 mm
	400x200 mm
	300x300 mm
	300x200 mm
	600X200 mm
	600x300 mm

600x400 mm

800x400 mm

---

**Performance**

Weight Capacity (Per Display)	88.2 lb [40 kg]
Minimum Display Size	37"
Maximum Display Size	75"
Fits Curved Display	Yes
Video Wall	No
Anti-theft	Yes

---

**Physical Characteristics**

Material	Steel
Product Length	39.3 in [99.8 cm]
Product Width	2.0 in [5.1 cm]
Product Height	17.3 in [44.0 cm]
Weight of Product	8.1 lb [3.7 kg]

---

**Packaging Information**

Package Quantity	1
Package Length	38.8 in [98.5 cm]
Package Width	9.2 in [23.4 cm]
Package Height	2.6 in [6.6 cm]
Shipping (Package) Weight	10.3 lb [4.7 kg]

---

**What's in the Box**

Included in Package	1 - wall mount
	1 - safety bar
	1 - left adapter bracket

- 1 - right adapter bracket
- 1 - level
- 2 - decorative covers
- 4 - decorative cover screws
- 4 - M5x14 mm screws
- 4 - M6x14 mm screws
- 4 - M8x50 mm screws
- 4 - M6x30 mm screws
- 4 - M8x30 mm screws
- 4 - rectangular washers
- 8 - small spacers
- 8 - large spacers
- 6 - screws
- 6 - concrete anchors
- 6 - circular washers
- 1 - instruction manual

---

***\*Product appearance and specifications are subject to change without notice.***