


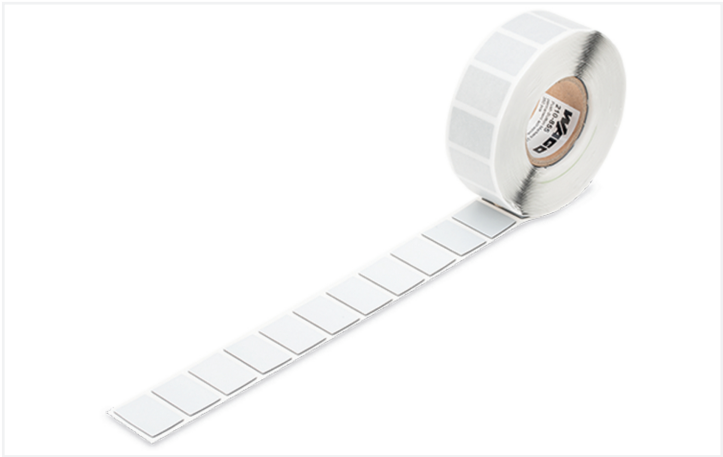

Color: silver-colored

Technical data	
Suitable	without button frame
Marking method	Thermal transfer
Marking	plain
Delivery form	Roll
Delivery form configuration	350 markers/reel; 1 line
Printing device	Smart Printer (thermal transfer printer)

Physical data	
Height	27 mm
Width	18 mm
Depth	0.65 mm
Marking surface	27 x 18 mm

Mechanical data	
Mounting type	Sticking
Smear resistance	in conjunction with 258-5005 Ink Ribbon

Material data	
Color	silver-colored
Material	Polyester
UV resistance	EN 60068-2-5:2010 Procedure B
Adhesive information	Acrylic; permanent
Halogen-free	Yes
Weight	139 g
Fire load	0 MJ



Environmental requirements		
Ambient temperature (storage)		≥+22 °C
Ambient temperature (operation)		-30 ... +130 °C
Relative humidity		40 ... 50 %

Commercial data		
Product Group		2 (Terminal Block Accessories)
eCl@ss 10.0		27-40-06-29
eCl@ss 9.0		27-40-06-29
ETIM 8.0		EC001288
ETIM 7.0		EC001288
PU (SPU)		1 pcs
Packaging type		Box
Country of origin		DE
GTIN		4050821674948
Customs tariff number		39199080888

Environmental Product Compliance		
RoHS Compliance Status		Compliant,No Exemption

Downloads

Environmental Product Compliance

Compliance Search		
Environmental Product Compliance 210-855		

Documentation

Operating Instructions			
210-852 Information on handling print material	1 28.08.2020	pdf 1004.72 KB	

1 Compatible Products

1.1 Optional Accessories

1.1.1 Marking

1.1.1.1 Frame



Item No.: 210-853
Universal push-button border; halogen-free; black

1.1.1.2 Marking device



Item No.: 258-5000

Thermal transfer printer; Smart Printer; for complete control cabinet marking; 300 dpi; With marking material