

DATA SHEET

40W LED RECHARGEABLE POWER LIGHT



JCB-PLT40 Technical Specification

Input Voltage: 100-240V, 50Hz

Power: 40W

Material: Iron Stand, Aluminium Alloy & Rubber Coating Head, PC Lens, 4mm Tempered Glass

LED: 4 x 1616 COB Chip

CRI: 70Ra

Power Factor: 0.9

Colour Temperature: 6500K

IK Rating: IK09

Life Expectancy: 20,000 hrs

Working Temperature: -10°C - 40°C

Battery: 2 x 22.2V 4.4Ah

Charge Time: 3-4 hours / battery

Function: 100% - 50% - Off


PCB Protection: Charging Protection / Discharging Protection / High Temperature Protection (70°C)

Battery Indicator: 5 Level Indicator - Green/Green/Green/Amber/Red

Dimensions: L234 x W178 x H284mm

Charger: 25.2V, 2A

Weight: 3.9Kg

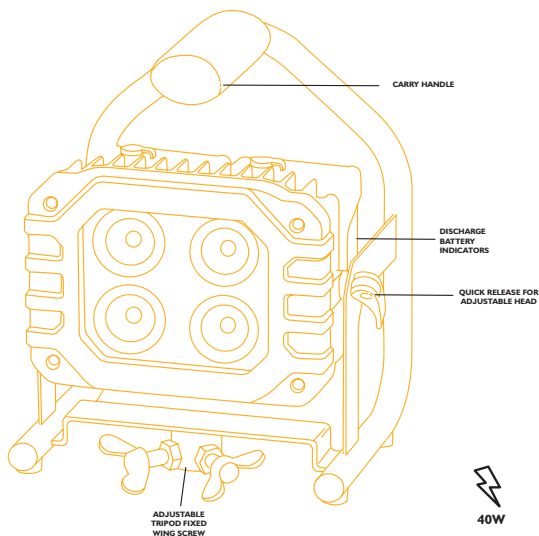

40W



4000
LUMENS



60°
BEAM ANGLE



IP65



3-3.5/6-7 HRS
RUN TIME
1/2 BATTERIES



T. 0800 292 2188
E. sales@jcb-lighting.com

JCB Lighting is used under licence by Property Perspective Ltd

Version 1. 11/2019

