

Delivery specification:

Counter complete with push-on connectors


Accessories:

- Socket box 946.1
- Sealing cover K2
- Front frame F2B

Order information:

- Art-No.
- If special voltages ... are requested, please state exact counter type, voltage and model e.g. BVa 15.31, 12 V DC...


Type BVa 15.01

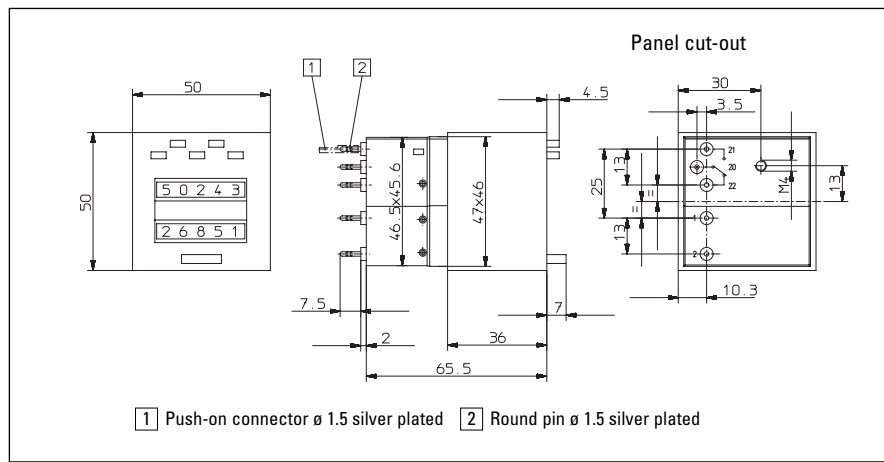

	BVa 15.01			BVa 15.01/3		
	24 V Art-No.	115 V Art-No.	230 V Art-No.	24 V Art-No.	115 V Art-No.	230 V Art-No.
DC (25 Imp/s)	2.100.011.033	-	-	2.120.011.033	2.120.011.064	2.120.011.066
AC (18 Imp/s)	2.100.011.061	2.100.011.064	2.100.011.066	2.120.011.061	2.120.011.064	2.120.011.066

Colour of housing black:
Art-No. 2.1X0.011.XXX


Type BVa 15.11

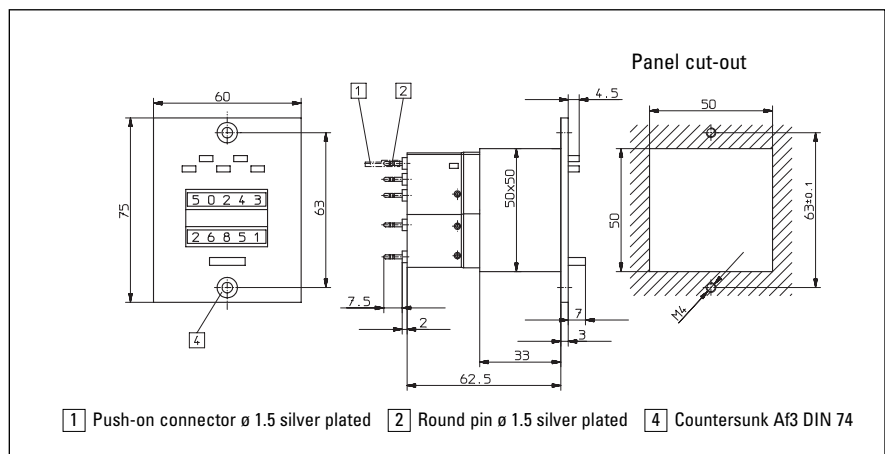

	BVa 15.11			BVa 15.11/3		
	24 V Art-No.	115 V Art-No.	230 V Art-No.	24 V Art-No.	115 V Art-No.	230 V Art-No.
DC (25 Imp/s)	2.100.110.033	-	-	2.120.110.033	2.120.110.064	2.120.110.066
AC (18 Imp/s)	2.100.110.061	2.100.110.064	2.100.110.066	2.120.110.061	2.120.110.064	2.120.110.066


Colour of housing black:
Art-No. 2.1X0.111.XXX

Type BVa 15.21

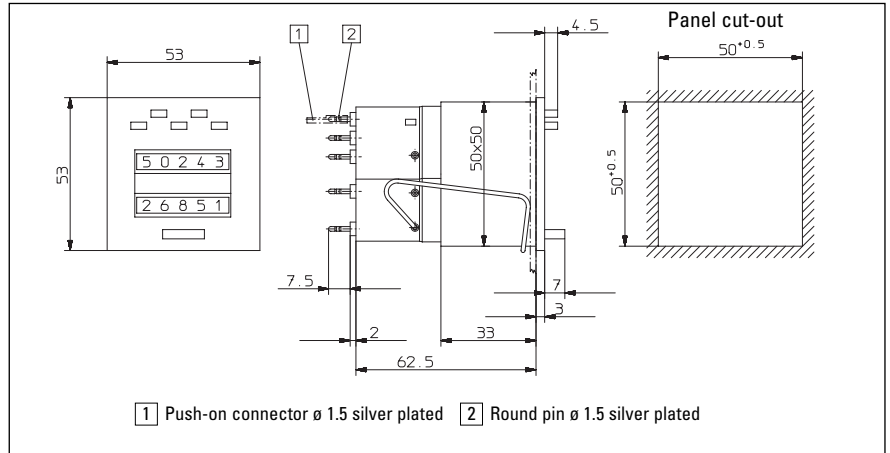

	BVa 15.21			BVa 15.21/3			Colour of housing black: Art.-No. 2.1X0.211.XXX
	24 V Art-No.	115 V Art-No.	230 V Art-No.	24 V Art-No.	115 V Art-No.	230 V Art-No.	
DC (25 Imp/s)	2.100.210.033	—	—	2.120.012.033	2.120.210.064	2.120.210.066	
AC (18 Imp/s)	2.100.210.061	2.100.210.064	2.100.210.066	2.120.210.061	2.120.210.064	2.120.210.066	

Type BVa 15.31

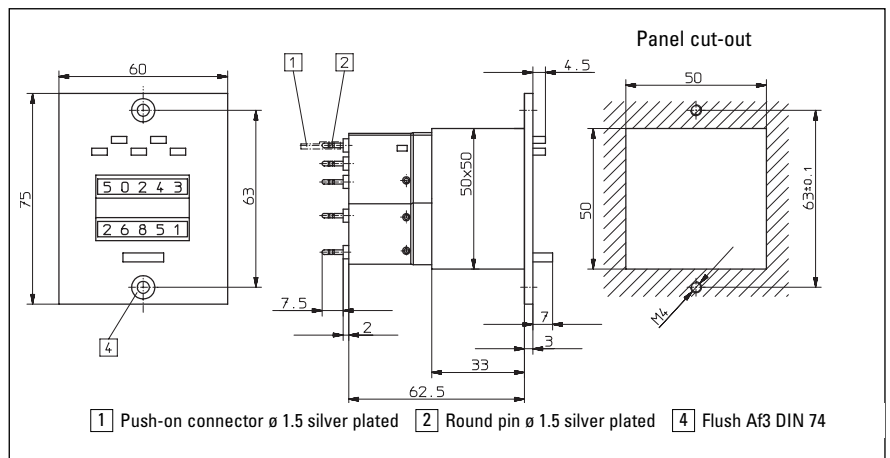

	BVa 15.11			BVa 15.11/3			Colour of housing black: Art.-No. 2.1X0.311.XXX
	24 V Art-No.	115 V Art-No.	230 V Art-No.	24 V Art-No.	115 V Art-No.	230 V Art-No.	
DC (25 Imp/s)	2.100.310.033	—	—	2.120.110.033	2.120.310.064	2.120.310.066	
AC (18 Imp/s)	2.100.310.061	2.100.310.064	2.100.310.066	2.120.310.061	2.120.310.064	2.120.310.066	

Options:

Key-locking 0-reset

Colour of housing grey: Art-No. 2.1X0XX6.XXX

Colour of housing black: Art-No. 2.1X0.XX7.XXX

Knob-locking transparent cover (IP55)

Counter with front plate size 3

Art-No. 2.1X0.8XX.XXX

Flexible sealing cover K2 (IP 54)

Counter with front plate size 3

Art-No. 2.1X0.6XX.XXX