


PXP0036/2M00 Datasheet

Product Name // IP67 Sealed HDMI Cable 2m

 [View Product Page](#)

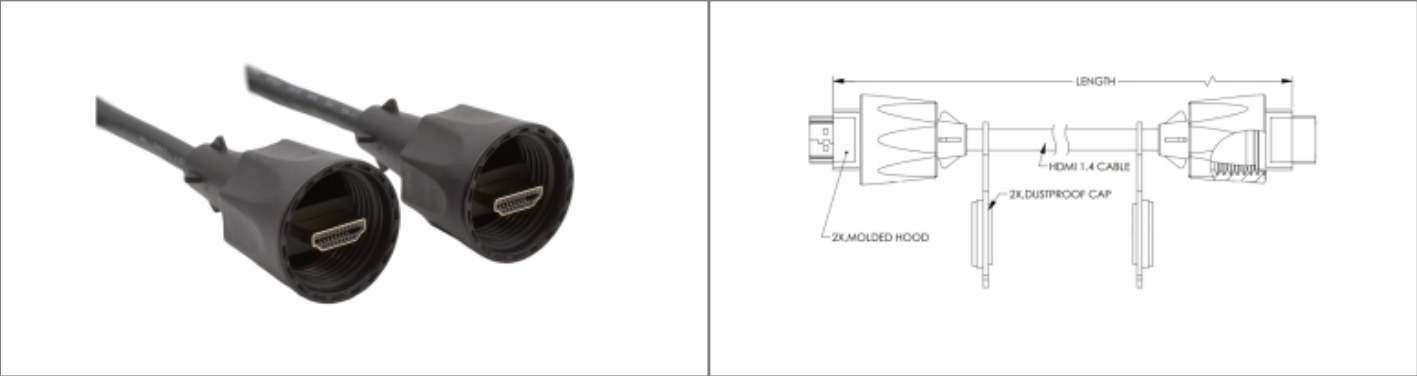

// Product Description:

- IP67 Sealed HDMI Cable 2m
 - Attached dust cap on each end of the cable
 - Threaded coupling Rated to IP67
- Gold plated Contact ensures reliable and repeated connections
 - PVC molded durable backshells
 - Length 2M

// General Information:

Product Display Title:	Double Ended Cable Assembly
Product Family:	Circular Data Connectors
Product Series:	30 Series HDMI
Body Colour:	Black
Body Material:	PVC
Body Material Type:	Plastic Body
Cable Length:	2m
Contact Pin Material:	Brass, Gold plated
Contact Type:	Plug Contact
Coupling Type:	Screw
Data Cable Type:	HDMI 1.4 to HDMI 1.4 Plug Sealed Cable Assembly
Diameter Over Coupling Ring Mm:	37.87mm
Dielectric Withstanding Voltage:	300V DC 0.1S
Durability:	1000
Flamability Rating:	UL94V-0
Function:	Double Ended Cable Assembly
Insulation Resistance:	20MΩ MIN
Ip Rating:	IP67
Max Operating Temperature:	85°C
Min Operating Temperature:	-24°C
Number Of Contacts:	19 Contacts
Rohs Compliant:	Yes
Sheath Colour:	Black
Sheath Material:	PVC
Thread Size:	3/4"-14 mating
Voltage Max:	5.3

// Product PDF Links

 [30 Series Waterproof HDMI...](#)

// Product 3D CAD Model Links

 [PXP0036/2M003D CAD Model](#)



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)