


Revision No. 变更数	Revisions 变更事项	Changed 修改者	Date 日期	Approved 确认者	Date 日期
①	Drawing update	Lance. Lv	2019-01-15	Kevin. Tang	2019-01-15

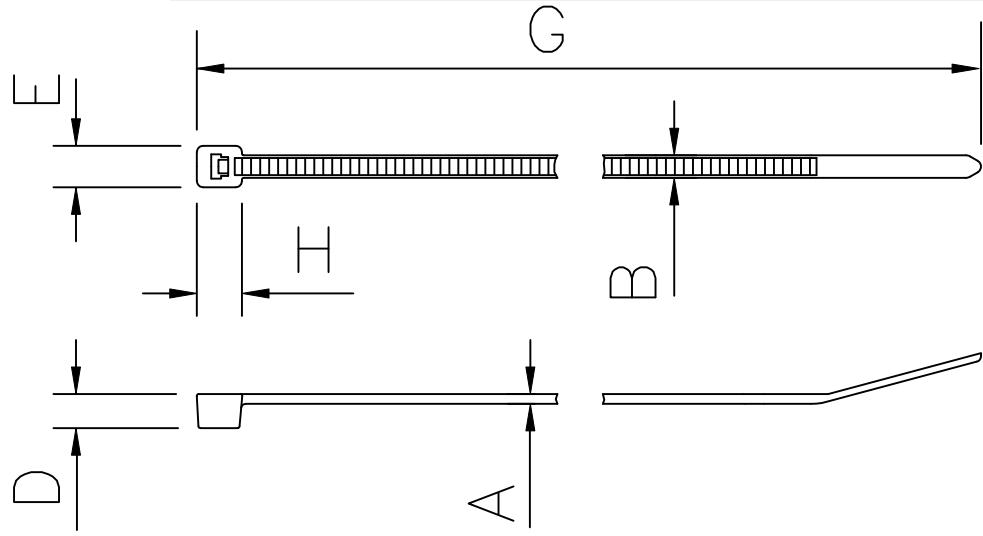

Part Type 型号	Material 材料	Color 颜色	Continuous Operation Temperature/适用温度范围	Flame Rating 耐燃性	A	B	D	E	G	H
T50I	尼龙66 (聚酰胺66) 66 Nylon (Polyamid 66)	Milky White/乳白色	-40℃~+85℃	UL94V-2	1.2±0.2	4.6±0.2	5.8±0.3	7.8±0.3	305.0±5	7.0±0.6
T50I-B	尼龙66 (聚酰胺66) 66 Nylon (Polyamid 66)	Black/黑色	-40℃~+85℃							
T50I-W	尼龙66 (聚酰胺66) 耐候型 66 Nylon (Polyamid 66)	Black/黑色	-40℃~+85℃							
T50I-HS	尼龙66 (聚酰胺66) 耐热型 66 Nylon (Polyamid 66)	Light Green/浅绿色	-40℃~+105℃							
T50I-HSB	尼龙66 (聚酰胺66) 耐热型 66 Nylon (Polyamid 66)	Black/黑色	-40℃~+105℃							
T50I-HSW	尼龙66 (聚酰胺66) 耐热, 耐候型 66 Nylon (Polyamid 66)	Black/黑色	-40℃~+105℃							
T50I-HR	尼龙46 (聚酰胺46) 耐热型 46 Nylon (Polyamid 46)	Biege/棕黄色	-40℃~+150℃							
T50I-PA11	尼龙11 (聚酰胺11) 11 Nylon (Polyamid 11)	Black/黑色	-30℃~+50℃	UL94V-0						
T50I-V0	尼龙66 (聚酰胺66) 难燃型 66 Nylon (Polyamid 66)	White/白色	-40℃~+85℃							

适用绑扎工具
Applicable Tool
EVO7

UL 编号
UL File-No. E193818

Standard Packing
标准包装
100根/袋, 50袋
(共5000根)/箱
100 Pcs/bag, 50 bags
(Total 5000Pcs)/box

Min. Loop Tensile Strength
最小环形拉断力
225N

Bundle Diameter
捆扎直径 ①
1.5 to 80.0mm

Dimension Units/尺寸单位
mm

PERFORMANCE / 性能
SPECIFICATION / 标准

CAD

the copyright of this drawing is reserved by HELLERMANNTYTON. it is issued on condition that it is not reproduced, copied or disclosed to a third party, either wholly or in part, without the consent of HELLERMANNTYTON.

Drawn/制图 Lance. Lv 26/Feb/2016
Approved/审核 Roger. Chang 17/Mar/2016

HellermannTyton
海尔曼太通 (无锡) 电器配件有限公司
(WUXI) Electrical Accessories Co., Ltd.
Tel: +86-510-85282536
Fax: +86-510-85280112

Scale/比例 NO / 无

Title/品名
T50I Series

Drawing-No/图号
10-0871-001-CSC

Format/格式
A4