




Philips
Micro Music System

Internet radio, DAB+

Bluetooth, Spotify Connect
USB, MP3-CD
50 W

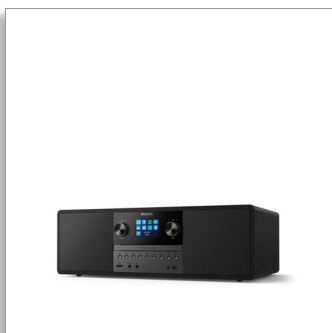

TAM6805

All in one

With Internet radio, Spotify Connect, Bluetooth and a CD player, this compact all-in-one micro system can play it all. You can also connect other sources via audio-in or USB. Enjoy richer sound from a system that fits into almost any room.

Rich sound for your music

- 2 x 3" full-range drivers. 50 W maximum output power
- Compact all-in-one micro system
- Integrated bass-reflex speaker system
- Digital Sound Control. Choose a preset sound style

Fill the room with tunes

- AC-powered. Remote control
- At home in your home
- Main unit dimensions: 420 x 262 x 140 mm

More to love

- All your music, podcasts and more
- Internet radio. DAB+ FM radio
- Spotify Connect. Bluetooth. Audio-in. CD player
- USB port. Connect a legacy source or charge a mobile
- Classic looks. Modern functions

PHILIPS

Highlights

All your music



From classic tunes to the latest podcasts. You can stream Spotify's best-quality signal over Wi-Fi with Spotify Connect. You can also stream playlists and more via Bluetooth, play CDs or connect to other sources via audio-in or USB.

Internet radio, DAB+ FM



Internet radio is your ticket to thousands of global stations broadcasting every conceivable

kind of programme. The digital tuner delivers crystal-clear reception and you can set presets for your favourite internet, DAB+ or FM stations.

Rich sound for your music



Two speakers are built right into the cabinet of this all-in-one micro system. You get clear sound and good bass from the full-range drivers and bass-reflex ports. The 50 W maximum output is perfect for kitchens, offices and smaller living areas.

Classic looks

The wooden cabinet and integrated speakers recall the design of retro hi-fi separates. A clear colour display shows the source or station, as well as album art and song

information. Textured dials control volume, source selection and tuning.

Digital Sound Control

Hip-hop or choral, symphony or rock opera? Whatever you love, this micro system's Digital Sound Control function lets you enjoy it more. Pick from preset sound styles designed to bring out the best in your music.

At home in your home

This AC-powered micro system looks great in any room. Bluetooth wireless range is 10 m and you can charge a smart device via the USB port. An easy-to-use remote puts key functions at your fingertips.

Specifications

Sound

- Sound enhancement: digital sound control, bass reflex speaker system
- Volume control: rotary
- Frequency response: 50-20000 Hz, ± 3 dB
- Sound mode: Powerful, Clear, Bright, Warm, Balanced
- Maximum output power (RMS): 50 W
- Speaker impedance: 6 ohm

Loudspeakers

- Full-range driver diameter: 3"
- Number of full-range drivers: 2
- Driver configuration: Full range
- Number of sound channels: 2.0

Connectivity

- USB: USB host, Max. 2 A Charging
- Bluetooth version: 4.2
- Bluetooth profiles: A2DP, AVRCP
- Bluetooth range: 10 M (free space)
- Headphone jack: 1 x 3.5 mm
- Audio in: 3.5 mm
- Wi-Fi: 802.11 a/b/g/n
- DLNA Standard: n.a.
- Smart Home: Spotify Connect

Audio playback

- Disc playback modes: fast forward/reverse, next/previous track search, repeat/shuffle/programme
- Playback media: CD, CD-R/RW, MP3-CD, USB flash drive
- USB Direct playback modes: fast reverse/fast forward, play/pause, previous/next, repeat, shuffle, stop
- Audio supported formats: MP3
- Max sample rate: 24-bit/44.1 kHz

Tuner/Reception/Transmission

- Antenna: Detachable pigtail (75 ohm)
- Tuner bands: FM, DAB/DAB+, Internet Radio
- Station presets: 20 FM, 20 DAB, 40 Internet radio/Podcasts, 10 Spotify

- RDS: Yes.
- Tuner type: Digital

Convenience

- Clock: On main display, 24/12-hour display
- Remote Control
- Loader type: tray
- Sleep timer
- Display screen type: 2.4" TFT
- Clock update: DAB/Internet radio
- No. of alarms: 2
- Alarms: Yes, Buzzer, Internet radio, DAB, FM

Compatibility

- Smartphone/tablet APP control: No

Power

- Power supply: 100-240 VAC, 50/60 Hz

Packaging dimensions

- Height: 21.6 cm
- Packaging type: Box
- Type of shelf placement: Standing
- Width: 49.2 cm
- Depth: 33.8 cm
- Number of products included: 1
- EAN: 48 95229 10984 1
- Gross weight: 6.07 kg
- Net weight: 4.7 kg
- Tare weight: 1.37 kg

Accessories

- Included accessories: AC power cord (x2), FM antenna, Remote Control, 2 x AAA Batteries, Quick start guide, Warranty Leaflet
- Power cord: Length: 1.5 m

Design

- Wall mountable: No
- System components: Main unit

Dimensions

- Main Unit (W x H x D): 420 x 140 x 262 mm
- Main Unit Weight: 4.43 kg



Issue date 2024-05-29

Version: 10.10.3

EAN: 48 95229 10984 1

© 2024 Koninklijke Philips N.V.
All Rights reserved.

Specifications are subject to change without notice.
Trademarks are the property of Koninklijke Philips N.V.
or their respective owners.

www.philips.com