


Allthread Studding – Course thread

Description

Din 975 Grade A2 (18/8) Stainless Steel fully threaded screwed rod. Can be cut to length on site. Corrosion resistant under normal atmospheric conditions.

Allthread Studding – Course thread

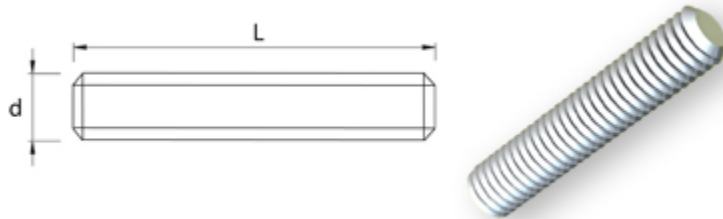

Materials and Finishes

A2 Stainless Steel

Preferred Lengths

		Length (L) m	
		1 Metre	3 Metre
Thread (d) mm	M3	A2	
	M4	A2	
	M5	A2	
	M6	A2	A2
	M8	A2	A2
	M10	A2	A2
	M12	A2	
	M16	A2	
	M20	A2	
	M24	A2	
	M30	A2	
	M36	A2	
	M42	A2	

A2 Stainless Steel

All data is correct to the best of our knowledge, however TR cannot be held responsible for any errors or omissions