


Technical data sheet

Article number:
151-04088

QGDHC5.2-8.0M

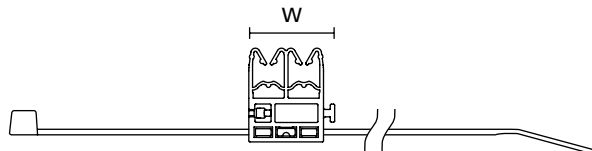

Product Group	Fixings elements for parallel routing
Product Family	with connecting element
Material	Polyamide 6.6, UV-resistant (PA66W)
Colour	Black (BK)
Bundle Diameter max (metric)	8.0 mm
Bundle Ø min.	5.2 mm
Fixation Method	Cable Tie
Height (H)	25.1 mm
Operating Temperature	-40 °C to +85 °C
Package Content packed in	bag
Pack Cont.	50 pcs.
ROHS compliant	Yes
Thickness (T)	12 mm
Width (W)	23 mm

HF ✓ RoHS ✓