

## AH25

### Active Weatherproof Horn Speaker

Item ref: 952.102UK



User Manual



Caution: Please read this manual carefully before operating  
Damage caused by misuse is not covered by the warranty

The AH25 horn speaker is a robust, weatherproof horn with a built-in amplifier and can be installed indoors or outdoors onto a wall or other surface from its adjustable mounting bracket.

Follow the wiring guide below for power and signal connections to the 4-core cable (connections should be sealed or sheltered from the elements)

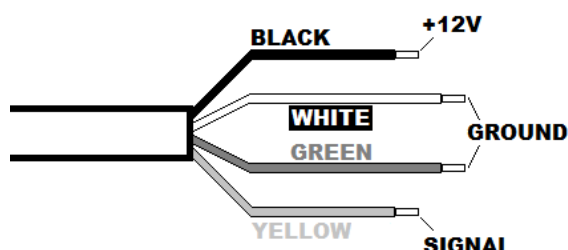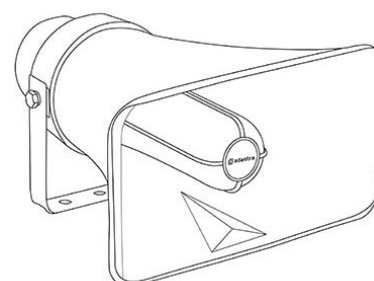

The amplifier can be operated from any 12Vdc power supply capable of delivering up to 2.1A current.

Connect +12V to the black wire and connect the Ground to the white wire

Connect the Line Level Audio (0dB = 0.775Vrms) input to the yellow wire and Ground to the green wire (signal & power ground are common)

### Specifications

If you connect the power with no signal you may get a buzz or interference, to prevent this, it is necessary to shield the yellow wire (insulation tape).

Power supply	12Vdc, 2.1A (not included)
Construction	ABS moulded body, metal bracket
Connection	Hard-wired cable (power + line in)
Output power : max.	25W
IP rating	IP66
Dimensions	295 x 265 x 25mm
Weight	2.05kg



**Disposal:** The "Crossed Wheelie Bin" symbol on the product means that the product is classed as Electrical or Electronic equipment and should not be disposed with other household or commercial waste at the end of its useful life. The goods must be disposed of according to your local council guidelines.

*Errors and omissions excepted.  
copyright© 2018. AVSL Group Ltd.*