

8MP Single Channel Split Joint HD RJ45 Video Balun Adapter Video Balun With Power

BNC-LAN-P-8MP

4K/8MP



- HD CVI/TVI/AHD/CVBS transmissidn
- Multiple can be used in combination
- Male BNC with extended 140mm mini-coax pigtail
- Reliable push-pin terminal block connection for UTP cable
- Built-in solid state TVS (Transient Voltage Suppressor) for surge protection
- Wave Filter Design, Anti-Static Design
- Lightning protection design Grade: III
- 60 dB crosstalk and noise immunity
- Exceptional interference rejection
- ABS engineering plastic housing


Connectable design for neat installation



Installation Step:



Application Diagram

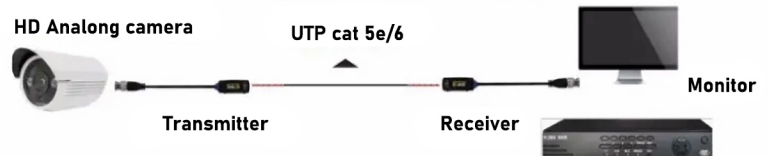

TRANSMISSION MAX DISTANCE

	720P	1080P	4MP	5MP	6MP	4K
HDCVI	720P	1080P	4MP	5MP	6MP	4K
COLOR VIDEO	400M	300M	250M	250M	200M	200M
HDCVI	720P	1080P	3MP	5MP	8MP	
COLOR VIDEO	200M	200M	180M	150M	150M	
AHD	720P	960P	1080P	3MP	4MP	5MP
COLOR VIDEO	400M	400M	300M	300M	250M	250M

COLOR VIDEO MAC UP TO 400M FOR CVBS CAMERA