



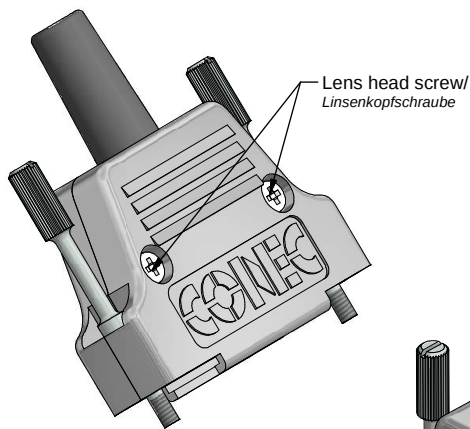

Lens head screw/
Linsenkopfschraube

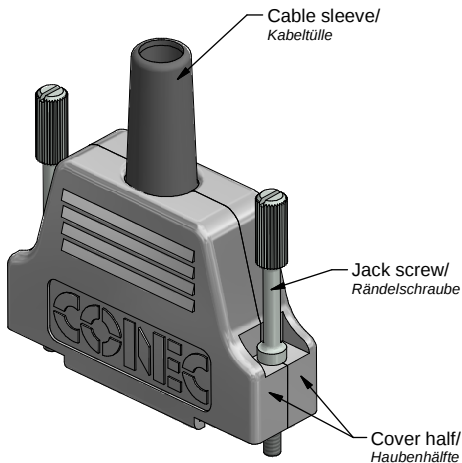

Cable sleeve/
Kabeltülle

Jack screw/
Rändelschraube

Cover half/
Haubenhälfte

b) Technical specification:

Technische Daten:


Temperature range/ - 35 °C ... + 90 °C
Temperaturbereich:

Materials/ Werkstoffe:

 
Cover half/ GD-Zn, Ni
Haubenhälfte:
Cable strain relief/ Steel, Ni
Kabel Zugentlastung:
Cable sleeve/ Rubber
Kabeltülle:
Jack screw/ Steel, Ni
Rändelschraube:
Lens head screw/ Steel, Ni
Linsenkopfschraube:

Installation specification/ Montagedaten:

Cable outlet/ straight/ gerade
Kabelausgang:

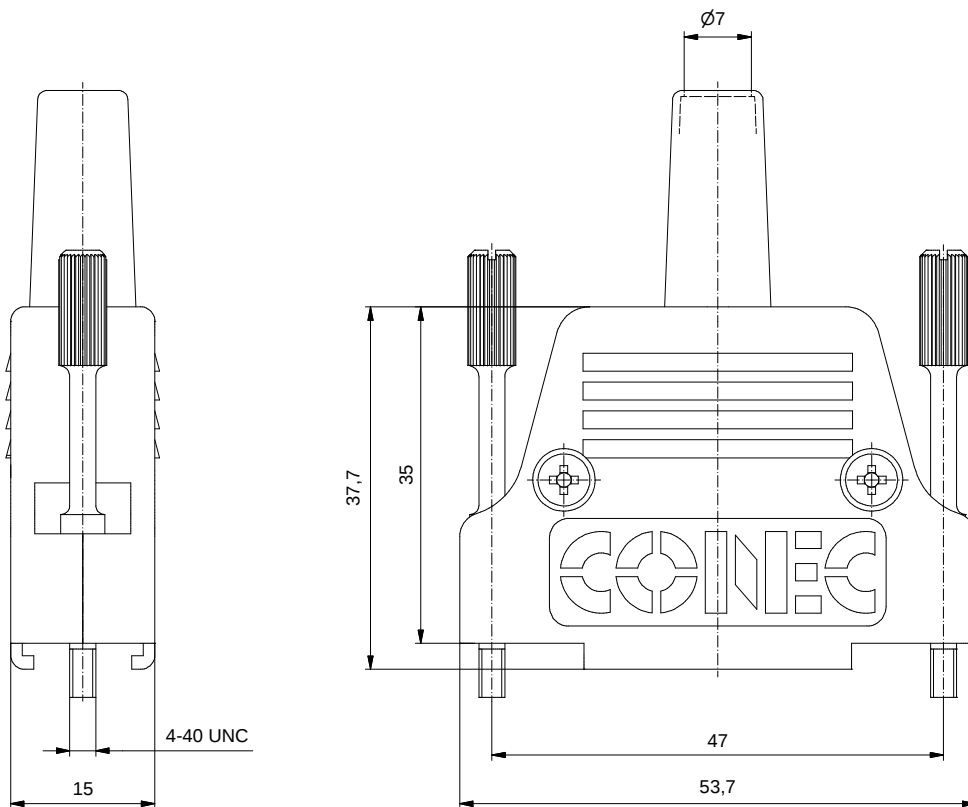

Part no./ Art.-Nr.	
165X17329X	Bulk package/ Massenverpackung
165X17329XE	Single package/ Einzelverpackung

				dim. in mm		Full metal hood 25pos. with straight cable exit Vollmetallhaube 25pol. mit gradem Kabelausgang	
		drawn/ gez.	Date/Datum	Name			
		appd./ gepr.	16.04.2018	Unkrüer			
			17.04.2018	Schmidt			
Index: b Ä7223 16.04.18 L.U.	scale/Maßstab: 2:1			dwg no / Z.-nr.:		16K1A4048	DIN- A3
Status: InBearbeitung							
RoHS compliant/ konform							1 / 1