



Trust Gaming GXT 759P XXL Gaming Mousepad - Purple

XXL Gaming mousepad with stitched edges for smooth and sturdy gameplay

Article number: 25614
Barcode: 8713439256147
GTIN: 08713439256147

Core content

Brand	Trust Gaming
Product type	XXL Gaming Mousepad
Colour	Purple
Key features	- XXL 900x400mm gaming mousepad with enough room for your keyboard and mouse - Stitched edges adds a touch of class and increases longevity without fraying - Optimised surface texture for optimal mouse accuracy and smooth control - Rubberised anti-skid bottom keeps the mousepad in place even during the most intense gameplay - Easy to clean material allows you to easily free of dust and dirt under running water
Package contents	- XXL mousepad

Marketing

Extended retailer text	I need space With a whopping XXL size, this mousepad is large and in charge. Boasting an impressive 900x400mm surface area, you'll have plenty of room for your mouse and keyboard so you can enjoy a full range of movement. In stitches Cool and convenient, this mousepad comes with stitched edges for a touch of class and extra longevity without fraying. What's more, its optimised surface texture, designed to provide optimal accuracy and smooth control, makes sure nothing gets in the way of your next win. Ready, steady, go!
------------------------	--

You’ve got a desk, not an ice rink, so this mousepad, complete with a rubberised anti-skid bottom, makes sure there’s no slipping and sliding going on whilst you game. Mousepad need a refresh? The easy-to-clean material allows you to easily get rid of dust and dirt simply by running it under water.

Specifications

Total weight	665 g
Weight of main unit	665 g
Height of main product (in mm)	3 mm
Width of main product (in mm)	900 mm
Depth of main product (in mm)	400 mm
Shape	rectangle
Anti-skid	Yes
Edges	Stitched
Roll-up	Yes
Two-sided	No
Wrist support	No
Size (XS-XXXL)	XXL
Designed for gaming	Yes
Backlight	No
Material topside	PET

Surface	soft
Supported sensor type	laser optical

Main image

	25614_pictures_product_visual_1.tif ImageWidth: 5.000 px ImageHeight: 5.001 px ImageResolution: 300 dpi
--	---


Additional Product Images

	25614_pictures_product_visual_2.tif ImageWidth: 5.000 px ImageHeight: 5.000 px ImageResolution: 300 dpi
	25614_pictures_product_top_2.tif ImageWidth: 5.000 px ImageHeight: 5.000 px ImageResolution: 300 dpi
	25614_pictures_product_top_3.tif ImageWidth: 5.000 px ImageHeight: 5.000 px ImageResolution: 300 dpi
	25614_pictures_product_top_1.tif ImageWidth: 5.000 px ImageHeight: 5.000 px ImageResolution: 300 dpi

Product Pictorials



25614_EN_pictures_product_pictorial_1.tif
ImageWidth: 4.000 px
ImageHeight: 4.000 px
ImageResolution: 300 dpi

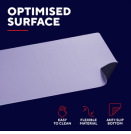

25614_EN_pictures_product_pictorial_2.tif
ImageWidth: 4.000 px
ImageHeight: 4.000 px
ImageResolution: 300 dpi



25614_EN_pictures_product_pictorial_3.tif
ImageWidth: 4.000 px
ImageHeight: 4.000 px
ImageResolution: 300 dpi

Package Images



25614_pictures_package_visual_1.tif
ImageWidth: 5.000 px
ImageHeight: 5.000 px
ImageResolution: 300 dpi



25614_pictures_package_front_1.tif
ImageWidth: 883 px
ImageHeight: 5.551 px
ImageResolution: 300 dpi