

# groovv▶▶e

## GV-BT1800 Fusion



## User Manual

**wireless** | AUDIO  
PLAYBACK **wired**

Wireless Headphones  
with Active Noise  
Cancelling





### **30 Day Right To Return**

We do not envisage any problems occurring with your Groov-e GV-BT1800 Fusion Wireless Active Noise Cancelling Headphones. However, for your peace of mind, should any fault occur, please return it within 30 days to your retailer with proof of purchase for an exchange or refund.



### **12 Month Guarantee**

This product is guaranteed for twelve months. Please retain your receipt as this will be required as proof of purchase in the event that the device does not perform as expected then please contact your original point of purchase, should you require further assistance then please contact us.



### **Extended Warranty**

Please register your product within 30 days from date of purchase [www.groov-e.co.uk/warranty](http://www.groov-e.co.uk/warranty). Proof of purchase required.



### **Contact Us**

Reach out to us at [info@groov-e.co.uk](mailto:info@groov-e.co.uk) or visit [www.groov-e.co.uk](http://www.groov-e.co.uk)

***"Congratulations on your purchase and Thank You for choosing the groov-e GV-BT1800 Fusion Wireless Headphones with Active Noise Cancelling. Please read the guide carefully before using".***


## **CAUTION**

- 1.** When not in use for a long period of time please turn off the headphones and store carefully to avoid any damage.
- 2.** In order to prolong the battery life, please charge every 6 months.
- 3.** Please charge the headphones first if it has been left unused for a long time.
- 4.** The battery in the headphones is original and please do not attempt to change it yourself.
- 5.** Please keep the headphones in a dry place.
- 6.** Please keep away from temperatures in excess of 60 C to avoid battery blast accident.
- 7.** Please don't bend or twist the headphones bracket to avoid deformation.
- 8.** Please do not remove the ear-cushions.
- 9.** Do not play at high volumes for long periods at a time. to avoid potential hearing damage.
- 10.** Do not use the headphones in a dangerous place or whilst driving.

## **OVERVIEW**

### **In the box:**


- 1x** GV-BT1800 Headphones
- 1x** USB-C Charging Cable
- 1x** Removable Audio Cable
- 1x** Manual

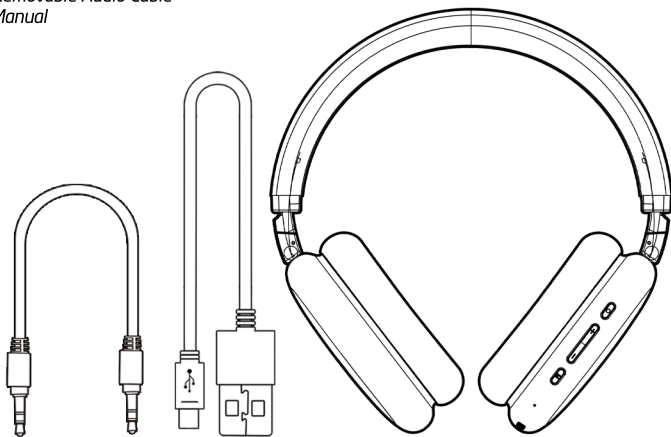

## OVERVIEW



- MFB**
- Power On/Off**
- Voice Assistant**
- Answer/Reject**
- Play/Pause**
- Volume+ / Next Track**
- Volume - / Previous Track**
- ANC On/Off**
- LED Indicator**

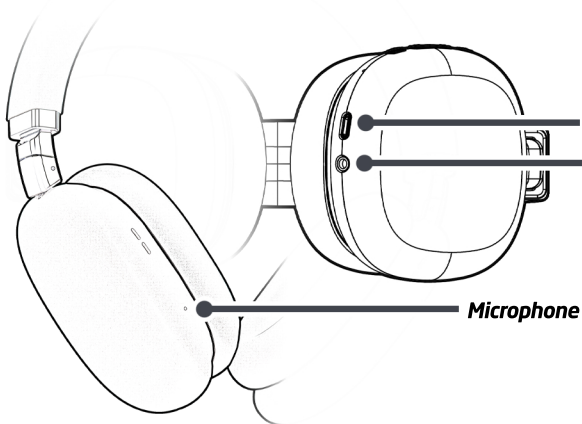

- USB-C**
- Charging Port**
- AUX Port**
- Microphone**



## OPERATION

### Charging the Headphones

The headphones come with a USB-C cable that can be connected to your computer or other device made for charging.



**1.** Plug the USB-C end of the included USB cable into the USB-C port under the right ear-cup of the headphones.

**2.** Plug the other end into a USB port on your computer or other devices made for USB charging.

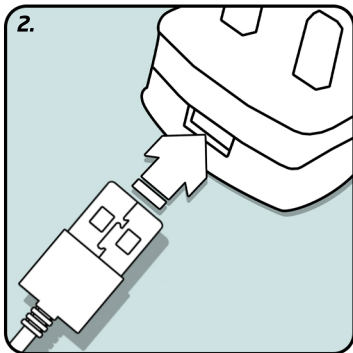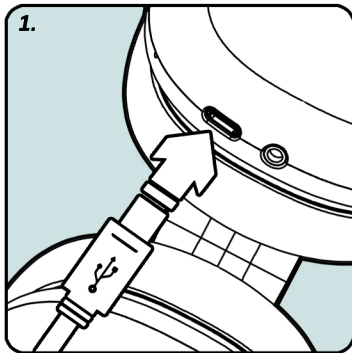

**3.** The indicator light will be red while charging.


**4.** Once fully charged the indicator light will go out.  
Charging time is about 3 hours on an empty battery.

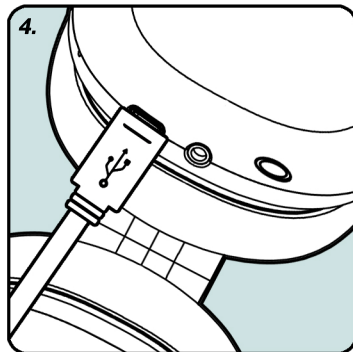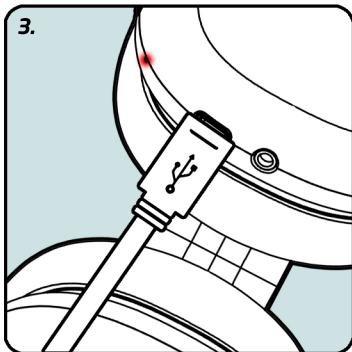


## OPERATION

### SWITCH ON/OFF BLUETOOTH

**1.** To switch on, press and hold the **MFB** for about 3 seconds. The headset enters Bluetooth searching mode, and the blue and red indicator light starts to flash.

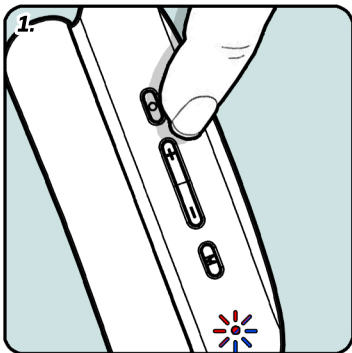


**2.** To switch off, press and hold the **MFB** for about 3 seconds, the red indicator light goes to flashing red then the light goes out.

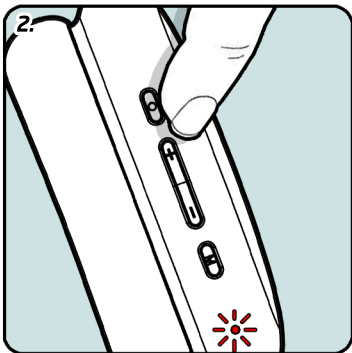


### PAIRING

Ensure that your phone or Bluetooth device you wish to pair is switched on.

**3.** To pair the headphones if it has not been previously paired with a device, firstly switch on the headphones using the **MFB**.

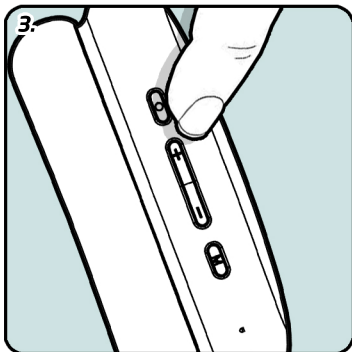

**4.** The headphones enter pairing mode, the LED indicator light will start to flash blue and red alternately.

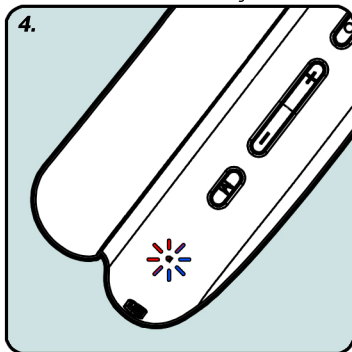

**Note:** To pair the headphones with a new device if it has previously been paired, ensure that the original paired device is switched off.


## OPERATION

### PAIRING


5. Activate the Bluetooth feature on your phone or Bluetooth devices, and set it to search for Bluetooth devices.



6. Select "GV-BT1800" from the list of found devices on your phone or Bluetooth devices, Bluetooth is connected once there is the "BLUETOOTH CONNECTED" prompt.

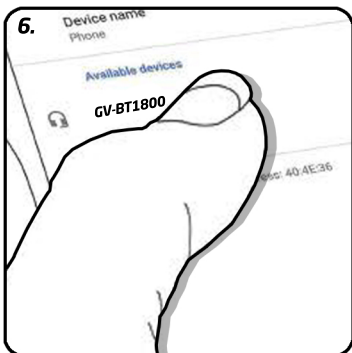

7. When successfully connected, and while playing music or paused, the blue light will flash slowly.

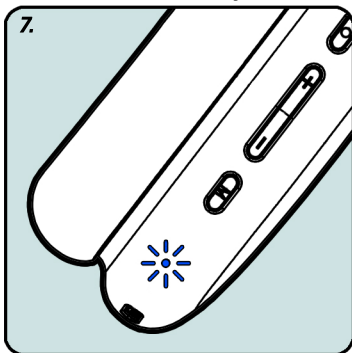

The headphones that have been previously paired with another device will automatically connect with the device if the device is powered on and within connecting range, if not, the headset will enter standby mode with a flashing red and blue light.

"GV-BT1800" can make and receive calls hands-free with your compatible mobile phone and listen to music from a compatible Bluetooth device, but they should be with 10 meters (33 feet) of each other.

## OPERATION

### VOLUME/NEXT TRACK

**1. During a call or while listening to music.**

**Volume Up:** Press the + Button

**Volume Down:** Press the - Button

**To select the next song:** During playback, long press the + button.



**To select the previous song:** Long press the - button.

**Note:** A "Volume Maximum" tone is heard when the volume reaches maximum level.

### CALLS/MUSIC

**2. To make a call:** use your mobile phone in the normal way when the headset is connected to it. During an incoming call, quickly press the **MFB** to answer it, or press and hold about 2 seconds to reject the call. During a call, short press **MFB** to end it.

**To Play Music:** To play or pause a music track press the **MFB** button.

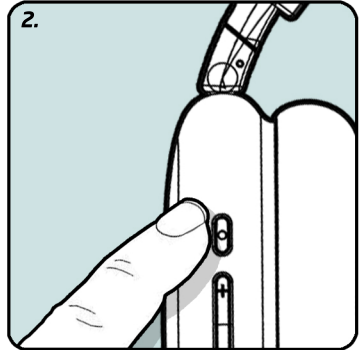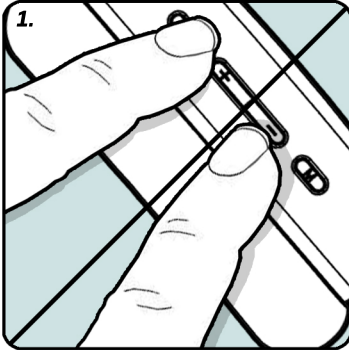



### VOICE ASSISTANT

To use voice assistant function, double press the **MFB** button to activate the assistant on your phone. This function is based on your phone support Siri/Google/Alexa.

### ACTIVE NOISE CANCELLING (ANC)

**Turn ANC On:** Long press the ANC Button with a "ANC On" prompt.

**Turn ANC Off:** Long press the ANC Button with a "ANC Off" prompt.

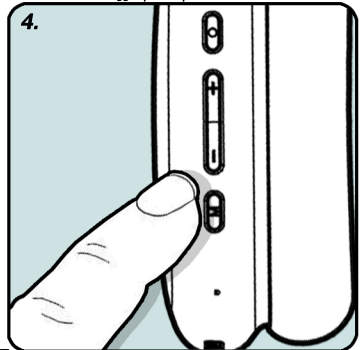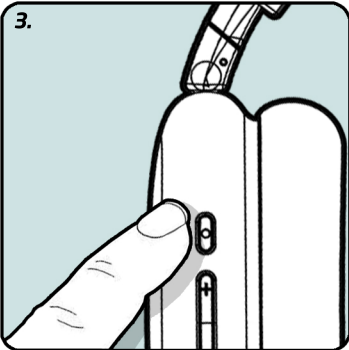




## OPERATION

### **PASSIVE MODE**

**1.** You can use the "GV-BT1800" as a wired headphone to save batteries.

Simply connect one end of the 3.5mm audio cable to the bottom of the Right ear-cup and the other end to your phone or audio device. Inserting the 3.5mm audio cable will disable the wireless functionality, so previous/next track, volume and phone call functions will be controlled on your device.

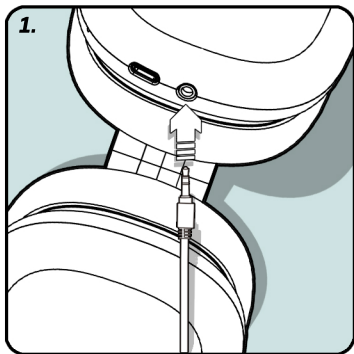

### **DISCONNECT THE HEADPHONES**

To disconnect the headphones from your device, switch off the headset, or disconnect it in Bluetooth menu of your device.

### **RECONNECT THE HEADPHONES**

To connect the headphones to the phone or Bluetooth devices that you have last used with it, switch on the headset, or make the connection in the Bluetooth menu of your device.

### **LOW BATTERY WARNING**

At power on condition, there will be a warning prompt "battery is low".

### **POWER OFF AT LOW BATTERY**

At power on condition, the headset will switch off automatically when the battery power drops below certain level.

## SPECIFICATIONS

Bluetooth version: V5.3  
Wireless range: 10M (open area)  
Battery: Lithium battery: 400mAh  
Music playing time: 32 hours @50% volume  
Charging time: 3 hours  
Standby time: 200 hours  
Driver unit: 40mm  
ANC: 20dB +/- 3dB  
Impedance: 32 ohms +/- 15%  
Speaker frequency: 20-20KHz  
Speaker sensitivity: 114dB +/- 3dB  
Microphone sensitivity: -38dB +/- 3dB  
Supports hands-free conversation  
LED battery indicator

## FEATURES

- 40mm Neodymium drivers for premium sound
- ANC (Active Noise Cancelling) technology blocks out external noise
- Bluetooth or Corded - both options for you to enjoy!
- 32 hours wireless music playback (Bluetooth)
- 3.5mm headphone jack for corded audio playback (non-Bluetooth)
- Voice assistant enabled
- Super bass
- Soft, on-ear cushions for long listening comfort
- Swivel ear cups
- Rechargeable battery
- Built-in mic for hands-free calls
- USB-C charging cable (included)
- Removable audio cable (included)



Active Noise Cancelling (ANC)



Wireless Audio Playback (32 hours)



Super Bass



Voice Assistant



Hands-Free Microphone



Folding Design



Removable Audio Cable

## BATTERY REMOVAL/DISPOSAL

*This product contains batteries and should not be treated as normal household waste and should be recycled. Please take it to your nearest collection facility or for further details contact your local council or visit [www.recycle-more.co.uk](http://www.recycle-more.co.uk)*

*Batteries contain substances that may be harmful to the environment and human health. Keep out of the reach of children and seek immediate medical help if swallowed. Never throw batteries into a fire or attempt to open the outer casing.*

*Should your product develop a fault and your battery needs replacing for further advice on how to safely remove your battery please visit our website at [www.groov-e.co.uk](http://www.groov-e.co.uk)*

### Environment Protection

*Waste electrical products should not be disposed of with household waste. Please recycle where facilities exist. Check with your Local Authority or retailer for recycling advice.*



## **GUARANTEE**

**Subject to the conditions stated below, Groov-e guarantees this equipment against defects in workmanship or materials of its mechanical and electronic component parts (excluding styling, battery cells, magnetic tapes, re-chargeable batteries, user removeable memory devices, with the exception where the battery is inbuilt into the product) for a period of one year from the date of purchase. This product will be repaired or if necessary replaced free of charge if it has been proven to be defective within the one year warranty period.**

**1)** Claims under this guarantee should be made through the authorised dealer/retailer from whom the equipment was purchased. If this is not possible, please contact Groov-e directly.

**2)** This guarantee is only valid when the equipment is purchased and retained within the United Kingdom and a valid proof of purchase has been provided.

**3) This Guarantee Excludes:**

**(i)** All damage caused through accident, misuse, wear and tear, neglect, installation and/or use in a manner inconsistent with technical and safety standards.

**(ii)** Alterations or adjustments made to equipment

**(iii)** Loss of data resultant from malfunction of hard drive or other storage device

**(iv)** Damage caused to any third party device as a result of using the product.

**4)** No liability under this guarantee shall be incurred:

**(i)** In respect of damage or loss occurring during transit to or from the purchaser

**(ii)** Where the serial number plate of the equipment has been removed or altered in any way.

**5)** Groov-e shall not be liable for consequential damage, loss or injury arising from or in connection with the equipment, excepting only that nothing in this condition shall or shall be construed so as to exclude or restrict liability for negligence.

**6)** The cost of carriage to and from Groov-e shall be borne by the purchaser.

**7)** This guarantee is personal to the original purchaser and is not transferable.

**8)** If the equipment, in respect of which a claim hereunder is made, is found on examination to comply with the published specifications, a test fee may be incurred.

**This guarantee is in addition to and does not in any way affect any statutory or other right of consumer purchasers, including those rights in relation to sections 13 to 15 of the Sale of Goods Act 1979, the Sale and Supply of Goods to Consumer Regulations 2002, The Consumer Rights Act 2015 or the Sale of Goods and Supply of Services Act 1980 (for ROI).**

## **DECLARATION OF CONFORMANCE**

*Groov-e hereby declares that this product is in compliance with the essential requirements and other relevant provisions of the Radio Equipment Directive 2014/53/EU. The complete declaration of conformity can be requested from us at:*

**groov»e**

**Unit J**

**Braintree Industrial Estate**

**Braintree Road**

**Ruislip**

**Middlesex**

**HA4 0EJ UK**

**[www.groov-e.co.uk](http://www.groov-e.co.uk)**

**Email: [info@groov-e.co.uk](mailto:info@groov-e.co.uk)**

**Telephone: 020 8839 0978**

*Register your purchase for extended warranty*

**[www.groov-e.co.uk/warranty](http://www.groov-e.co.uk/warranty)**

### **Authorised EU Representative**

*Rashmian EU Ltd*

*Robwyn House*

*Suite 3E*

*Corrintra*

*Castleblayney*

*Co. Monaghan*

*Ireland*