


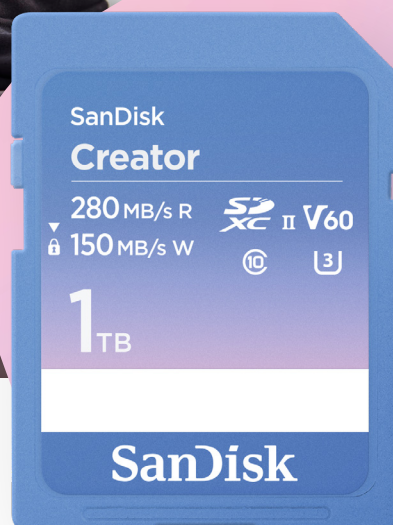

SanDisk®

CREATOR SD UHS-II CARD

The professional-grade SD card for creating professional-grade content.

Elevate your content with the SanDisk® Creator SD UHS-II Card, a high-performance memory card for creators who require professional-grade image and video capture with exceptional reliability. With capacities from 128GB up to 1TB,¹ you can shoot your inspiration, edit your shots, and publish your posts even faster, giving you more time to grow your following and refine your craft. And with one month of Adobe Creative Cloud⁴ on us, you'll have access to even more tools to help make sure your execution matches your vision.

HIGHLIGHTS

- **FOR CREATORS WITH A VISION.** The SanDisk® Creator Series helps you amplify your creative voice with a collection of products that elevate every step of your workflow.
- **SPACE FOR YOUR BIGGEST IDEAS.** Pursue your passion with up to 1TB¹ of capacity, and have the space you need to capture your memorable moments.
- **STREAMLINE YOUR PROCESS.** With rapid transfer speeds up to 280MB/s,² you can move, edit, and publish your content faster.
- **GIVE YOUR CREATIVE TOOLS A BOOST.** Unlock the capabilities of your UHS-II camera with a memory card engineered to keep up, even when shooting video in 6K.³
- **ADOBE CREATIVE CLOUD.**⁴ Shoot, edit, and publish like a pro with one included month of Adobe Creative Cloud,⁴ a suite of 20+ apps built for creators like you.
- **YOUR CONTENT: COVERED.** Recover accidentally deleted files with two years of RescuePRO® Deluxe data recovery software.⁵ And create worry-free with a lifetime limited warranty.⁶

SanDisk®

CREATOR SD UHS-II CARD

The professional-grade SD card
for creating professional-grade
content.



PRODUCT SPECIFICATIONS

INTERFACE	UHS-II
PRODUCT TYPE	SD CARD
CAPACITIES ¹	128GB, 256GB, 512GB, 1TB
DATA TRANSFER RATE ²	256GB-1TB: UP TO 280MB/S READ SPEED; UP TO 150MB/S WRITE SPEED 128GB: UP TO 280MB/S READ SPEED; UP TO 100MB/S WRITE SPEED
PRODUCT DIMENSIONS	0.94" X 1.25" X 0.08" (24 MM X 32 MM X 2.1 MM)
PRODUCT WEIGHT	0.06 LB 0.26 G
COUNTRY OF ORIGIN	TAIWAN
LIMITED WARRANTY ⁶	LIFETIME LIMITED

¹ 1GB=1,000,000,000 bytes. 1TB=1,000,000,000,000 bytes. Actual user storage less.

² [256GB-1TB] Up to 280MB/s read speeds. Up to 150MB/s write speed. Based on internal testing; performance may be lower depending on host device, interface, usage conditions, and other factors.

Compatible device required capable of reaching such speeds. 1MB=1,000,000 bytes.

[128GB] Up to 280MB/s read speed. Up to 100MB/s write speed. Based on internal testing; performance may be lower depending on host device, interface, usage conditions, and other factors. Compatible device required capable of reaching such speeds. 1MB=1,000,000 bytes.

³ Compatible device required. 6K (6144 x 3456) video support may vary based upon host device, file attributes, and other factors. See www.sandisk.com/HD.

⁴ Individual membership. Internet connection and Adobe ID required. Not available in all countries. Offer limited to 1 per SanDisk Creator product purchase; subject to acceptance of applicable Terms of Use. Offer must be redeemed by April 30, 2026, while activation code supplies last. SanDisk reserves the right to change or discontinue this offer at any time without notice. See www.sandisk.com/creator-cc for applicable legal terms and privacy policy.

⁵ Registration required; terms and conditions apply.

⁶ 30-year warranty in Germany, Canada and regions not recognizing lifetime warranty. See www.sandisk.com/wug.

SanDisk, the SanDisk logo and RescuePRO are registered trademarks or trademarks of SanDisk Corporation or its affiliates in the US and/or other countries. Adobe and Creative Cloud are either registered trademarks or trademarks of Adobe in the United States and/or other countries. SDXC is a trademark of SD-3C LLC. All other marks are the property of their respective owners. Product specifications subject to change without notice. Pictures shown may vary from actual products.

© 2024 SanDisk Corporation or its affiliates. All rights reserved.