


# Display panel system VARIO® WALL 5

Article number	555107	Sales unit quantity	1 Set
Colour	Dark blue	Sales unit EAN	4005546506494
Packaging unit	1 set	Packing weight (gross)	515.9 G
Base EAN	4005546506494	Country of origin	DE

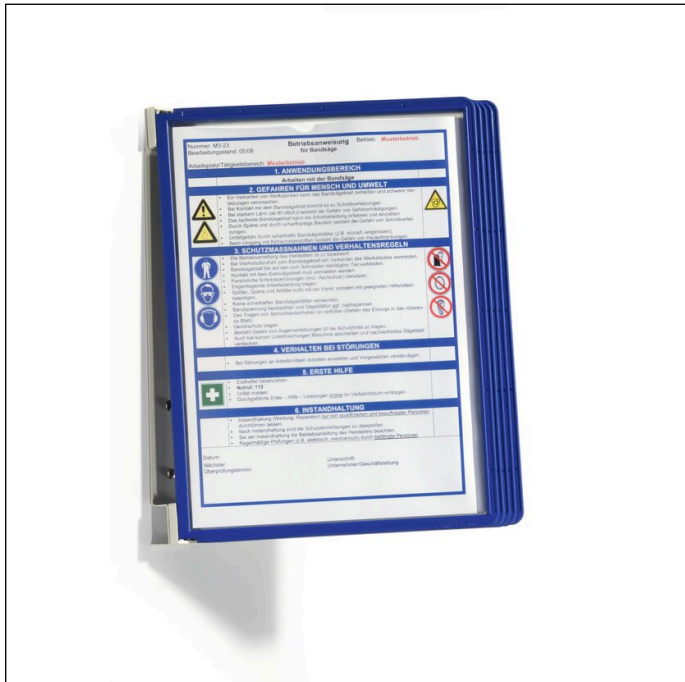

## Logos and awards



## Product description

- Complete display panel set for wall applications
- Wall mount with 5 SHERPA® display panels in A4 format
- Polypropylene display panels with coloured profile frame and low-reflection film suitable for scanners
- Simple wall mounting
- Practical pivot mechanism for simple replacement of the displays
- 5-year warranty

## Product features

Outer width (mm)	360
Outer height (mm)	325

# Display panel system VARIO® WALL 5

Outer depth / length	260 mm
Filling quantity / Filling quantity for	5 Display panel(s)
Format / Format for	A4
Orientation Format	Portrait
Brand	DURABLE
Inner display panel width (mm)	210
Inner display panel height (mm)	297
Set includes display panels	Yes
Rotate / Swivel amounts	No
Adjustable reading angle	No
Extendable	No
Tabs with blank labels included	Yes
Antibacterial	No
Warranty	5 years
Product features relating to documents	Can be scanned, anti-glare
Base / mount type	Wall mount