

TECHNICAL DATA SHEET

PRO-POWER

RoHS
Compliant

STAINLESS STEEL P-CLIPS MODELS: ACTSSPCLIPxx


 


Specifications:

Rubber-lined stainless-steel P-clips
304 stainless steel
Various sizes available
Supplied in bags of 25

Applications:

Ideal product for securing wires and cables. The rubber clamp is to protect cable and wire.

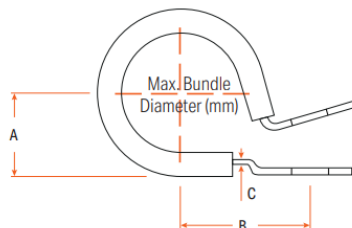

Important Notice: This data sheet and its contents (the "Information") belong to pro-POWER. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but pro-POWER assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where pro-POWER was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict pro-POWER's liability for death or personal injury resulting from its negligence.

PRO-POWER

TECHNICAL DATA SHEET

PRO-POWER

RoHS
Compliant

Models:

Model	Dimensions (mm)							Max. Bundle Dia. (mm)
	A	B	C	D	E	F	G	
ACTSSPCLIP5	3.5	13	0.8	6.6	12	15	7	5
ACTSSPCLIP6	4.5	15	0.8	6.6	12	15	7	6
ACTSSPCLIP8	5.5	16	0.8	6.6	12	15	7	8
ACTSSPCLIP10	6.5	18	0.8	6.6	12	15	7	10
ACTSSPCLIP13	8	19	0.8	6.6	12	15	7	13
ACTSSPCLIP16	9.5	20	0.8	6.6	12	15	7	16
ACTSSPCLIP19	11	21	0.8	6.6	12	15	7	19
ACTSSPCLIP21	12	22	0.8	6.6	12	15	7	21
ACTSSPCLIP25	15	24	0.8	6.6	12	15	7	25
ACTSSPCLIP29	16	26	0.8	6.6	12	15	7	29
ACTSSPCLIP35	19	29	0.8	6.6	12	15	7	35
ACTSSPCLIP40	22	32	0.8	6.6	12	15	7	40
ACTSSPCLIP50	25	35	0.8	6.6	12	15	7	50

Important Notice: This data sheet and its contents (the "Information") belong to pro-POWER. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but pro-POWER assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where pro-POWER was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict pro-POWER's liability for death or personal injury resulting from its negligence.

PRO-POWER