



Portable Monitors with Wireless Power Supply

PN: 32087, 32088

Description




The Verbatim Portable Touchscreen Monitor adds a new dimension to your work and play. Lighter thanks to its durable housing, it's ideal for travel, presentations, or as an extra screen for your phone, tablet, or gaming system.

For added convenience, the 16:9 monitor includes a wireless power supply via magnetic charging with the included MagSafe-compatible power bank, helping to preserve your laptop's battery or power your phone/tablet without draining them.

Compact and highly versatile, it boosts productivity and entertainment wherever you go. The 10-point touch screen supports swipe, scroll, drag, and pinch gestures for smooth, intuitive interaction.

Whether you're working remotely or gaming on the move, it's the perfect way to overcome one-screen limits and enhance your visual experience—anytime, anywhere.

- Available in two size: 13.3", 14"
- Display colours: 16.7M colours
- Supports: HDR, FreeSync, Low Blue Light
- Frame material: Plastic and Aluminium
- 2-year limited warranty

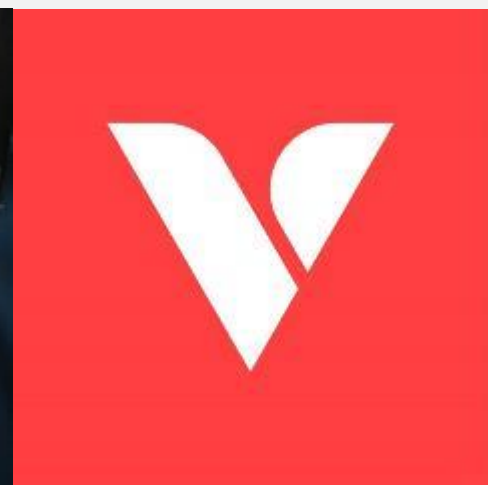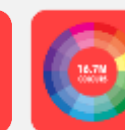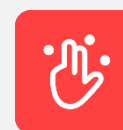

PN: 32087, 32088

| PN | Size | Resolution (H x V) | Touch | Power | Power Bank | Case |
|-------|-------|--------------------|----------------------|------------------|------------|-----------|
| 32087 | 13.3" | WUXGA 1920x1200 | Capacitive G+G | USB-C / Wireless | Yes | Aluminium |
| 32088 | 14" | FHD 1920x1080 | Multi-touch function | USB-C / Wireless | Yes | Plastic |



Languages

Front of pack: English (Product description also in French)

Back of pack: English, French, German, Dutch, Italian, Spanish, Portuguese, Polish, Russian, Czech, Hungarian, Serbian, Croatian, Traditional Chinese, Simplified Chinese, Korean, Japanese

Quick Installation Languages:

English, German + Technical support text in English, French, German, Dutch, Italian, Spanish, Portuguese, Polish, Russian, Czech, Hungarian, Serbian, Croatian, Traditional Chinese, Simplified Chinese, Korean, Japanese

Pack Content:

- Verbatim Touchscreen Monitor
- 2x USB-C to USB-C cable 1.0m
- HDMI-HDMI cable 1.5m
- EU power supply with UK adapter (5V, 3A)
- Neoprene protection sleeve
- Charge'n'Go Essential Power Bank Magnetic Wireless 5000mAh (PN 32225)
- Quick Start Guide

PN 32225

- Power Bank 5000 mAh
- Metal ring
- USB-C to USB-C cable (30cm)
- Quick Start Guide

| Reorder No. | Description | Tariff Code | Barcode | EAN-128 | EAN-14 |
|-------------|---|-------------|--------------|--|----------------------------------|
| 32087 | Portable 13.3 WUXGA Touch Monitor ALU with Wireless Power Supply incl. Power Bank 5000mAh | 8528521200 | 023942320876 | (02)0023942320876(37)02(91)491 (02)0023942320876(37)06(91)491 | 20023942320870 50023942320871 |
| 32088 | Portable 14 FHD Touch Monitor LIGHT with Wireless Power Supply incl. Power Bank 5000mAh | 8528521200 | 023942320883 | (02)0023942320883(37)02(91)491 (02)0023942320883(37)06(91)491 | 20023942320887 50023942320888 |

| Reorder No. | 32087 | 32088 |
|-----------------------------------|---------------------|---------------------|
| Product Dimensions L x W x H | 300 x 200 x 7/13 mm | 322 x 205 x 7/13 mm |
| Product Weight | 925 g | 550 g |
| Units per Pack | 1 | 1 |
| Pack Dimensions L x W x H | 425 x 253 x 56 mm | 430 x 256 x 58 mm |
| Pack Weight | 2170 g | 1860 g |
| Units per Inner Carton | 2 | 2 |
| Inner Carton Dimensions L x W x H | 422 x 132 x 262 mm | 442 x 132 x 280 mm |
| Inner Carton Weight | 4650 g | 4045 g |
| Units per Outer Carton | 6 | 6 |
| Outer Carton Dimensions L x W x H | 440 x 422 x 282 mm | 460 x 422 x 300 mm |
| Outer Cartons Weight | 14100 g | 12615 g |
| Outer Cartons per Layer | 6 | 6 |
| Layers per Pallet | 4 | 4 |
| Units per Pallet | 132 | 132 |

