


## Network Cable Stripper and Cutter, Professional Wire Stripper for UTP/FTP/STP/Coax Cables, Rotary Wire Stripping and Cutting Tool

**Product ID:** CABLESTRIPCUT

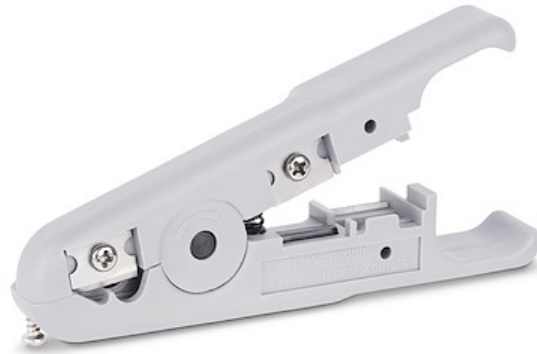

This portable Rotary Cable Stripper quickly and easily removes insulation from a variety of cables, making it an essential tool for network, coaxial, and multi-conductor cable preparation.

This cable stripping tool features an easy-to-use design that enables effortless removal of cable jackets and insulation. With its 360-degree rotation, it ensures precise control, reducing hand strain during repetitive tasks. The tool fits cables with an outer diameter ranging from 3.5mm (0.13in) to 7.5mm (0.29in), making it ideal for various types of cables including UTP, FTP, STP, coaxial, and multi-conductor cables.

Designed for use with a diverse range of cable types, this Network Cable Stripper features specific slots for both round and flat cables. It helps streamline your workflow by efficiently preparing coaxial, network, and audio cables for installation, making it an ideal tool for any professional or DIY project.

This Cable Stripping and Cutting Tool allows you to adjust the clamping depth using a Phillips head screw to accommodate different cable thicknesses. This ensures precise insulation removal without damaging internal conductors. The built-in cutting slot enables you to neatly trim cable lengths, eliminating the need for additional cutting tools.

## Certifications, Reports and Compatibility

## Applications

## Features

- ROTARY CABLE STRIPPING: Strip and cut UTP, FTP, STP, coaxial, and multi-conductor cables with 360-degree

rotation for controlled jacket and insulation removal; Supports cables with 3.5mm to 7.5mm (0.13in to 0.29in) diameters

- **VERSATILE COMPATIBILITY:** Compatible with round and flat cables, including coaxial, network, and audio; Features dedicated slots for efficient, accurate stripping, streamlining installations across multiple cable types
- **ADJUSTABLE DEPTH:** Easily adjust the clamping height using the Phillips head screw to match cable thickness; Minimize the risk of damaging conductors and other wires while ensuring precise and consistent insulation removal
- **INTEGRATED CUTTER:** Built-in cutting slot fits round and flat cables for reliable fray-free cutting; Cleanly trim excess cable length and eliminate the need for separate cutting tools, saving time during installations
- **COMPACT DESIGN:** Lightweight and portable, this tool fits seamlessly in your kit; Perfect for frequent use or occasional cabling tasks, ensuring you're always prepared on-site

---

#### Environmental

|                       |                                            |
|-----------------------|--------------------------------------------|
| Warranty              | 2 Years                                    |
| Operating Temperature | 0&degC to 50&degC (32&degF to 122&degF)    |
| Storage Temperature   | -40&degC to 70&degC (-40&degF to 158&degF) |
| Humidity              | 30% - 70%                                  |

---

#### Physical Characteristics

|                   |                  |
|-------------------|------------------|
| Color             | Gray             |
| Material          | ABS              |
| Product Length    | 4.3 in [10.9 cm] |
| Product Width     | 2.1 in [5.2 cm]  |
| Product Height    | 0.7 in [1.7 cm]  |
| Weight of Product | 1.6 oz [45.0 g]  |

---

#### Packaging Information

|                           |                  |
|---------------------------|------------------|
| Package Length            | 8.7 in [22.0 cm] |
| Package Width             | 5.0 in [12.8 cm] |
| Package Height            | 0.7 in [1.8 cm]  |
| Shipping (Package) Weight | 1.7 oz [49.0 g]  |

---

#### What's in the Box

|                     |                               |
|---------------------|-------------------------------|
| Included in Package | 1 - Cable Stripper and Cutter |
|                     | 1 - Quick-Start Guide         |

---

#### Warranty Information

|          |         |
|----------|---------|
| Warranty | 2 Years |
|----------|---------|

---

*\*Product appearance and specifications are subject to change without notice.*