

EMT 16 LG

Membrane spout, TPE, RAL 7035, M16



Products may differ in size, colour and appearance to those shown. If you require further information or customisation, please contact us directly.



Material	Thermoplastic elastomer
Temp. range min	-40 °C
Temp. range max	80 °C
Glow wire test	750 °C
Protection class	IP66
Ø Connection thread D	16
Length screw-in thread L	9,5 mm
Ø cable diameter min	1 mm
Ø cable diameter max	9 mm
External diameter ED	21 mm
Total length TL	11 mm
Ø Drilling	16 mm - 17,2 mm
Wall thickness S	2 mm
Product Color	RAL 7035
Order no. RAL 7035	10062559
Type	EMT 16 LG
Packing unit	100
EAN number	4007685625593
Tariff number	39269097
ETIM-Classification	EC000451

02.09.2025


Your Contact:

WISKA Hoppmann GmbH

Kisdorfer Weg 28 · 24568 Kaltenkirchen · Germany

☎ +49-4191-508-0 · 📠 +49-4191-508-209

contact@wiska.de · www.wiska.com

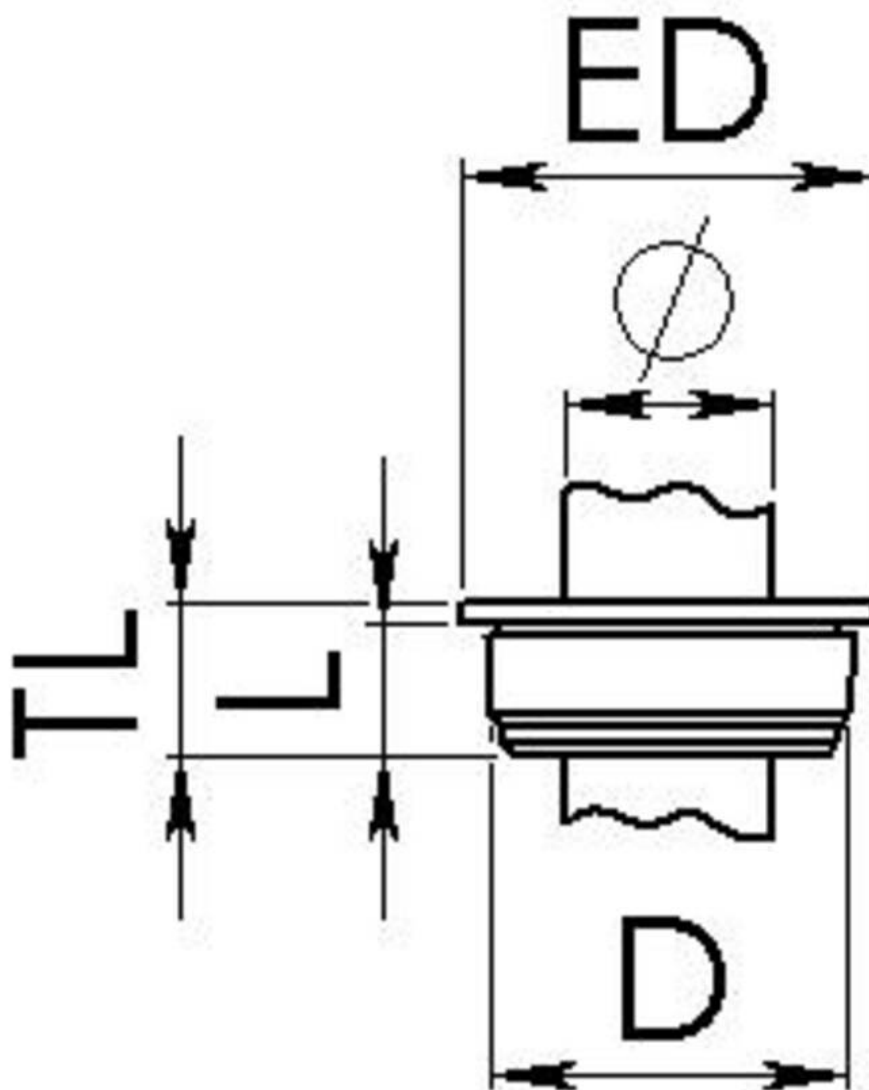

Your Contact:

WISKA Hoppmann GmbH

Kisdorfer Weg 28 · 24568 Kaltenkirchen · Germany

☎ +49-4191-508-0 · 📠 +49-4191-508-209

contact@wiska.de · www.wiska.com

Other technical data on request / subject to change without notice